

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

39357-0004

Status:

Active

Overview:

Eurostyle™ Terminal Blocks

Description:

3.50mm Pitch Beau Eurostyle™ Fixed Mount PCB Terminal Block, 4 Circuits

Documents:

3D Model

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

UL

E48521

General

Product Family

Terminal Blocks

Series

39357

Application

N/A

Component Type

One Piece

Overview

Eurostyle™ Terminal Blocks

Product Name

Eurostyle™ Fixed Mount

Type

Euro Block

UPC

756054634141

Physical

Circuits (Loaded)

4

Circuits (maximum)

4

Entry Angle

Horizontal

Flammability

94V-0

Lock to Mating Part

None

Net Weight

2.000/g

Number of Rows

1

Orientation

Vertical

PC Tail Length

3.50mm

PCB Retention

None

PCB Thickness - Recommended

1.60mm

Panel Mount

No

Pitch - Mating Interface

3.50mm

Pitch - Termination Interface

3.50mm

Polarized to Mating Part

No

Shrouded

Fully

Stackable

Yes

Surface Mount Compatible (SMC)

No

Temperature Range - Operating

-30°C to +85°C

Wire Size AWG

16, 18, 20, 22, 24, 26, 28

Wire Size mm²

0.20 - 1.00

Electrical

Current - Maximum per Contact

17.5A

Voltage - Maximum

300V

Material Info


Old Part Number

350104

Reference - Drawing Numbers

Sales Drawing

SD-39357-001

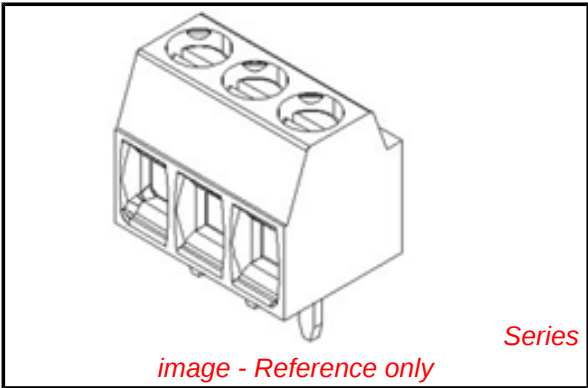

EU RoHS

RoHS Compliant by Exemption

REACH SVHC

Contains SVHC: No

Low-Halogen Status

Low-Halogen

China RoHS



Pb

Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

39357Series

This document was generated on 12/22/2014

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION