

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

19073-0170

Status:

Active

Overview:

Solderless Terminals

Description:

Avikrimp™ Ring Tongue Terminal for 10 to 12 AWG Wire, Stud Size 10 (M5), Length 27.71mm

Documents:

Drawing (PDF)

Product Specification PS-19902-011 (PDF)

Product Specification PS-19902-013 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

CSA	LR18689
UL	E32244

General

Product Family	Ring and Spade Terminals
Series	19073
Comments	Type II Insulated; Class 1 and 2
Crimp Quality Equipment	Yes
Mil-Spec	AS25036-112, MS25036-112
MolexKits	Yes
Overview	Solderless Terminals
Product Name	Avikrimp™
Type	Ring
UPC	800753077027

Physical

Barrel Type	Closed
Flammability	94V-2
Insulation	Nylon (PA)
Material - Plating Mating	Tin
Net Weight	2.318/g
Packaging Type	Bag
Plating min - Mating	2.540µm
Plating min - Termination	2.540µm
Stud Size	10 (M5)
Wire Insulation Diameter	5.70mm max.
Wire Size AWG	10, 12
Wire Size mm²	3.30 - 5.00

Material Info

Old Part Number	C-828-10
-----------------	----------

Reference - Drawing Numbers

Product Specification	PS-19902-011, PS-19902-013
Sales Drawing	SD-19073-007

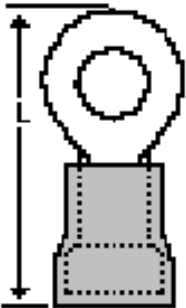


image - Reference only

Series

EU RoHS

ELV and RoHS Compliant

REACH SVHC

Not Reviewed

Low-Halogen Status

Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

19073Series

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
Crimp Head for the AT-200™ Pneumatic Hand Tool	0640050100
PremiumGrade™ Hand Crimp Tool	0640010100