




**SPECIFICATION
CONTROL DRAWING
Crystal Resonator**

FREQUENCY

16.000000MHz

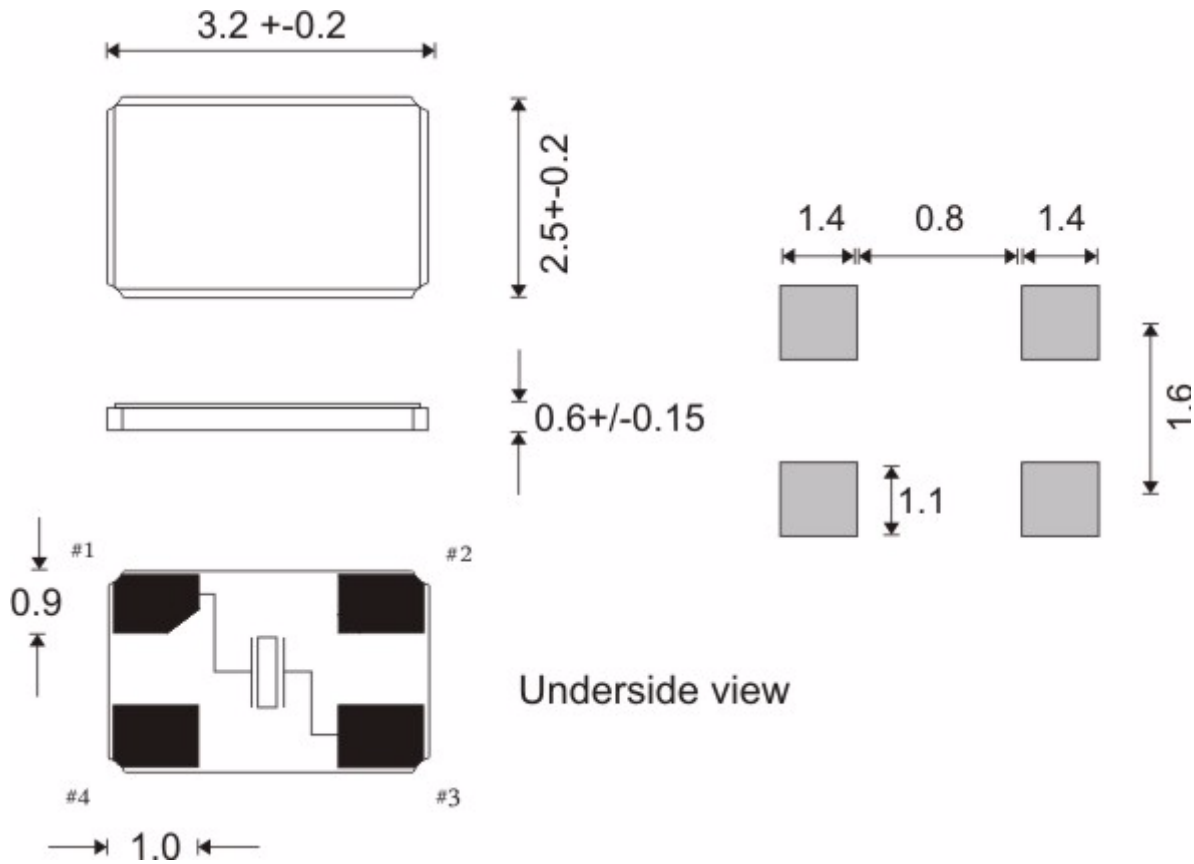

Holder Style	3X25X06 4-Pad
Mode	Fundamental
Adjustment Tolerance	As Required by CSR Chipset
Temperature Stability	As Required by CSR Chipset
Operating Temp. Range	-40°C to +85°C
Load Capacitance	9 pF
ESR	80 Max Ohm
Static Capacitance (C0)	As Required by CSR Chipset
Ageing	As Required by CSR Chipset
Marking	16.000 / YWWX

Amdt Date	Change Note	AEL Code
	CSR Approved	E3SB16.0000F09G11AE
		Issue Ref A