

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

**Part Number:** [39530-0004](#)  
**Status:** **Active**  
**Overview:** Eurostyle™ Terminal Blocks  
**Description:** 5.08mm Pitch Eurostyle™ Horizontal Plug, 4 Circuits

**Documents:**  
[3D Model](#) [Product Specification PS-39500-001 \(PDF\)](#)  
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)


**General**  
Product Family Terminal Blocks  
Series [39530](#)  
Application N/A  
Component Type Plug  
MolexKits Yes  
Overview [Eurostyle™ Terminal Blocks](#)  
Product Name ESE, Eurostyle™ Pluggable  
Type Euro Block  
UPC 822350531115

**Physical**  
Circuits (Loaded) 4  
Entry Angle Vertical  
Lock to Mating Part Yes  
Net Weight 7.110/g  
Number of Rows 1  
Orientation Horizontal  
Panel Mount No  
Pitch - Mating Interface 5.08mm  
Pitch - Termination Interface 5.08mm  
Polarized to Mating Part Yes  
Stackable No  
Temperature Range - Operating -40°C to +105°C  
Wire Size AWG 12, 14, 16, 18, 20, 22, 24, 26  
Wire Size mm² 0.13 - 3.31

**Electrical**  
Current - Maximum per Contact 18A  
Voltage - Maximum 300V

**Material Info**

**Reference - Drawing Numbers**  
Product Specification PS-39500-001, RPS-39500-001  
Sales Drawing SD-39530-001

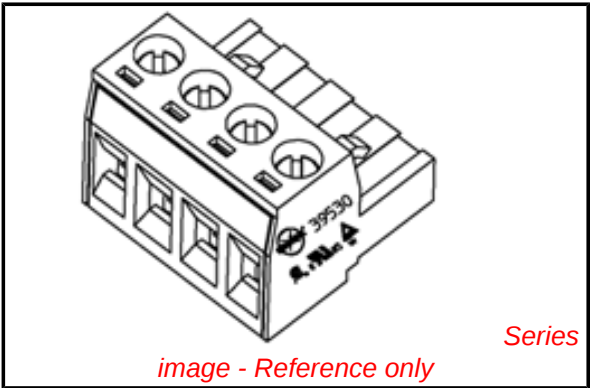

**EU RoHS**  
**RoHS Compliant by Exemption**  
**REACH SVHC**  
Not Reviewed  
**Low-Halogen Status**  
**Low-Halogen**

**China RoHS**  
  
Pb

**Need more information on product environmental compliance?**  
Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
For a multiple part number RoHS Certificate of Compliance, [click here](#)  
Please visit the [Contact Us](#) section for any non-product compliance questions.

**Search Parts in this Series**  
[39530Series](#)

**Mates With**  
39531 Vertical PCB Header, 39532 Horizontal PCB Header, 39538 Dual Level PCB Header, Open Ends, Most 5.08mm Pitch Industry Standard PCB Headers

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION