


## Header - SAMPLE PTSM 0,5/ 6-HH0-2,5SMDW - 1820686

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

Header, Nominal current: 6 A, Rated voltage (III/2): 250 V, Number of positions: 6, Pitch: 2.5 mm, Color: white, Contact surface: Tin, Assembly: Taped SMD/THT/THR components



### Key commercial data

Packing unit	5 pc
Minimum order quantity	5 pc
GTIN	 4 046356 787352
Weight per Piece (excluding packing)	1.5 g
Custom tariff number	85369010
Country of origin	Germany
Product key	AACMBA

### Technical data

Product type	Printed circuit board housing
Rated voltage (IEC)	250
Rated current (IEC)	6
Mounting type	Taped SMD/THT/THR components
Number of positions	6
Pitch	2.5 mm
Levels	Single-level
Type of locking	Without

### Classifications

eCl@ss

eCl@ss 4.0	27141111
eCl@ss 4.1	27141109
eCl@ss 5.0	27141190

# Header - SAMPLE PTSM 0,5/ 6-HH0-2,5SMDW - 1820686

## Classifications

### eCl@ss

eCl@ss 5.1	27141190
eCl@ss 6.0	27261101
eCl@ss 7.0	27440401
eCl@ss 8.0	27440401

### ETIM


ETIM 3.0	EC001121
ETIM 4.0	EC002643
ETIM 5.0	EC002637

### UNSPSC


UNSPSC 6.01	30211801
UNSPSC 7.0901	39121432
UNSPSC 11	34131203
UNSPSC 12.01	39121432
UNSPSC 13.2	39121432

## Drawings


Drilling diagram

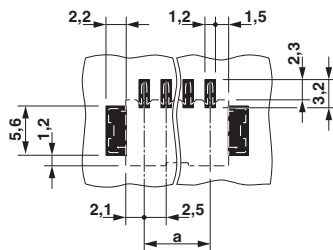

Dimensioned drawing

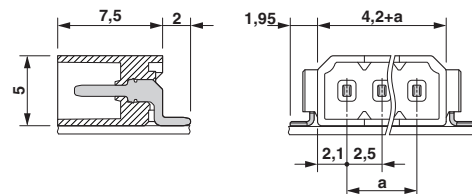

Diagram

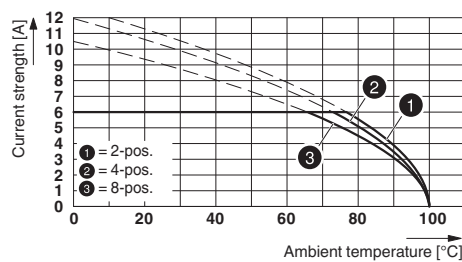

Derating curve for: PTSM 0,5/...-P-2,5 with PTSM 0,5/...-HH-2,5-SMD R..