

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

19204-0013

Status:

Active

Overview:

Splices

Description:

InsulKrimp™ 4 Way Splice for 14-16 AWG Wire

Documents:

Drawing (PDF)

Product Specification PS-19902-009 (PDF)

Product Specification PS-19902-011 (PDF)

Product Specification PS-19902-013 (PDF)

RoHS Certificate of Compliance (PDF)

General

Product Family

Series

Comments

Crimp Quality Equipment

Mil-Spec

Overview

Product Name

UPC

Splices

19204

4 Way Connector

Yes

N/A

Splices

4 Way, InsulKrimp™

800753051638

Physical

Barrel Type

Color - Resin

Insulation

Material - Metal

Material - Plating Mating

Material - Plating Termination

Material - Resin

Net Weight

Packaging Type

Plating min - Mating

Plating min - Termination

Temperature Range - Operating

Wire Insulation Diameter

Wire Size AWG

Wire Size mm²

Closed

Blue

PVC

Copper

Tin

Tin

PVC

4.372/g

Bag

2.540µm

2.540µm

-40°C to +105°C

4.45mm max.

14, 16

1.30 - 2.00

Electrical

Voltage - Maximum

600V

Material Info

Old Part Number

B-2XCX


Reference - Drawing Numbers

Product Specification

Sales Drawing

PS-19902-009, PS-19902-011, PS-19902-013

SD-19204-002

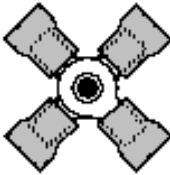

Series

image - Reference only

EU RoHS

ELV and RoHS

Compliant

REACH SVHC

Not Reviewed

Low-Halogen Status

Not Reviewed

China RoHS

Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

19204Series

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
Crimp Head for the AT-200™ Pneumatic Hand Tool	0640050100
PremiumGrade™ Hand Crimp Tool	0640010100
Crimp Head for the AT-200™ Pneumatic Hand Tool	0640050300
Hand Crimp Tool	0640010300