

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 19204-0025
Status: Active
Overview: Splices
Description: InsulKrimp™ 4 Way Splice for 10-12 AWG Wire

Documents:
[Drawing \(PDF\)](#)
[Product Specification PS-19902-009 \(PDF\)](#)
[Product Specification PS-19902-011 \(PDF\)](#)
[Product Specification PS-19902-013 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

General
Product Family Splices
Series 19204
Comments 4 Way Connector
Crimp Quality Equipment Yes
Mil-Spec N/A
Overview Splices
Product Name 4 Way, InsulKrimp™
UPC 800753051799

Physical
Barrel Type Closed
Color - Resin Natural
Insulation PVC
Material - Metal Copper
Material - Plating Mating Tin
Material - Plating Termination Tin
Material - Resin PVC
Net Weight 7.960/g
Packaging Type Bag
Plating min - Mating 2.540µm
Plating min - Termination 2.540µm
Temperature Range - Operating -40°C to +105°C
Wire Insulation Diameter 6.35mm max.
Wire Size AWG 10, 12
Wire Size mm² 3.30 - 5.00

Electrical
Voltage - Maximum 600V

Material Info
Old Part Number C-2XCX

Reference - Drawing Numbers
Product Specification PS-19902-009, PS-19902-011, PS-19902-013
Sales Drawing SD-19204-002

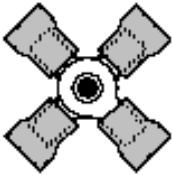


image - Reference only

Series

EU RoHS
ELV and RoHS
Compliant
REACH SVHC
Not Reviewed
Low-Halogen Status
Not Reviewed

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
19204Series

Application Tooling | FAQ
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.
Global

Description	Product #
Crimp Head for the AT-200™ Pneumatic Hand Tool	0640050100
PremiumGrade™ Hand Crimp Tool	0640010100
Crimp Head for the AT-200™ Pneumatic Hand Tool	0640050300
Hand Crimp Tool	0640010300