

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

19039-0009

Status:

Active

Overview:

Snap Plugs and Receptacles

Description:

Avikrimp™ Snap Plug Receptacle for 14-16 AWG Wire, PVC, Fits Male Plug Diameter 4.57mm

Documents:

Drawing (PDF)

Product Specification PS-19902-011 (PDF)

Product Specification PS-19902-013 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

CSA

LR18689

UL

E152602

General

Product Family

Quick Disconnects

Series

19039

Comments

Fits Male Plug Dia. 4.57mm

Crimp Quality Equipment

Yes

Insulated

Fully

Overview

Snap Plugs and Receptacles

Product Name

Avikrimp™

Type

Snap Receptacle

UPC

800753049437

Physical

Barrel Type

Closed

Color - Resin

Blue

Flammability

94V-0

Gender

Female

Glow-Wire Compliant

No

Insulation

PVC

Lock to Mating Part

None

Material - Metal

Brass

Material - Plating Mating

Tin

Material - Plating Termination

Tin

Material - Resin

PVC

Net Weight

1.452/g

Orientation

Straight

Packaging Type

Bag

Tab Thickness

N/A

Tab Width

N/A

Temperature Range - Operating

-40°C to +105°C

Termination Interface: Style

Crimp or Compression

Wire Insulation Diameter

3.81mm max.

Wire Size AWG

14, 16

Wire Size mm²

1.00 - 2.50

Electrical

Voltage - Maximum

Per Wire Specification

Material Info

Old Part Number

BRB-8180

Reference - Drawing Numbers

Product Specification

PS-19902-011, PS-19902-013

Sales Drawing

SD-19039-001

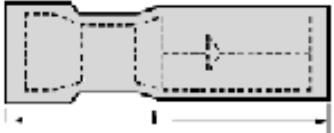


image - Reference only

Series

EU RoHS

ELV and RoHS

Compliant

REACH SVHC

Not Reviewed

Low-Halogen Status

Not Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
19039Series

Application Tooling | FAQ
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.
Global

Description	Product #
Hand Crimp Tool	0640012100
Crimp Head for the AT-200™ Pneumatic Hand Tool	0640052100

This document was generated on 02/24/2015

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION