

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [19073-0222](#)
Status: **Active**
Overview: [Solderless Terminals](#)
Description: Avikrimp™ Ring Tongue Terminal for 10 to 12 AWG Wire, Stud Size 8 (M4), Length 26.59mm

Documents:
[Drawing \(PDF\)](#) [Product Specification PS-19902-013 \(PDF\)](#)
[Product Specification PS-19902-011 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR18689
UL E32244

General

Product Family Ring and Spade Terminals
Series [19073](#)
Crimp Quality Equipment Yes
Mil-Spec N/A
Overview [Solderless Terminals](#)
Product Name Avikrimp™
Type Ring
UPC 800753077621

Physical


Barrel Type Closed
Flammability 94V-2
Insulation Nylon (PA)
Material - Plating Mating Tin
Net Weight 2.120/g
Packaging Type Bag
Stud Size 8 (M4)
Wire Insulation Diameter 5.72mm max.
Wire Size AWG 10, 12
Wire Size mm² 3.30 - 5.00

Material Info

Old Part Number C-836-08

Reference - Drawing Numbers

Product Specification PS-19902-011, PS-19902-013
Sales Drawing SD-19073-008

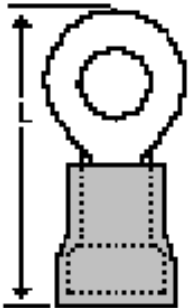

Series

image - Reference only

EU RoHS

**ELV and RoHS
Compliant**

REACH SVHC

Not Reviewed

Low-Halogen Status

Low-Halogen

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of
Compliance, [click here](#)

Please visit the [Contact Us](#) section for any
non-product compliance questions.

Search Parts in this Series

[19073Series](#)

Application Tooling | FAQ

*Tooling specifications and manuals are
found by selecting the products below.
Crimp Height Specifications are then
contained in the Application Tooling
Specification document.*

Global

Description	Product #
Crimp Head for the AT-200™ Pneumatic Hand Tool	0640050100
PremiumGrade™ Hand Crimp Tool	0640010100

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION