

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 19121-0009
Status: Active
Overview: Solderless Terminals
Description: InsulKrimp™ Flanged Spade Tongue Terminal for 18-22 AWG Wire, Stud Size 10 (M5)

Documents:
[Drawing \(PDF\)](#)
[Product Specification PS-19902-009 \(PDF\)](#)
[Product Specification PS-19902-011 \(PDF\)](#)
[Product Specification PS-19902-013 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR18689
UL E32244

General

Product Family Ring and Spade Terminals
Series 19121
Crimp Quality Equipment Yes
Mil-Spec N/A
Overview Solderless Terminals
Product Name InsulKrimp™
Type Spade
UPC 800753095298

Physical

Barrel Type Closed
Flammability 94V-0
Insulation PVC
Material - Plating Mating Tin
Net Weight 0.608/g
Packaging Type Bag
Stud Size 10 (M5)
Wire Insulation Diameter 3.68mm
Wire Size AWG 18, 20, 22
Wire Size mm² 0.25 - 1.50

Material Info

Old Part Number AA-215-10X

Reference - Drawing Numbers

Product Specification PS-19902-009, PS-19902-011, PS-19902-013
Sales Drawing SD-19121-001

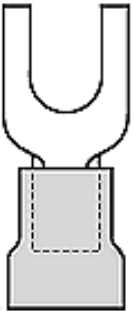


image - Reference only

Series

EU RoHS
ELV and RoHS
Compliant
REACH SVHC
Not Reviewed
Low-Halogen Status
Not Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
19121Series

Application Tooling | FAQ
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.
Global

Description	Product #
Crimp Head for the AT-200™ Pneumatic Hand Tool	0640050100
PremiumGrade™ Hand Crimp Tool	0640010100
Crimp Head for the AT-200™ Pneumatic Hand Tool	0640050300
Hand Crimp Tool	0640010300