

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

19139-0016

Status:


Active

Overview:

Solderless Terminals

Description:

Avikrimp™ Block Spade Terminal for 18-22 AWG Wire, Stud Size 4 (M2.6)

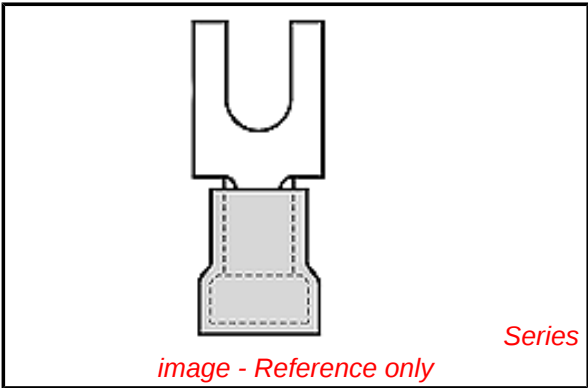

Documents:

Drawing (PDF)

Product Specification PS-19902-011 (PDF)

Product Specification PS-19902-013 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR18689
UL	E32244
General	
Product Family	Ring and Spade Terminals
Series	19139
Crimp Quality Equipment	Yes
Mil-Spec	N/A
Overview	Solderless Terminals
Product Name	Avikrimp™
Type	Spade Block
UPC	800753102606

Physical	
Barrel Type	Closed
Flammability	94V-2
Insulation	Nylon (PA)
Material - Plating Mating	Tin
Net Weight	1.217/g
Packaging Type	Bag
Plating min - Mating	2.540µm
Plating min - Termination	2.540µm
Stud Size	4 (M2.6)
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	3.56mm
Wire Size AWG	18, 20, 22
Wire Size mm²	0.25 - 1.50

Electrical	
Voltage - Maximum	600V

Material Info	
Old Part Number	AA-838-04

Reference - Drawing Numbers	
Product Specification	PS-19902-011, PS-19902-013
Sales Drawing	SD-19139-001

EU RoHS

ELV and RoHS

Compliant

REACH SVHC

Not Reviewed

Low-Halogen Status

Not Reviewed

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

19139Series

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
Crimp Head for the AT-200™ Pneumatic Hand Tool	0640050100
PremiumGrade™ Hand Crimp Tool	0640010100

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION