

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [19141-0081](#)
Status: **Active**
Overview: [Solderless Terminals](#)
Description: Krimptite™ Spade Tongue Terminal for 10-12 AWG Wire

Documents:
[Drawing \(PDF\)](#) [Product Specification PS-19902-013 \(PDF\)](#)
[Product Specification PS-19902-011 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR18689
UL E32244

General

Product Family Ring and Spade Terminals
Series [19141](#)
Crimp Quality Equipment Yes
Mil-Spec N/A
Overview [Solderless Terminals](#)
Product Name Krimptite™
Type Spade
UPC 800755086652

Physical


Barrel Type Closed
Insulation None
Material - Plating Mating Tin
Net Weight 1.633/g
Packaging Type Bag
Plating min - Mating 2.540µm
Plating min - Termination 2.540µm
Stud Size 5-6 (M3-3.5)
Wire Size AWG 10, 12
Wire Size mm² 3.30 - 5.00

Material Info

Old Part Number C-141-06

Reference - Drawing Numbers

Product Specification PS-19902-011, PS-19902-013
Sales Drawing CCD10302

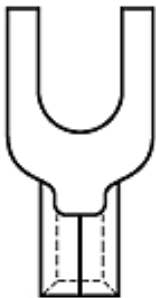

Series

image - Reference only

EU RoHS

**ELV and RoHS
Compliant**

REACH SVHC

Not Reviewed

Low-Halogen Status

Low-Halogen

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of
Compliance, [click here](#)

Please visit the [Contact Us](#) section for any
non-product compliance questions.

Search Parts in this Series

[19141Series](#)

Application Tooling | FAQ

*Tooling specifications and manuals are
found by selecting the products below.
Crimp Height Specifications are then
contained in the Application Tooling
Specification document.*

Global

Description	Product #
PremiumGrade™ Hand Crimp Tool	0640030100
Crimp Head for the AT-200™ Pneumatic Hand Tool	0640070100