

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

19147-0019

Status:

Active

Overview:

VersaKrimp™ Terminals and Splices

Description:

VersaKrimp™ Block Spade Terminal for 18-22 AWG Wire

Documents:

Drawing (PDF)

Product Specification PS-19902-013 (PDF)

Product Specification PS-19902-011 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

CSA

LR18689

UL

E32244

General

Product Family

Ring and Spade Terminals

Series

19147

Crimp Quality Equipment

Yes

Mil-Spec

N/A

Overview

VersaKrimp™ Terminals and Splices

Product Name

VersaKrimp™

Type

Spade

UPC

800755088403

Physical

Barrel Type

Closed - Brazed

Insulation

None

Material - Plating Mating

Tin

Net Weight

0.428/g

Packaging Type

Bag

Plating min - Mating

2.540µm

Plating min - Termination

2.540µm

Stud Size

5-6 (M3-3.5)

Termination Interface: Style

Crimp or Compression

Wire Size AWG

18, 20, 22

Wire Size mm²

0.35 - 0.80

Material Info

Old Part Number

AA-338-06

Reference - Drawing Numbers

Product Specification

PS-19902-011, PS-19902-013

Sales Drawing

AACD30301

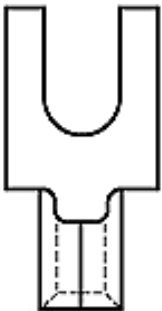


image - Reference only

Series

EU RoHS

ELV and RoHS

Compliant

REACH SVHC

Not Reviewed

Low-Halogen Status

Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

19147Series

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
PremiumGrade™	0640030100
Hand Crimp Tool	
Crimp Head for the	0640070100
AT-200™ Pneumatic	
Hand Tool	

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION