

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

15-29-1027

Status:


Active

Overview:

C-Grid® Products

Description:

2.54mm Pitch C-Grid® Shunt Terminal Housings, 0.762μm Gold (Au), 2 Circuits, with Pin Stop

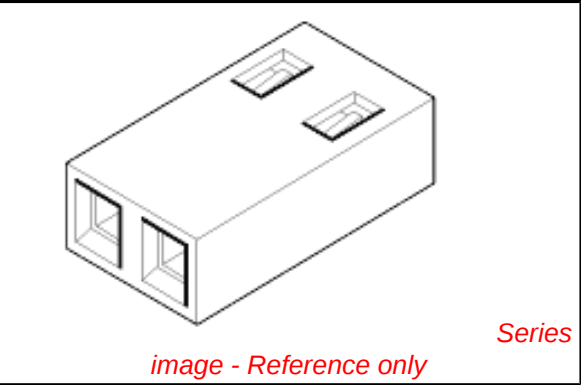

Documents:

3D Model

Drawing (PDF)

Product Specification PS-7859 (PDF)

Test Summary TS-7859-0001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR19980
UL	E29179
General	
Product Family	Accessories
Series	7859
Component Type	Shunt
Overview	C-Grid® Products
Product Name	C-Grid®, C-Grid III™, SL™
UPC	800753604414
Physical	
Circuits (Loaded)	2
Color - Resin	Black
Flammability	94V-0
Lock to Mating Part	No
Material - Metal	Phosphor Bronze
Material - Resin	Polyester
Net Weight	0.164/g
Number of Rows	1
Packaging Type	Bag
Temperature Range - Operating	-40°C to +105°C
Electrical	
Current - Maximum per Contact	5A
Material Info	
Old Part Number	7859-2A561N
Reference - Drawing Numbers	
Product Specification	PS-7859
Sales Drawing	SDA-7859-2A***N
Test Summary	TS-7859-0001

EU RoHS

ELV and RoHS Compliant

REACH SVHC

Not Reviewed

Low-Halogen Status

Not Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

7859Series

Use With

70280 C-Grid Breakaway Header, 71308 C-Grid® Header, 71764 C-Grid® Breakaway Header, 42375 KK® Breakaway Header, 42377 KK® Breakaway Header, 4030 KK® Wire-to-Board Header, 42152 KK® Wire-to-Board Header

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION