



# Ecoclick Starters

S10 4-65W SIN 220-240V WH EUR

Range of premium-quality glow switch starters for igniting fluorescent lamps with electromagnetic ballast.

## Product data

### • General Characteristics

System Description	Single
Cap-Base Information	2P
Colour of the Housing	White

### • Electrical Characteristics

Lamp Wattage	4-65 W
Voltage	220-240 V
Pulse Voltage	900 (min) V
Non Reclosure Voltage	140 (min) V
Capacitor	yes

### • Luminaire Design Requirements

Ambient Temperature	-15 (min), 75 (max) C
---------------------	-----------------------

### • Product Dimensions

Overall Length C	40.3 (max) mm
------------------	---------------


Overall Width E	21.5 (max) mm
-----------------	---------------

### • Product Data

Order code	697691 31
Full product code	871150069769131
Full product name	S10 4-65W SIN 220-240V WH EUR
Order product name	S10 4-65W SIN 220-240V WH EUR/20X10CT
Pieces per pack	1
Packing configuration	20X10CT
Packs per outerbox	200
Bar code on pack - EAN1	8711500697691
Bar code on intermediate packing - EAN2	8711500697899
Bar code on outerbox - EAN3	8711500697905
Logistic code(s) - 12NC	928392220238
Net weight per piece	7.000 gr

**PHILIPS**

Dimensional drawing

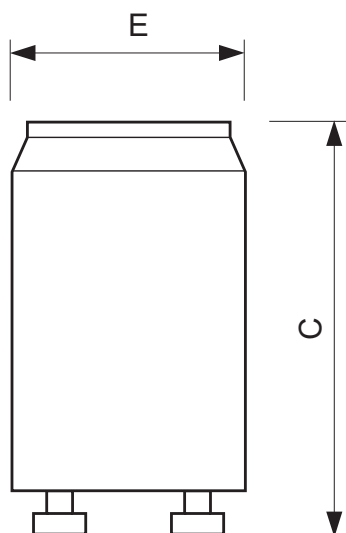

S10 4-65W SIN 220-240V WH EUR

Product	C (Max)	E (Max)
S10 4-65W SIN 220-240V WH EUR	40.3	21.5



© 2014 Koninklijke Philips N.V. (Royal Philips)  
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips N.V. (Royal Philips) or their respective owners.

[www.philips.com/lighting](http://www.philips.com/lighting)

2014, October 31  
data subject to change