

Data & Signal, Plug, 2.5 mm, 2-pole, solder terminal, shielded



Description

- Solder terminal:
for cable mounting
- Data and Signal transfer
- Data and Signal Connectors 2-pole, shielded, straight

References

Alternative: Housing insulated [4801.1210](#)


Weblinks

[pdf-datasheet](#), [html-datasheet](#), [General Product Information](#), [RoHS](#), [CHINA-RoHS](#), [REACH](#), [Mating Connectors](#), [e-Shop](#), [SCHURTER-Stock-Check](#), [Distributor-Stock-Check](#)

Technical Data

Diameter	2.5 mm	Allowable Operation Temp.	-20 °C to 70 °C
Number of Poles	2-pole	Terminal	solder terminal
Ratings DC	1 A / 12VDC	Housing	screened
Ratings AC	0.65 A / 12 VAC	Style	straight
Dielectric Strength	500 VDC	Lifetime	10000 Insertions
Insulation Resistance	> 10000 MΩ @ 500VDC		

Dimensions

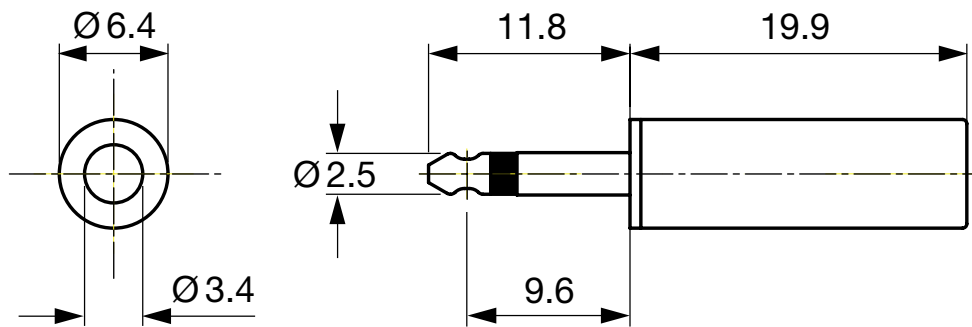

All Variants

Product group	Diameter [mm]	Number of Poles	Terminal	Order Number
Data and Signal Plug/ Sockets	2.5	2-pole	solder terminal	4801.1200

Most Popular.

Availability for all products can be searched real-time: <http://www.schurter.com/en/Stock-Check/Stock-Check-SCHURTER>

Packaging unit 100 Pcs

Mating Outlets/Connectors

Category / Description

[Data and Signal Plug/Socket Overview complete](#)

Daten & Signal, Socket, 2.5 mm, 2-pole, solder terminal, shielded

4801.2200

[Data and Signal Plug/Socket further types to 4801 UK-Stecker, D=2,5mm](#)