



MASTER TL-D Super 80

MASTER TL-D Super 80 58W/835 1SL

Low-pressure mercury discharge lamps with a tubular 26 mm envelope

Product data

• General Characteristics

Cap-Base	G13 [Medium Bi-Pin Fluorescent]
Cap-Base Information	Green Plate
Bulb	T8 [26 mm]
Life to 10% failures EM	12000 hr
Life to 10% fail	17000 hr
Preheat EL,3h	
Life to 10% fail	10000 hr
Nonpreh EL,3h	
Life to 50% failures EM	15000 hr
Life to 50% fail	20000 hr
Preheat EL,3h	
Life to 50% fail	12000 hr
Nonpreh EL,3h	
LSF EM 2000h Rated, 3h cycle	99 %
LSF EM 4000h Rated, 3h cycle	99 %
LSF EM 6000h Rated, 3h cycle	99 %
LSF EM 8000h Rated, 3h cycle	99 %
LSF EM 12000h Rated,3h cycle	89 %
LSF EM 16000h Rated,3h cycle	33 %
LSF EM 20000h Rated,3h cycle	2 %

• Light Technical Characteristics

Colour Code	835 [CCT of 3500K]
Colour Rendering Index	85 Ra8
Colour Designation	White

Colour Temperature	3500 K
Luminous Flux EM 25°C, Rated	5240 Lm
Luminous Flux EM 25°C, Nominal	5240 Lm
Lum Efficacy Rated EM 25°C	90 Lm/W
LLMF EM 2000h Rated	96 %
LLMF EM 4000h Rated	95 %
LLMF EM 6000h Rated	94 %
LLMF EM 8000h Rated	93 %
LLMF EM 12000h Rated	92 %
LLMF EM 16000h Rated	91 %
LLMF EM 20000h Rated	90 %
Design Temperature	25 C
Chromaticity Coordinate X	409 -
Chromaticity Coordinate Y	394 -

• Electrical Characteristics

Lamp Wattage	58 W
Lamp Wattage EM 25°C, Nominal	58 W
Lamp Wattage EM 25°C, Rated	58.5 W
Lamp Voltage EM 25°C	111 V

MASTER TL-D Super 80

Lamp Current EM 0.670 A
25°C
Dimmable yes

• Environmental Characteristics

Energy Efficiency A
Label (EEL)
Mercury (Hg) 2.0 mg
Content
Energy consumption 68 kWh
kWh/1000h

 

• Product Dimensions

Base Face to Base 1500.0 (max) mm
Face A
Insertion Length B 1504.7 (min), 1507.1 (max) mm
Overall Length C 1514.2 (max) mm
Diameter D 28 (max) mm

• Product Data

Order code 632166 40
Full product code 871150063216640
Full product name MASTER TL-D Super 80 58W/835 1SL
Order product name MASTER TL-D Super 80 58W/835 1SL/25
Pieces per pack 1
Packing configuration 25
Packs per outerbox 25
Bar code on pack - EAN1 8711500632166
Bar code on outerbox - EAN3 8711500643490
Logistic code(s) - 12NC 927922083523
ILCOS code FD-58/35/1B-E-G13
Net weight per piece 172.600 gr

Dimensional drawing


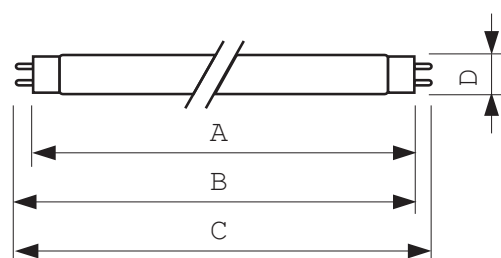


G13

MASTER TL-D Super 80 58W/835 1SL

Product	A (Max)	B (Min)	B (Max)	C (Max)	D (Max)
TL-D 58W/835	1500.0	1504.7	1507.1	1514.2	28

Photometric data

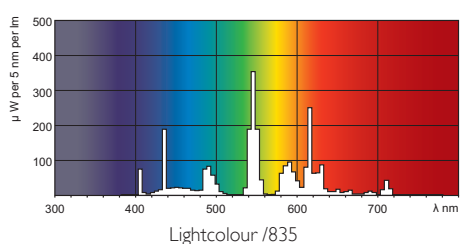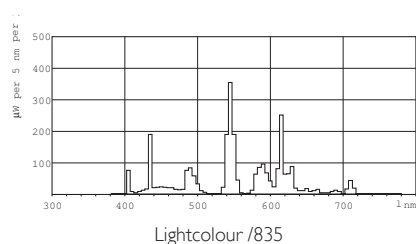



© 2014 Koninklijke Philips N.V. (Royal Philips)
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips N.V. (Royal Philips) or their respective owners.

www.philips.com/lighting

2014, October 31
data subject to change