


Item no.: 852-101  
Product description: 5-Port 100BASE-TX Industrial Switch

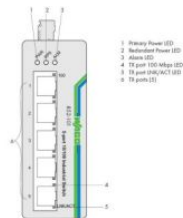

Produkt kann von Bild abweichen / product may differ

Packing unit 1 piece

Ports	5 x 10/100Base-TX (RJ-45)
Maximum distances	10/100Base-TX: 100 m
Supply voltage	DC 9 V ... 48 V (line length < 30 m)
Energy consumption max.	3.84 W
Operating temperature	0 °C ... +60°C
Storage temperature	-20 °C ... +80°C
Relative air humidity	95 %
Vibration resistance	acc. to IEC 60068-2-6
Shock resistance	acc. to IEC 60068-2-27
Degree of protection	IP 30
EMC immunity to interference	in acc. with EN 61000-6-2 (2005)
EMC emission of interference	in acc. with EN 61000-6-4 (2001)
Weight	639 g
Color	black
Height	120 mm
Height	4.724 in
Width	50 mm
Width	1.969 in
Depth	105 mm
Depth	4.134 in
Customs Tariff No.	85176200

Country of Origin

Taiwan

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected