

EMEA Region

639235

EMEA Region

BRIGHT

- Provides 80 lumens of light in high mode
- Uses premium Nichia® LED technology.



VERSATILE

- Spot, flood, strobe and area lights plus night vision LEDs
- Push button switch cycles modes



ECONOMICAL

- Runs 26 hours on one set of batteries in high mode
- LEDs never need replacing



WEATHERPROOF

- Meets IEC 60529 IPX4 standards
- Continues to operate after exposure to splashing water from all directions



Lightweight, versatile and comfortable, the Energizer® 6-LED Headlight is perfect for electrical, plumbing, HVAC or other work that requires both hands. It puts light where you are looking and has a swivel adjustment with ratchet positioning for accurate aim.

Variable light sources allow you to choose the best illumination for the job – area, flood, spot or night vision. Also, this light mounts securely to hard hats or can be comfortably worn around the head for long periods of time.



Before Using Your Flashlight:

Please read all instructions and cautionary markings on the package and light

Product Detail:

- Designation:** Energizer
6-LED Headlight
- SAP:** 639235
- Colour:** Orange
- Power Source:** Three "AAA"
- IEC:** LR03
- Lamp:** Four White LEDs, Two Red LEDs
- Lamp Life (hr):** Lifetime


| Mode: | 4 White | 2 Spot | 2 Flood | Red |
|------------------------------|---------|--------|---------|-----|
| Lamp Output (lumens): | 80 | 60 | 30 | 4 |
| Run Time (h:mm): | 8:30 | 13 | 26 | 25 |
| Beam Distance (m): | 19 | 19 | 5 | - |

- Weight:** 87.5 grams with batteries
- Dimensions (mm):** 45 x 40 x 73

Performance:

Run Time

Continuous Drain to
End of Useable Light (21° C)

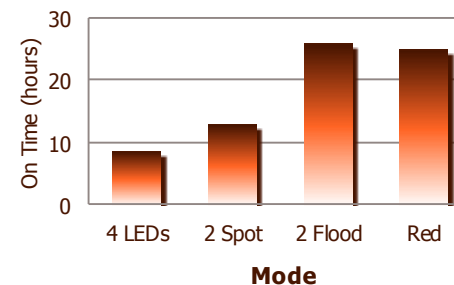

Tested according to ANSI/NEMA FL 1 Standards.

Important Notice

This datasheet contains information specific to products manufactured at the time of its publication
Contents herein do not constitute a claim or warranty

©Energizer / All Rights Reserved

Energizer

1-800-383-7323 USA/CAN