

# Cable trunking SES® with slots and base punching




GF-DIN-A7/5  
GF-DIN-A6/4



## GF-DIN-A7/5 -A6/4


|                                |                                |
|--------------------------------|--------------------------------|
| <b>Material:</b>               | Rigid PVC quality 9051 LF      |
| <b>Colours:</b>                | grey RAL7030 - black           |
| <b>Operating temperatures:</b> | -5 to +65°C                    |
| <b>Volume resistivity:</b>     | 10 <sup>15</sup> Ω.cm          |
| <b>Dielectric strength:</b>    | 15kV/mm                        |
| <b>Spécification:</b>          | V0 UL94                        |
| <b>Standard length:</b>        | 2 meters                       |
| <b>Double sided adhesive:</b>  | upon request                   |
| <b>Minimum delivery:</b>       | 1 complete packing (with lids) |

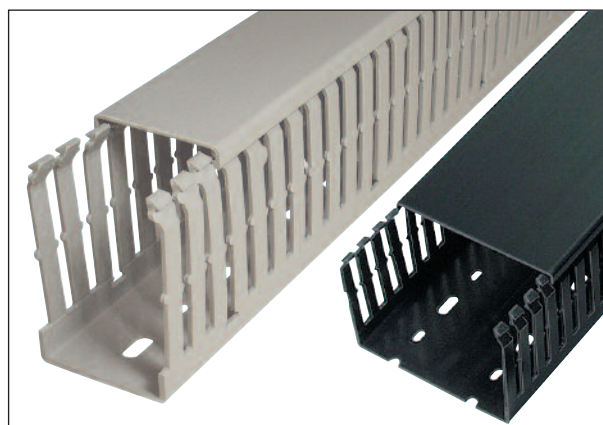


Example for order:

Colours: grey 013 black 010

| code group | detail article | code colour |
|------------|----------------|-------------|
| 0845       | xxxxxx         | xxxxxx      |

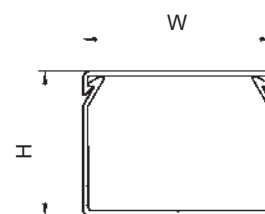


| type                   | trunking<br>art. no. | <br>m | outside dim. |         | cables per trunking<br>(filling 50 %) |            |            | lids<br>(alone) |    | <br>m |
|------------------------|----------------------|------------------------------------------------------------------------------------------|--------------|---------|---------------------------------------|------------|------------|-----------------|----|--------------------------------------------------------------------------------------------|
|                        |                      |                                                                                          | H<br>mm      | W<br>mm | 1<br>mm²                              | 1,5<br>mm² | 2,5<br>mm² | art. no.        |    |                                                                                            |
| GF-DIN-A7/5 25 x 25    | 0845 0031 ***        | 48                                                                                       | 23           | 23      | 25                                    | 21         | 17         | 0845 0640 ***   | 48 |                                                                                            |
| GF-DIN-A7/5 37,5x 25   | 0845 0041 ***        | 48                                                                                       | 35,5         | 23      | 44                                    | 36         | 30         | 0845 0640 ***   | 48 |                                                                                            |
| GF-DIN-A7/5 37,5x 37,5 | 0845 0051 ***        | 24                                                                                       | 35,5         | 35,5    | 74                                    | 61         | 51         | 0845 0645 ***   | 24 |                                                                                            |
| GF-DIN-A7/5 37,5x 50   | 0845 0061 ***        | 24                                                                                       | 35,5         | 48      | 105                                   | 86         | 72         | 0845 0650 ***   | 24 |                                                                                            |
| GF-DIN-A7/5 50 x 25    | 0845 0131 ***        | 48                                                                                       | 48           | 23      | 62                                    | 51         | 42         | 0845 0640 ***   | 48 |                                                                                            |
| GF-DIN-A7/5 50 x 37,5  | 0845 0141 ***        | 24                                                                                       | 48           | 35,5    | 104                                   | 85         | 71         | 0845 0645 ***   | 24 |                                                                                            |
| GF-DIN-A7/5 50 x 50    | 0845 0151 ***        | 24                                                                                       | 48           | 48      | 146                                   | 120        | 100        | 0845 0650 ***   | 24 |                                                                                            |
| GF-DIN-A7/5 50 x 75    | 0845 0152 ***        | 24                                                                                       | 48           | 73      | 230                                   | 189        | 158        | 0845 0655 ***   | 24 |                                                                                            |
| GF-DIN-A7/5 50 x 100   | 0845 0153 ***        | 12                                                                                       | 48           | 98      | 315                                   | 259        | 216        | 0845 0630 ***   | 12 |                                                                                            |
| GF-DIN-A7/5 50 x 125   | 0845 0154 ***        | 12                                                                                       | 48           | 123     | 399                                   | 328        | 274        | 0845 0665 ***   | 12 |                                                                                            |
| GF-DIN-A7/5 75 x 25    | 0845 0211 ***        | 48                                                                                       | 73           | 25      | 101                                   | 83         | 69         | 0845 0640 ***   | 48 |                                                                                            |
| GF-DIN-A7/5 75 x 37,5  | 0845 0221 ***        | 24                                                                                       | 73           | 35,5    | 161                                   | 132        | 111        | 0845 0645 ***   | 24 |                                                                                            |
| GF-DIN-A7/5 75 x 50    | 0845 0231 ***        | 24                                                                                       | 73           | 48      | 227                                   | 186        | 156        | 0845 0650 ***   | 24 |                                                                                            |
| GF-DIN-A7/5 75 x 75    | 0845 0241 ***        | 24                                                                                       | 73           | 73      | 358                                   | 294        | 246        | 0845 0655 ***   | 24 |                                                                                            |
| GF-DIN-A7/5 75 x 100   | 0845 0251 ***        | 12                                                                                       | 73           | 98      | 489                                   | 402        | 336        | 0845 0630 ***   | 12 |                                                                                            |
| GF-DIN-A7/5 75 x 125   | 0845 0261 ***        | 12                                                                                       | 73           | 123     | 620                                   | 509        | 426        | 0845 0665 ***   | 12 |                                                                                            |
| GF-DIN-A6/4 100 x 50   | 0845 0286 013        | 24                                                                                       | 100          | 48      | 304                                   | 250        | 209        | 0845 0650 013   | 24 |                                                                                            |
| GF-DIN-A6/4 100 x 75   | 0845 0296 013        | 12                                                                                       | 100          | 73      | 484                                   | 398        | 333        | 0845 0655 013   | 24 |                                                                                            |

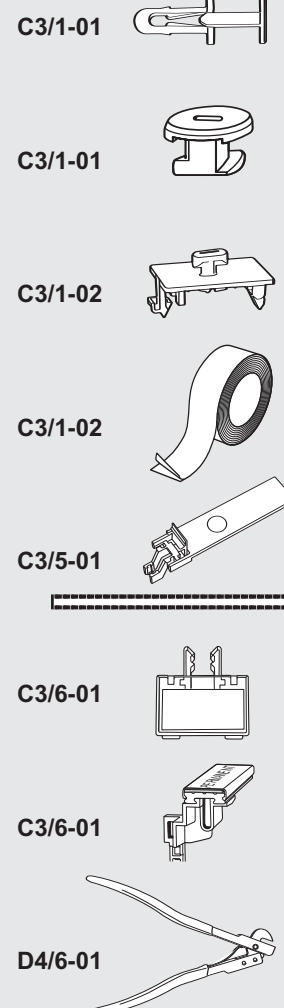




GF-DIN-A7/5

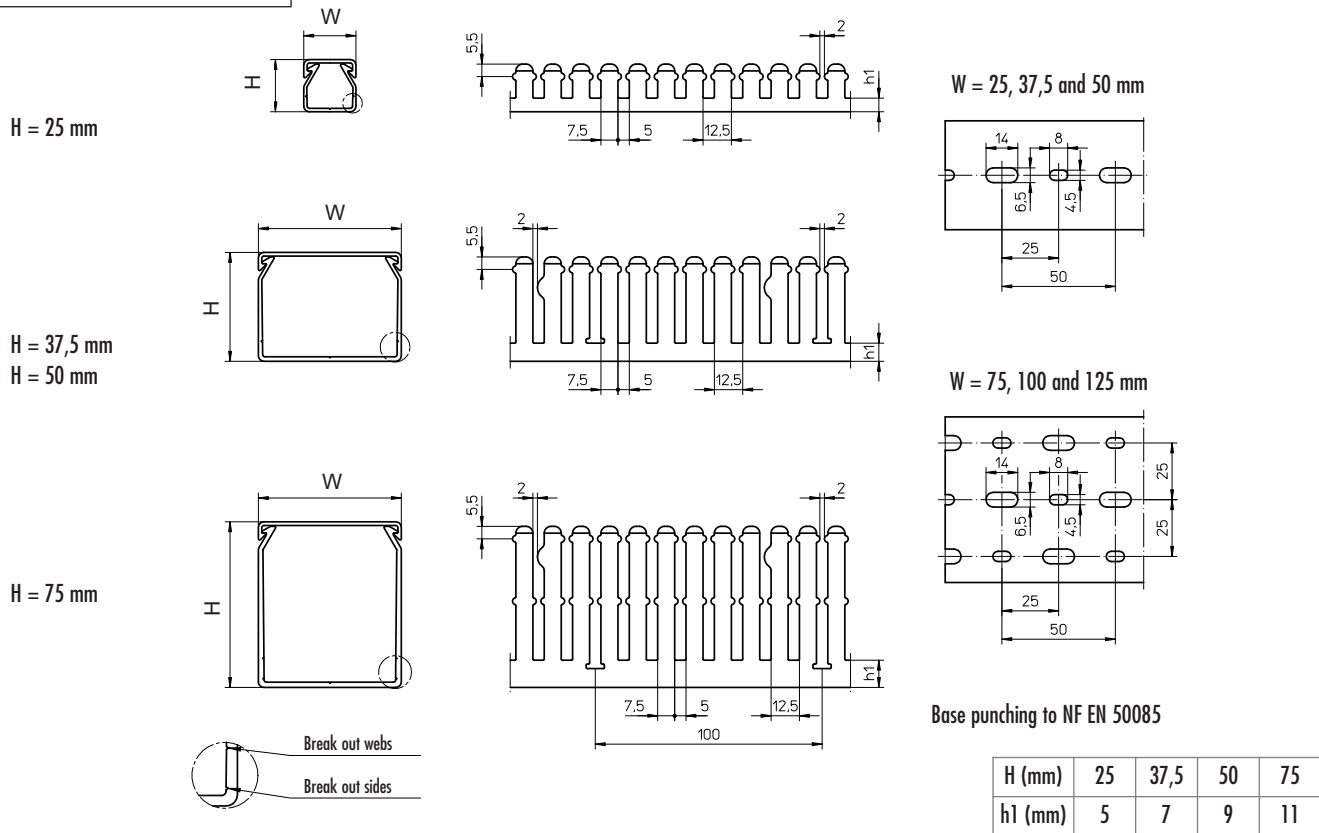

GF-DIN-A6/4

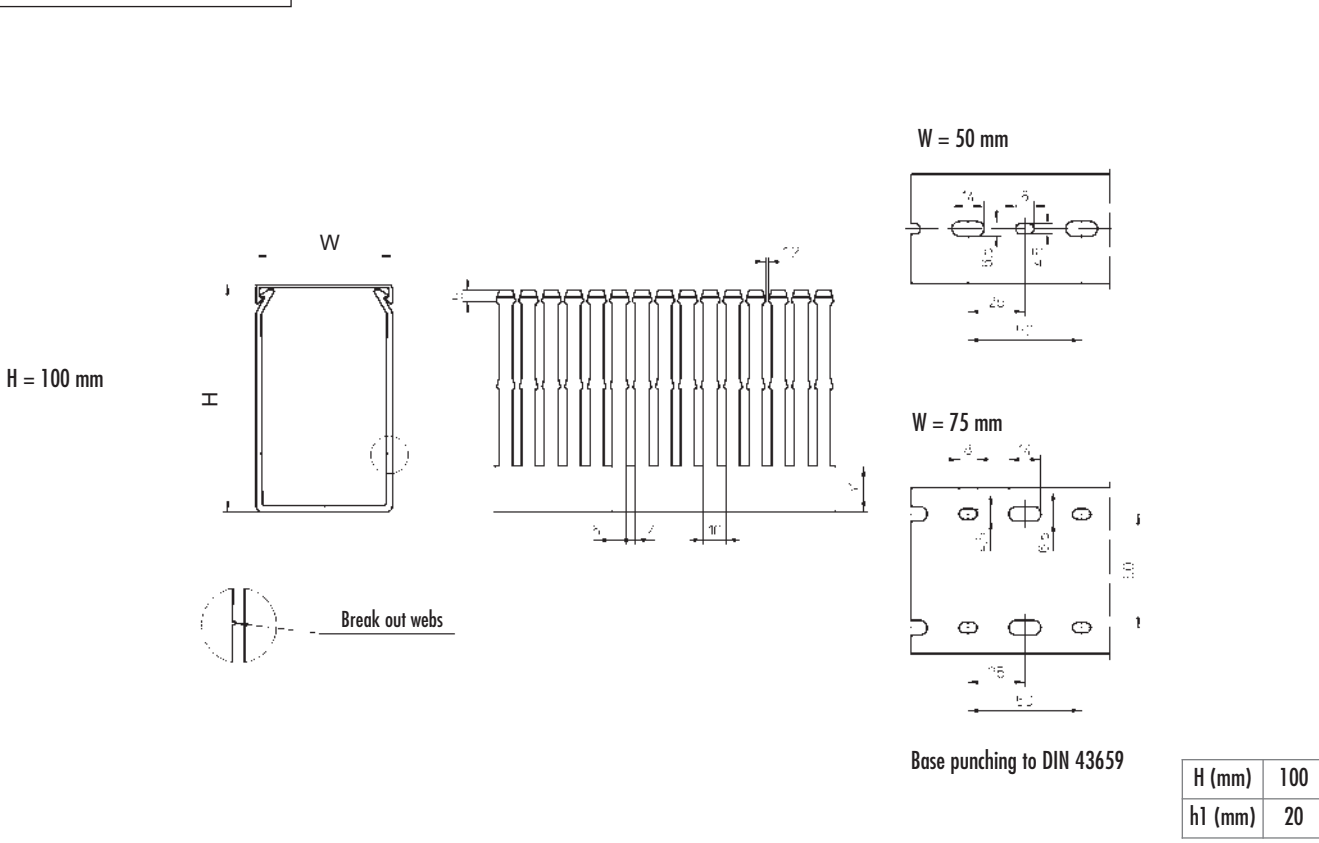

# Cable trunking SES® halogene free with slots and base punching



GF-DIN-SH-A7/5





## GF-DIN-SH-A7/5

|                                |                                        |
|--------------------------------|----------------------------------------|
| <b>Material:</b>               | polyphenylene ether, modified (PPE/PS) |
| <b>Colour:</b>                 | light grey RAL7035                     |
| <b>Operating temperatures:</b> | -25 to +70°C                           |
| <b>Volume resistivity:</b>     | 10 <sup>15</sup> Ω.cm                  |
| <b>Dielectric strength:</b>    | 16 kV/mm                               |
| <b>Specification:</b>          | V1 UL94                                |
| <b>Recommendations:</b>        | no contact with oils or greases        |
| <b>Standard length:</b>        | 2 meters                               |
| <b>Double sided adhesive:</b>  | upon request                           |
| <b>Minimum delivery:</b>       | 1 complete packing (with lids)         |





| type                      | trunking<br>art. no. | <br>m | outside dim. |         | cables per trunking<br>(filling 50 %) |                        |                        | lids<br>(alone)<br>art. no. | <br>m |
|---------------------------|----------------------|----------------------------------------------------------------------------------------|--------------|---------|---------------------------------------|------------------------|------------------------|-----------------------------|------------------------------------------------------------------------------------------|
|                           |                      |                                                                                        | H<br>mm      | W<br>mm | 1<br>mm <sup>2</sup>                  | 1,5<br>mm <sup>2</sup> | 2,5<br>mm <sup>2</sup> |                             |                                                                                          |
| GF-DIN-SH-A7/5 25 x 25    | 0848 0031 013        | 48                                                                                     | 23           | 23      | 25                                    | 21                     | 17                     | 0848 0640 013               | 12                                                                                       |
| GF-DIN-SH-A7/5 37,5x 25   | 0848 0041 013        | 48                                                                                     | 35,5         | 23      | 44                                    | 36                     | 30                     | 0848 0640 013               | 12                                                                                       |
| GF-DIN-SH-A7/5 37,5x 37,5 | 0848 0051 013        | 24                                                                                     | 35,5         | 35,5    | 74                                    | 61                     | 51                     | 0848 0645 013               | 12                                                                                       |
| GF-DIN-SH-A7/5 50 x 25    | 0848 0131 013        | 48                                                                                     | 48           | 23      | 62                                    | 51                     | 42                     | 0848 0640 013               | 12                                                                                       |
| GF-DIN-SH-A7/5 50 x 37,5  | 0848 0141 013        | 24                                                                                     | 48           | 35,5    | 104                                   | 85                     | 71                     | 0848 0645 013               | 12                                                                                       |
| GF-DIN-SH-A7/5 50 x 50    | 0848 0151 013        | 24                                                                                     | 48           | 48      | 146                                   | 120                    | 100                    | 0848 0650 013               | 12                                                                                       |
| GF-DIN-SH-A7/5 50 x 75    | 0848 0152 013        | 24                                                                                     | 48           | 73      | 230                                   | 189                    | 158                    | 0848 0655 013               | 12                                                                                       |
| GF-DIN-SH-A7/5 50 x 100   | 0848 0153 013        | 12                                                                                     | 48           | 98      | 315                                   | 259                    | 216                    | 0848 0660 013               | 12                                                                                       |
| GF-DIN-SH-A7/5 75 x 25    | 0848 0211 013        | 48                                                                                     | 73           | 23      | 101                                   | 83                     | 69                     | 0848 0640 013               | 12                                                                                       |
| GF-DIN-SH-A7/5 75 x 37,5  | 0848 0221 013        | 24                                                                                     | 73           | 35,5    | 161                                   | 132                    | 111                    | 0848 0645 013               | 12                                                                                       |
| GF-DIN-SH-A7/5 75 x 50    | 0848 0231 013        | 24                                                                                     | 73           | 48      | 227                                   | 186                    | 156                    | 0848 0650 013               | 12                                                                                       |
| GF-DIN-SH-A7/5 75 x 75    | 0848 0241 013        | 24                                                                                     | 73           | 73      | 358                                   | 294                    | 246                    | 0848 0655 013               | 12                                                                                       |
| GF-DIN-SH-A7/5 75 x 100   | 0848 0251 013        | 12                                                                                     | 73           | 98      | 489                                   | 402                    | 336                    | 0848 0660 013               | 12                                                                                       |
| GF-DIN-SH-A7/5 75 x 125   | 0848 0261 013        | 12                                                                                     | 73           | 123     | 620                                   | 509                    | 426                    | 0848 0665 013               | 12                                                                                       |


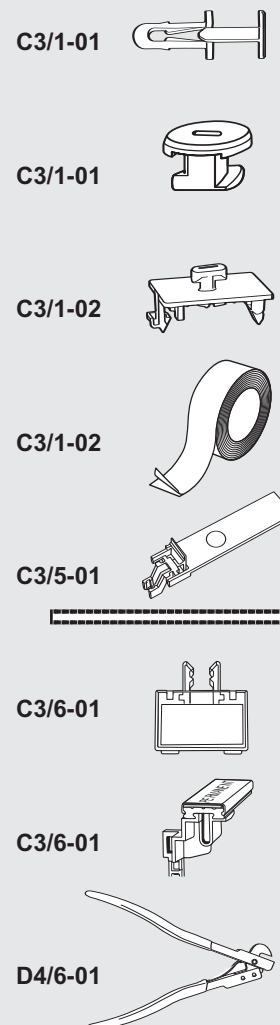
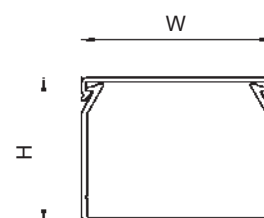






GF-DIN-SH-A7/5

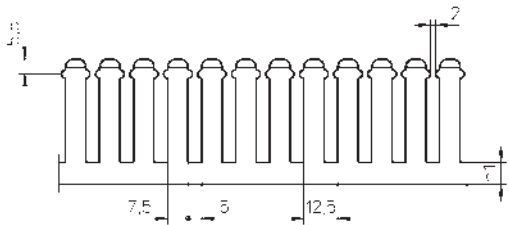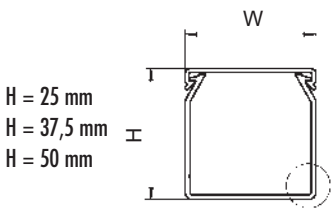

W = 25, 37,5 and 50 mm

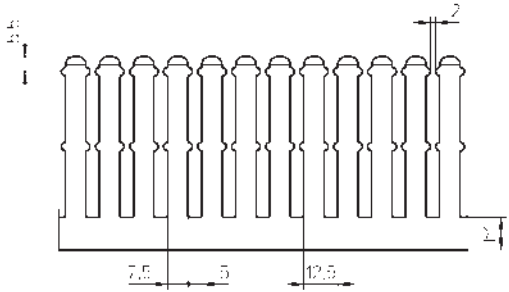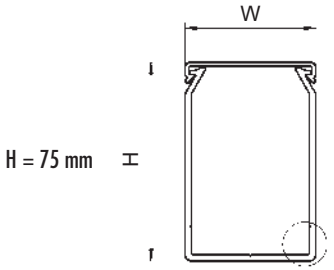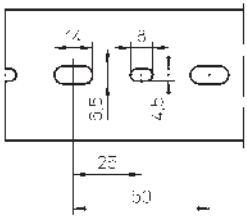

W = 75, 100 and 125 mm

 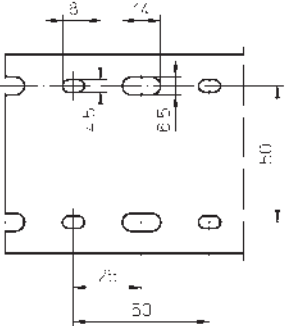

Base punching to DIN 43659

|         |    |      |    |    |
|---------|----|------|----|----|
| H (mm)  | 25 | 37,5 | 50 | 75 |
| h1 (mm) | 6  | 8    | 8  | 12 |



# Cable trunking SES® with slots and base punching




GF-DIN-C-A12/8



## GF-DIN-C-A12/8


|                                |                                |
|--------------------------------|--------------------------------|
| <b>Material:</b>               | Rigid PVC quality 9051 LF      |
| <b>Colour:</b>                 | grey RAL7030 - black           |
| <b>Operating temperatures:</b> | -5 to +65°C                    |
| <b>Volume resistivity:</b>     | 10 <sup>15</sup> Ω.cm          |
| <b>Dielectric strength:</b>    | 15 kV/mm                       |
| <b>Specifications:</b>         | V0 UL94                        |
| <b>Standard length:</b>        | 2 meters                       |
| <b>Double sided adhesive:</b>  | upon request                   |
| <b>Minimum delivery:</b>       | 1 complete packing (with lids) |

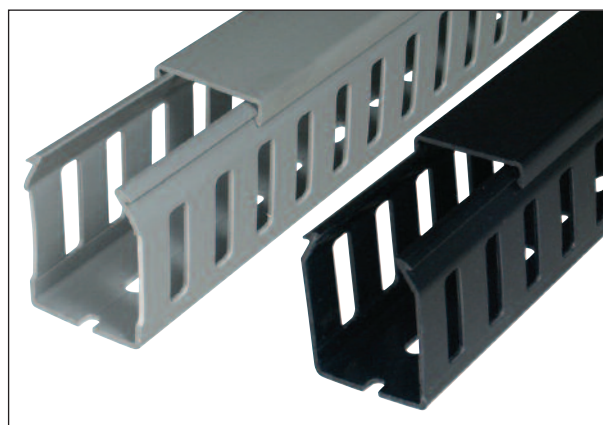


Example for order:

Colours: grey 013 black 010


| code group | detail article | code colour |
|------------|----------------|-------------|
| 0845       | xxxxxx         | xxxxxx      |

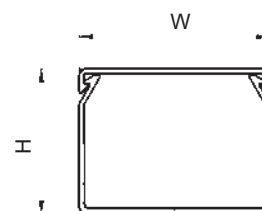

| type           | trunking<br>art. no. | <br>m | outside dim. |         | cables per trunking<br>(filling 50 %) |            |            | lids<br>(alone) |               | <br>m |
|----------------|----------------------|------------------------------------------------------------------------------------------|--------------|---------|---------------------------------------|------------|------------|-----------------|---------------|--------------------------------------------------------------------------------------------|
|                |                      |                                                                                          | H<br>mm      | W<br>mm | 1<br>mm²                              | 1,5<br>mm² | 2,5<br>mm² | art. no.        |               |                                                                                            |
| GF-DIN-C-A12/8 | 37,5x 25             | 0845 0046 ***                                                                            | 48           | 35,5    | 23                                    | 44         | 36         | 30              | 0845 0640 *** | 48                                                                                         |
| GF-DIN-C-A12/8 | 37,5x 37,5           | 0845 0056 ***                                                                            | 24           | 35,5    | 35,5                                  | 74         | 61         | 51              | 0845 0645 *** | 24                                                                                         |
| GF-DIN-C-A12/8 | 37,5x 50             | 0845 0066 ***                                                                            | 24           | 35,5    | 48                                    | 105        | 86         | 72              | 0845 0650 *** | 24                                                                                         |
| GF-DIN-C-A12/8 | 50 x 25              | 0845 0136 ***                                                                            | 48           | 48      | 23                                    | 62         | 51         | 42              | 0845 0640 *** | 48                                                                                         |
| GF-DIN-C-A12/8 | 50 x 37,5            | 0845 0146 ***                                                                            | 24           | 48      | 35,5                                  | 104        | 85         | 71              | 0845 0645 *** | 24                                                                                         |
| GF-DIN-C-A12/8 | 50 x 50              | 0845 0166 ***                                                                            | 24           | 48      | 48                                    | 146        | 120        | 100             | 0845 0650 *** | 24                                                                                         |
| GF-DIN-C-A12/8 | 50 x 75              | 0845 0167 ***                                                                            | 24           | 48      | 73                                    | 230        | 189        | 158             | 0845 0655 *** | 24                                                                                         |
| GF-DIN-C-A12/8 | 50 x100              | 0845 0168 ***                                                                            | 12           | 48      | 98                                    | 315        | 259        | 216             | 0845 0630 *** | 12                                                                                         |
| GF-DIN-C-A12/8 | 50 x125              | 0845 0169 ***                                                                            | 12           | 48      | 123                                   | 399        | 328        | 274             | 0845 0665 *** | 12                                                                                         |
| GF-DIN-C-A12/8 | 75 x 25              | 0845 0216 ***                                                                            | 48           | 73      | 25                                    | 101        | 83         | 69              | 0845 0640 *** | 48                                                                                         |
| GF-DIN-C-A12/8 | 75 x 37,5            | 0845 0226 ***                                                                            | 24           | 73      | 35,5                                  | 161        | 132        | 111             | 0845 0645 *** | 24                                                                                         |
| GF-DIN-C-A12/8 | 75 x 50              | 0845 0236 ***                                                                            | 24           | 73      | 48                                    | 227        | 186        | 156             | 0845 0650 *** | 24                                                                                         |
| GF-DIN-C-A12/8 | 75 x 75              | 0845 0246 ***                                                                            | 24           | 73      | 73                                    | 358        | 294        | 246             | 0845 0655 *** | 24                                                                                         |
| GF-DIN-C-A12/8 | 75 x100              | 0845 0256 ***                                                                            | 12           | 73      | 98                                    | 489        | 402        | 336             | 0845 0630 *** | 12                                                                                         |
| GF-DIN-C-A12/8 | 75 x125              | 0845 0266 ***                                                                            | 12           | 73      | 123                                   | 620        | 509        | 426             | 0845 0665 *** | 12                                                                                         |

 C3/1-01 

 
C3/1-01 

C3/1-02 

C3/1-02 

C3/5-01 

C3/6-01 

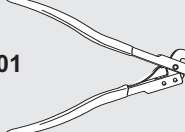D4/6-01 

|         |      |    |    |
|---------|------|----|----|
| H (mm)  | 37,5 | 50 | 75 |
| h1 (mm) | 8    | 8  | 12 |