

European Region

# 638532

## EUROPEAN REGION

### BRIGHT



- White LED provides 55 lumens of light on low setting and 150 on high.
- Tight white spot

### TOUGH



- Survives a 3-meter drop
- Rugged shatterproof lens

### RELIABLE



- Keeps cost of ownership low with impressive 58-hour run time on low setting, 19-hour on high
- LED never needs replacing

### WEATHERPROOF



- Meets IEC 60529 IPX4 standards for water resistance
- Ideal for outdoor applications

The Toughest Flashlight You'll Ever Need™ - ideally suited for mid-sized jobs in smaller areas, the Energizer® Hard Case Pro 4AA 1LED is easy to hold and pack up. Its bright white spot puts light where you need it most and the shatterproof lens shelters the LED. Made from impact resistant ABS plastic with steel sides and a shock absorbing rubber overmold, the light survives a 3-meter drop. It is water resistant, making it ideal for many outdoor applications. Finally, an impressive 58-hour run time keeps cost of ownership low.




**Before Using Your Flashlight:**  
Please read all instructions and cautionary markings on the package and light

### Product Detail:

- Designation:** Energizer Hard Case Professional 4AA 1 LED
- SAP:** 638532
- Colour:** Black and Dark Grey
- Power Source:** Four "AA"
- IEC:** LR6
- Lamp:** One Nichia® LED
- Lamp Life (hr):** Lifetime
- Lamp Output (lumens):** High- 150, Low- 55
- Beam Distance (m):** 265
- Peak Beam Intensity (cd):** 17,500
- Run Time (h:mm):** High- 19, Low- 58
- Durability:** Survives a 3-meter drop
- Typical Weight:** 333 grams without batteries
- Dimensions (mm):** 225 x 76

### Performance:

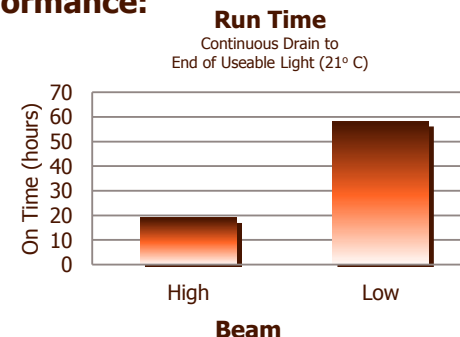

Tested according to ANSI/NEMA FL 1 Standards.

### Important Notice

This datasheet contains information specific to products manufactured at the time of its publication  
**Contents herein do not constitute a claim or warranty**  
©Energizer / All Rights Reserved