


CABLE SPECIFICATION

Model: CB08668 & CB08669
Type: Audio Cable
Specification: (129/0.15MMX2)X1C
Marketing: Propower Audio Cables

Appearance:

Shape	Color	Length	Package
Circle	Black	100M	Paper Spool

Constructure:

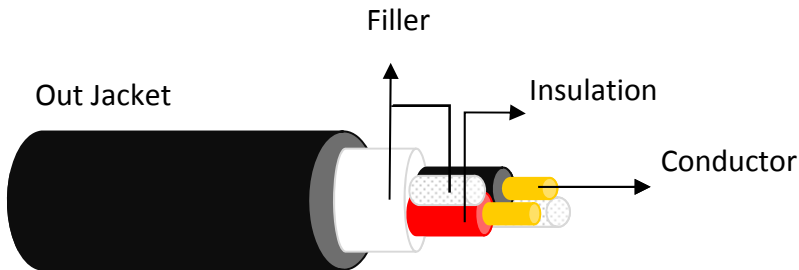

Conductor

Material: Bare Copper (OFC)
Construction: 129 X 0.15 MM
Cross Section: 2.3 MM² X 2

Insulation

Material: Polyvinylchloride (PVC)
Thickness: 0.40 MM
Diameter: 3.0 MM X 2C
Color: 1)Black;2)Red

Filler

Material: Cotton+Paper

Out Jacket

Material: Polyvinylchloride (PVC)
Thickness: 0.65 MM
Diameter: 7.30 MM

Operation Temp.: -20°C ~ 70°C

Approval By:

