


technical hotline +44 (0)1268 563720

conduit and mini | cable management

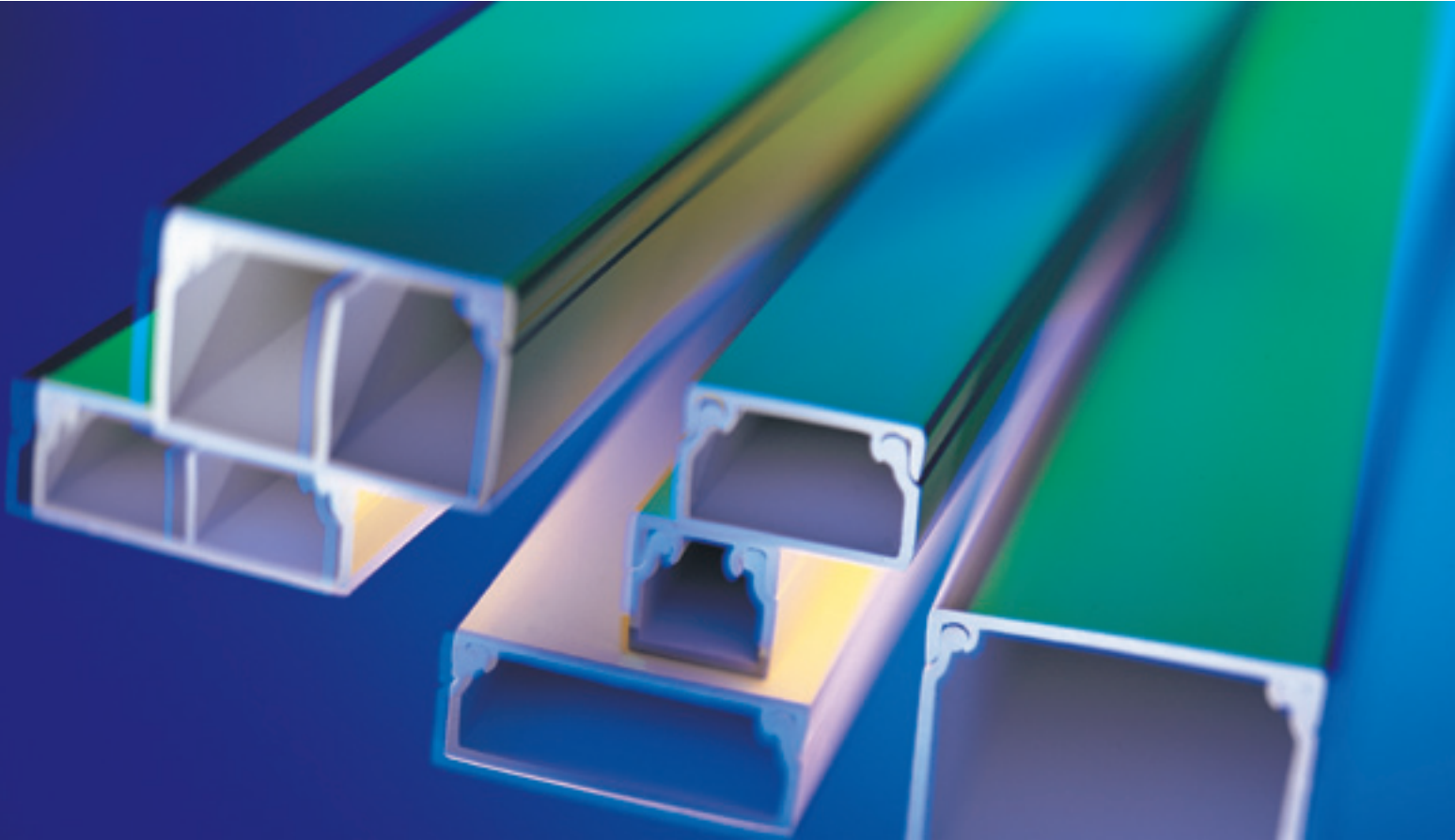

range introduction

Ega Mini Trunking consists of a range of sizes of extruded PVCu sections for the containment of electrical and data cabling for surface wiring.

The products are ideally suited for refurbishment programmes as well as new installation projects, both in the domestic and commercial sectors.

Speedfix Mini Trunking is complete with an acrylic foam adhesive for fast location of power circuits and secure containment of low voltage wiring.

features and benefits

- **Wide range of trunking profiles**
- **Wide range of integrated components maximises versatility of application**
- **Easy to assemble and install**
- **Durable and impact resistant**
- **Speedfix options allow fast installation**
- **All extrusions manufactured from 90% recycled material***

* Based on 2008 consumption.

Mini Trunking

3 METRE
LENGTHS

2 METRE
LENGTHS
(FOR NON UK
MARKETS)

Manufactured in accordance with BS EN 50085 Part 1.
STANDARD LENGTH: 3 metres
Available in 2 metre lengths for NON UK Markets.
MATERIAL: PVC-U



16 x 16mm	YT1WHI	90m			YT1D1WHI	60m
25 x 16mm	YT2WHI	90m	YT2CHA	30m	YT2D1WHI	60m
32 x 12.5mm	YT200WHI	30m			YT200D1WHI	32m
40 x 16mm	YT3WHI	45m			YT3D1WHI	32m
40 x 25mm	YT4WHI	45m	YT4CHA	30m	YT4D1WHI	32m
40 x 40mm	YT5WHI	45m			YT5D1WHI	32m
50 x 25mm	YT6WHI	30m			YT6D1WHI	32m
50 x 32mm	YT7WHI	30m			YT7D1WHI	32m
50 x 50mm	YT8WHI	12m				

Speedfix Mini Trunking

3 METRE
LENGTHS

2 METRE
LENGTHS

Twin Compartment Trunking

3 METRE
LENGTHS

Manufactured in accordance with BS EN 50085 Part 1.
STANDARD LENGTH: 3 metres
Available in 2 metre lengths for NON UK Markets.
MATERIAL: PVC-U

Self Adhesive Tape should not be relied upon for permanent fixing of the Speedfix range. A permanent means (such as screws) should also be used.



16 x 16mm	SPF1WHI	60m	SPF1D1WHI	60m		
25 x 16mm	SPF2WHI	30m	SPF2D1WHI	60m		
32 x 12.5mm						
40 x 16mm	SPF3WHI	30m	SPF3D1WHI	32m	ZT3WHI	30m
40 x 25mm	SPF4WHI	30m			ZT4WHI	30m
40 x 40mm						
50 x 25mm						
50 x 32mm						
50 x 50mm						

technical hotline +44 (0)1268 563720

conduit and mini | cable management

Coupling

End Cap

Internal
Corner

Internal
Data
Corner

External
Corner

External
Data
Corner

MOULDED



MOULDED

MOULDED

MOULDED

MOULDED

MOULDED

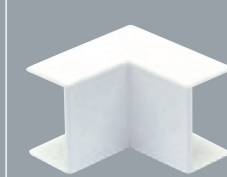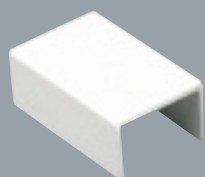

YC1WHI	20	YEP1WHI	20	YAI1WHI	20			YAE1WHI	20		
YC2WHI or CHA	20	YEP2WHI or CHA	20	YAI2WHI or CHA	20			YAE2WHI or CHA	20		
YC200WHI	20	YEP200WHI	20	YAI200WHI	20			YAE200WHI	20		
YC3WHI	10	YEP3WHI	20	YAI3WHI	5	YDAI3WHI	10	YAE3WHI	5	YDAE3WHI	5
YC4WHI	10	YEP4WHI or CHA	20	YAI4WHI or CHA	5			YAE4WHI or CHA	5		
YC5WHI	10	YEP5WHI	20	YAI5WHI	5			YAE5WHI	5		
		YEP6WHI	10	YAI6WHI	5			YAE6WHI	5		
		YEP7WHI	10	YAI7WHI (fabricated)	5			YAE7WHI (fabricated)	5		
YC8WHI	10	YEP8WHI	10	YAI8WHI	5			YAE8WHI	5		

Flat Angle

Flat Data
Angle

Flat Tee

Flat Data
Tee

2 METRE
LENGTHS





MOULDED

MOULDED

MOULDED

MOULDED

MOULDED

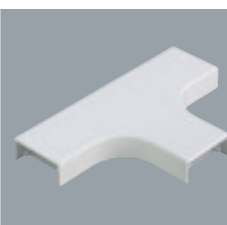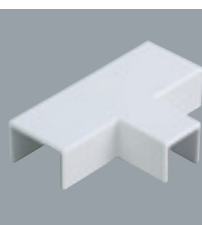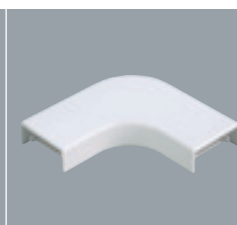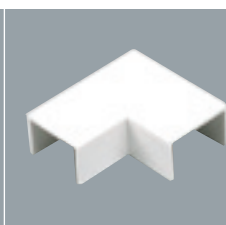

		YAF1WHI	20			YTF1WHI	20			
		YAF2WHI or CHA	20			YTF22WHI or CHA	20	YTF21WHI	20	
		YAF200WHI	20			YTF200WHI	20			
		YAF3WHI	5	YDAF3WHI	10	YTF3WHI	5		YDTF3WHI	10
ZT4D1WHI	32m	YAF4WHI or CHA	5			YTF4WHI or CHA	5	YTF42WHI or CHA	5	
		YAF5WHI	5			YTF5WHI	5			
		YAF6WHI	5			YTF6WHI	5			
		YAF7WHI (fabricated)	5			YTF7WHI (fabricated)	1			
		YAF8WHI	5			YTF8WHI	1			


Flat Tee vertical aperture sizes: YTF21WHI 16 x 16mm YTF42WHI 25 x 16mm

Side Tee


MOULDED




MOULDED

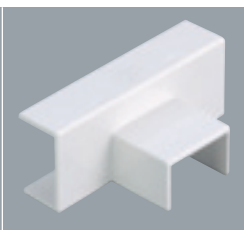Intersection
3 Way
Left Hand

MOULDED

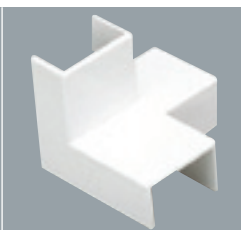Intersection
3 Way
Right Hand

MOULDED

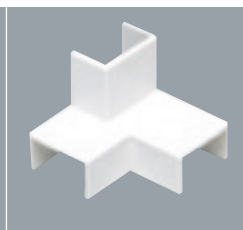

Adaptors


FOR USE WITH
MINI TRUNKING
BOXES
MOULDED

16 x 16mm									YEA1WHI	25
25 x 16mm	YST21WHI	10	YST22WHI	10	YAL2WHI	10	YAR2WHI	10	YEA2WHI or CHA	25
32 x 12.5mm					YAL200WHI	10	YAR200WHI	10	YEA200WHI	25
40 x 16mm									YEA3WHI	25

Side Tees (perpendicular)
Aperture Sizes
YST21WHI: 16 x 16mm
YST22WHI: 25 x 16mm

Adaptors

MOULDED

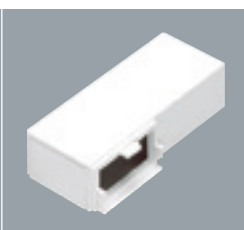Adaptors
Side MountingFOR USE WITH
MINI TRUNKING
BOXES
MOULDEDAdaptors
YT/1 Square to
20mm Round

MOULDED

Circular
Boxes

MOULDED



MOULDED



16 x 16mm	UEA1WHI	25	YSA1WHI	10	YTO12WHI	10	YCR1ELWHI	10		
25 x 16mm	UEA2WHI	25	YSA2WHI	10			YCR1ELWHI	10		
32 x 12.5mm			YSA200WHI	10			YCR2001EL	10	YCR2002EL	10
40 x 16mm	UEA3WHI	25	YSA3WHI	5			YCR1ELWHI	10		

UEA Adaptors
are for fixing with adhesive.
They are particularly useful
when spurring off from a
larger trunking section.

YSA Adaptors
are for use with Ega Mini
Trunking Boxes (page 379)
and incorporate removable
end caps for right and left
hand mounting.

Circular Boxes accept standard ceiling roses,
pull switches and plug-in lighting fittings.
The base incorporates an earth terminal facility
(order terminal separately, see page 370).

LID FIXING CENTRES: 50.8mm
PILLAR THREAD SIZE: M4 (Metal inserts)
LOAD SUSPENSION: 5kg @ 60°C max.

YCR2001EL is a One Way box
YCR2002EL is a Through box

technical hotline +44 (0)1268 563720

conduit and mini | cable management

Round Corner Accessory Boxes

Square Corner Accessory Boxes

Egaline Wall Box Assemblies



SURFACE

SURFACE

SURFACE

SIDE MOUNTING SURFACE

FOR AMERICAN ACCESSORIES

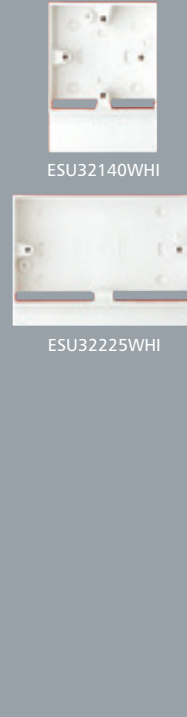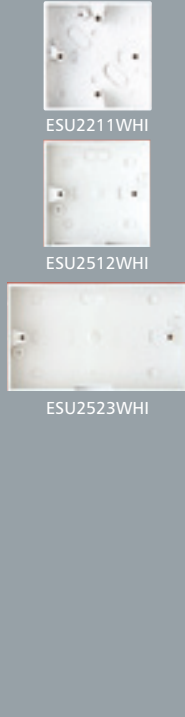

ESU231WHI 25
1 GANG 25MM
ONE ENTRY
CENTRE (TOP)

ESU2311WHI 25
1 GANG 25MM
ONE ENTRY (SIDE)

ESU2323WHI 10
2 GANG 25MM
THREE ENTRIES
(TOP & BOTH SIDES)

ESU3511WHI 25
1 GANG 32MM
ONE ENTRY
CENTRE (TOP)

ESU3523WHI 10
2 GANG 32MM
THREE ENTRIES.
(TOP, BOTTOM & SIDE)

ESU2211WHI 25
1 GANG 25MM
ONE ENTRY (SIDE)

ESU2512WHI 25
1 GANG 25MM
TWO ENTRIES
(TOP & BOTTOM)

ESU2223WHI 10
2 GANG 25MM
THREE ENTRIES
(TOP & BOTH SIDES)

ESU2523WHI 10
2 GANG 25MM
THREE ENTRIES
(TOP & BOTTOM)

ESU2713WHI 10
1 GANG 32MM
THREE ENTRIES
(TOP & BOTTOM)

ESU2721WHI 10
2 GANG 32MM
ONE ENTRY
CENTRE (TOP)

ESU4423WHI 5
2 GANG 41MM
THREE ENTRIES
(TOP & BOTH SIDES)

Ega Round and Square Corner boxes are for use in conjunction with mini trunking adaptors, reference: YEA- straight entry and YSA- side entry.

MATERIAL: PVC-U
DIMENSIONS:
1 gang: 86 x 86mm
2 gang: 86 x 146mm

FIXING CENTRES:
1 gang: 60.3mm
2 gang: 120.6mm
BS 4662 and BS 5733 where applicable.

ESU32125WHI 10
1 GANG TO FIT 25 x 16mm TRUNKING. TWO ENTRIES

ESU32140WHI 10
1 GANG TO FIT 40 x 16mm TRUNKING. TWO ENTRIES

ESU32225WHI 10
2 GANG TO FIT 25 x 16mm TRUNKING. TWO ENTRIES

ESU32240WHI 10
2 GANG TO FIT 40 x 16mm TRUNKING. TWO ENTRIES

Side mounting boxes do not require adaptors and can be used with 25mm x 16mm and 40 x 16mm mini trunking.

MATERIAL: PVC-U
DIMENSIONS:
1 gang: 86* x 86mm
2 gang: 86* x 146mm
* excluding plinth

FIXING CENTRES:
1 gang: 60.3mm
2 gang: 120.6mm

BS 4662 and BS 5733 where applicable.

ESUUSB17WHI 5
1 GANG
38MM DEPTH
FOUR ENTRIES (NON UK)

ESUUSB19WHI 5
1 GANG
45MM DEPTH
FOUR ENTRIES (NON UK)

ESUUSB22WHI 5
1 GANG
51MM DEPTH
FOUR ENTRIES (NON UK)

ESUUSB53WHI 5
2 GANG
DEEP BOX
FOUR ENTRIES (NON UK)

Egaline Wall Box assemblies are for use in conjunction with Mini Trunking Spout adaptors reference: YEA-straight entry and YSA-side entry.

MATERIAL: PVC-U
DIMENSIONS:
1 gang: 124 x 79mm