

PRODUCT SPECIFICATION

| | |
|-------------------------|--|
| Brand | C.K |
| Product Range | S2 Screwdriver bits sets |
| Catalogue number | 4501, 4502, 4508, 4509, 4517, 4518, 4520, 4521, 4522, 4523, 4524, 4525, 4527, 4528, 4566, 4569, 4583 |
| Date | 03/02/2015 |

Range Description

A range of professional quality screwdriver bits sets

Features

- Premium quality S2 alloy steel for exceptional strength & durability
- Precision machined tip for an exact fit & damage free screwdriving

Contents:

4502 – 31 set – Contents: PZ1 x1, PZ2 x4, PZ3 x1, PH1 x1, PH2 x2, TX10 x2, TX15 x4, TX20 x4, TX25 x2, TX30 x2, TX40 x1, Slotted 4,0 x1, 5,5 x1, 6,5 x1, Hex4 x1, Hex5 x1, Hex6 x1, Screwdriver bit holder x1

4501 – TX10 x1, TX15 x1, TX20 x1, TX25 x1, TX30 x1, TX40 x1, Screwdriver bit holder x1

T4517 - PZ1 x1, PZ2 x4, PZ3 x1



T4502



T4501




T4517

4520 – 4 bit sets Cat No. 4521, 4522, 4523 & 4524 plus 4570 bit driver



4520

4521 – Slotted 3, 4, 4.5, 5, 6, 7, 8 & 9mm

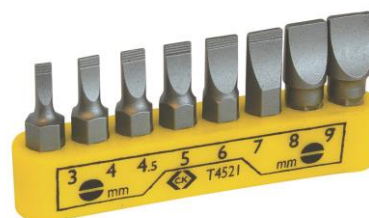


4521

4522 – PH 0, 1, 2, & 3 + PZD 0, 1, 2, & 3



4522

4523 – TX 8, 10, 15, 20, 25, 27, 30 & 40

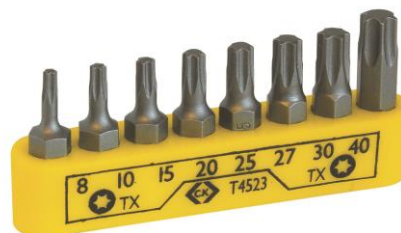

4523

4524 – Hex 1.5, 2, 2.5, 3, 4, 5, 5.5 & 6mm

4525 – Slotted 4, 5, & 7mm + PH 1, 2 & 3 + PZD1, 2 & 3 + TX 15 & 20



4524

4527 – TX Tamperproof 8, 10, 15, 20, 25, 27, 30 & 40



4525

4528 – Hex Tamperproof 2, 2.5, 3, 4, 5, 5.5, 6 & 7mm



4527

4509 – 41 piece set - Contents: PH1 x2, PH2 x4, PH3 x2, PZ1 x4, PZ2 x8, PZ3 x4, Slotted 4mm x2, 5.5mm x2, 6mm x2, 8mm x2, TX15 x1, TX20 x1, TX25 x1, TX30 x1, Hex3 x1, Hex4 x1, Hex5 x1, Hex 6 x1
Screwdriver bit holder x1



4528

4508 – 41 piece set

- ⊕ PH0 x1, PH1 x1, PH2 x3, PH3 x1
- ⊕ PZ0 x1, PZ1 x1, PZ2 x1, PZ3 x1
- ⊖ 4.0mm x1, 5.0mm x1, 6.0mm x1, 8.0mm x1
- ⊙ Size 4x1, Size 5x1, Size 6x1, Size 8x1
- ⊙ Size 4x1, Size 6x1, Size 8x1, Size 10x1
- ⊕ Size 6x1, Size 8x1, Size 10x1
- ⊙ TX8 x1, TX10 x1, TX15 x1, TX20 x1, TX25 x1, TX27 x1, TX30 x1, TX40 x1
- ⊙ Size 1x1, Size 2x1, Size 3x1, Size 4x1
- ⊙ Size 1x1, Size 2x1, Size 3x1
- ⊙ Screwdriver Bit Holder x1

4566 – (Discontinued) Slotted 4.5, 5.5, 6.5 + PH (three of each) 1, 2, & 3 + PZD (three of each) 1, 2 & 3 + TX 10, 15, 20, 25, 30 & 40 + Hex 3, 4 & 5 + bit driver 4570

4569 – TiN PZD 1, 2 (4 off) & 3 + 4570 bit driver

4583 - Slotted 5.5 & 6.5mm + PH 1 & 2 + PZD 1 & 2 + 4570 bit driver



T4509



T4508



4566



4569



4583

| Item Number | Item Description | EAN No | Commodity code | Carton Qty |
|-------------|---|---------------|----------------|------------|
| T4501 | Screwdriver Bit Set of 7 – TX | 5013969996807 | 82079030 | 12 |
| T4502 | Screwdriver Bit Set of 31 – Mixed | 5013969996814 | 82079030 | 6 |
| T4508 | Screwdriver Security Bit Set of 41 – Mixed | 5013969996616 | 82079030 | 6 |
| T4509 | Screwdriver Bit Set of 41 – Mixed | 5013969996623 | 82079030 | 6 |
| T4517 | Screwdriver Bit Set of 7 – PZ | 5013969996784 | 82079030 | 12 |
| T4518 | Screwdriver Bit Set of 7 – PH | 5013969996791 | 82079030 | 12 |
| T4520 | Screwdriver bit set (25mm) 33 Pce * | 5013969004984 | 82079030 | 6 |
| T4521 | Screwdriver Bit set in clip Slotted 8 Pce * | 5013969004977 | 82079030 | 6 |
| T4522 | Screwdriver Bit set in clip PH/PZD 8 Pce * | 5013969004960 | 82079030 | 6 |
| T4523 | Screwdriver Bit set in clip TX 8 Piece | 5013969004953 | 82079030 | 6 |
| T4524 | Screwdriver Bit set in clip Hex 8 Piece | 5013969004946 | 82079030 | 6 |
| T4525 | Screwdriver Bit set (100mm) 10 Pcs * | 5013969004939 | 82079030 | 6 |
| T4527 | Screwdriver Bit set in clip TX T/Proof | 5013969025675 | 82079030 | 6 |
| T4528 | Screwdriver Bit set in clip Hex T/Proof | 5013969025668 | 82079030 | 6 |
| T4566 | Screwdriver Bit Set 31pce * | 5013969978049 | 82079030 | 20 |
| T4569TINC | Screwdriver bit set PZD Bits TIN Carded * | 5013969035933 | 82079030 | 20 |
| T4583C | Screwdriver bit set Assorted Bits Carded * | 5013969171105 | 82079030 | 20 |

| | |
|------------------------------------|---|
| Technical product information | |
| Standards compliance | |
| User health and safety information | Users and bystanders are advised to wear safety goggles |
| RoHS/WEEE compliance | This product range does not fall within the scope of RoHS or WEEE regulations |
| Material safety data | None applicable |
| Warranty | C.K Drill bits are guaranteed for life against imperfect materials or workmanship Normal wear and tear or damage caused through inappropriate use is not covered |

| | |
|-------------------|--|
| Country of origin | 4566, 4569, 4583 – Germany All other – Taiwan |
|-------------------|--|

Dimensional details

| Item | Product only | | | | Product on primary packaging | | | |
|-----------|--------------|----------|-----------|--------------|------------------------------|----------|-----------|----------------|
| | Width mm | Depth mm | Height mm | Net weight g | Width mm | Depth mm | Height mm | Gross weight g |
| T4501 | 71 | 21 | 81 | 93 | - | - | - | - |
| T4502 | 100 | 28 | 130 | 291 | - | - | - | - |
| T4508 | 140 | 37 | 76 | 313 | 180 | 50 | 200 | 359 |
| T4509 | 140 | 37 | 76 | 313 | 180 | 50 | 200 | 359 |
| T4517 | 71 | 21 | 81 | 93 | - | - | - | - |
| T4518 | 71 | 21 | 81 | 93 | - | - | - | - |
| T4520 | - | - | - | - | 105 | 20 | 220 | 228 |
| T4521 | - | - | - | - | 90 | 20 | 110 | 56 |
| T4522 | - | - | - | - | 90 | 20 | 110 | 56 |
| T4523 | - | - | - | - | 90 | 20 | 110 | 56 |
| T4524 | - | - | - | - | 90 | 20 | 110 | 56 |
| T4525 | - | - | - | - | 110 | 15 | 170 | 274 |
| T4527 | - | - | - | - | 90 | 20 | 110 | 56 |
| T4528 | - | - | - | - | 90 | 20 | 110 | 56 |
| T4566 | - | - | - | - | 80 | 120 | 30 | 328 |
| T4569TINC | - | - | - | - | 82 | 18 | 113 | 90 |
| T4583C | - | - | - | - | 82 | 18 | 113 | 90 |

| Item | Shelf box (secondary packaging) | | | | Euro Pallet data Wi x Hi | |
|-------|---------------------------------|----------|-----------|----------------|-----------------------------|---------------------|
| | Width mm | Depth mm | Height mm | Gross weight g | No of cartons on base | Number of rows high |
| T4501 | 95 | 270 | 60 | 1186 | | |
| T4502 | 105 | 360 | 70 | 1855 | | |
| T4508 | 195 | 215 | 240 | 2270 | | |
| T4509 | 195 | 215 | 240 | 2270 | | |
| T4517 | 95 | 270 | 60 | 1186 | | |
| T4518 | 95 | 270 | 60 | 1186 | | |
| T4520 | 110 | 120 | 230 | 1425 | | |
| T4521 | 120 | 95 | 63 | 370 | | |

| | | | | | | |
|-----------|-----|-----|-----|------|--|--|
| T4522 | 120 | 95 | 63 | 370 | | |
| T4523 | 120 | 95 | 63 | 370 | | |
| T4524 | 120 | 95 | 63 | 370 | | |
| T4525 | 85 | 120 | 182 | 1705 | | |
| T4527 | 120 | 95 | 63 | 370 | | |
| T4528 | 120 | 95 | 63 | 370 | | |
| T45660 | 180 | 320 | 180 | 6770 | | |
| T4569TINC | 95 | 330 | 85 | 1890 | | |
| T4583C | 95 | 330 | 85 | 1890 | | |

Packaging waste details

| Item | Primary Packaging | | | | Secondary packaging | | | |
|-----------|-------------------|---------|--------|------|---------------------|-----|--------|--------|
| | Plastic g | Use | Card g | Use | Plastic g | Use | Card g | Use |
| T4501 | - | - | - | - | | | 70 | Carton |
| T4502 | - | - | - | - | | | 109 | Carton |
| T4508 | 44 | Blister | 2 | Card | | | 116 | Carton |
| T4509 | 44 | Blister | 2 | Card | | | 116 | Carton |
| T4517 | - | - | - | - | | | 70 | Carton |
| T4518 | - | - | - | - | | | 70 | Carton |
| T4520 | 20 | Blister | 12 | Card | | | 74 | Carton |
| T4521 | 4 | Blister | 6 | Card | | | 30 | Carton |
| T4522 | 4 | Blister | 6 | Card | | | 30 | Carton |
| T4523 | 4 | Blister | 6 | Card | | | 30 | Carton |
| T4524 | 4 | Blister | 6 | Card | | | 30 | Carton |
| T4525 | 8 | Blister | 10 | Card | | | 56 | Carton |
| T4527 | 4 | Blister | 6 | Card | | | 30 | Carton |
| T4528 | 4 | Blister | 6 | Card | | | 30 | Carton |
| T4566 | 40 | Bags | - | - | | | 170 | Carton |
| T4569TINC | 4 | Hanger | - | - | | | 98 | Carton |
| T4583C | 4 | Hanger | - | - | | | 98 | Carton |