


**AA**

# ALKALINE POWER

## Specifications


<b>Classification:</b>	Alkaline
<b>Chemical System:</b>	Zinc-Manganese Dioxide (Zn/MnO <sub>2</sub> ) No added mercury or cadmium
<b>Designation:</b>	ANSI-15A, IEC-LR6
<b>Nominal Voltage:</b>	1.5 volts
<b>Nominal IR:</b>	150 to 300 milliohms (fresh)
<b>Operating Temp:</b>	-18°C to 55°C (0°F to 130°F)
<b>Typical Weight:</b>	22.7 grams (0.8 oz.)
<b>Typical Volume:</b>	8.1 cubic centimeters (0.5 cubic inch)
<b>Jacket:</b>	Plastic Label
<b>Terminal:</b>	Flat Contact

## Industry Standard Dimensions

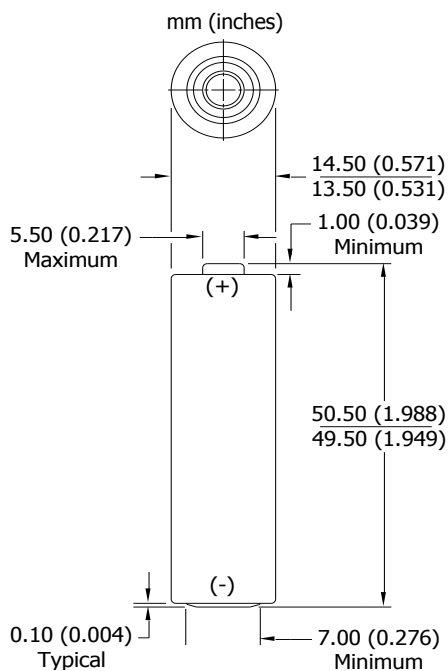


## Milliamp-Hours Capacity

Continuous discharge to 0.8 volts at 21°C

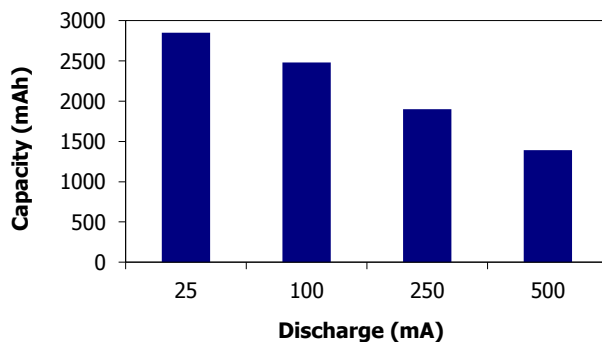

## Constant Current Performance





Typical Characteristics (21°C)

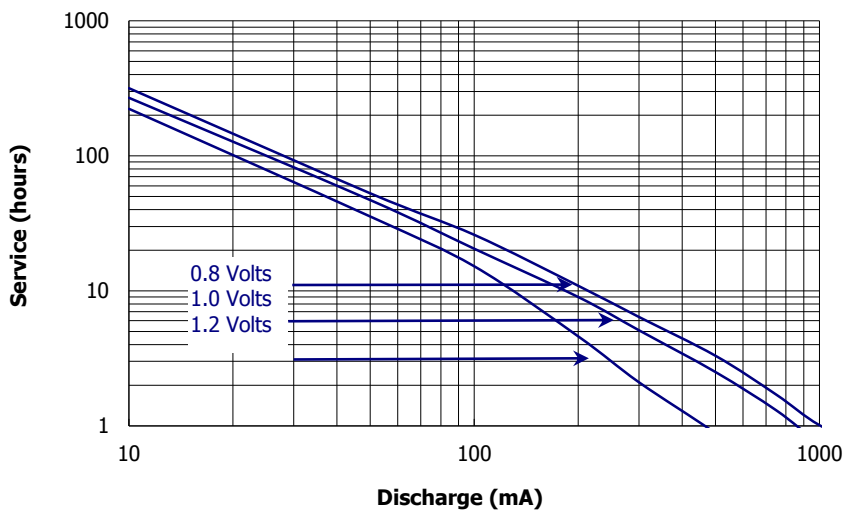

# ENERGIZER ALKALINE POWER

**AA**

## Industry Standard Tests (21°C)

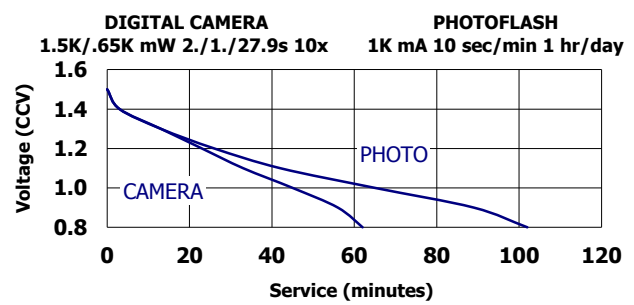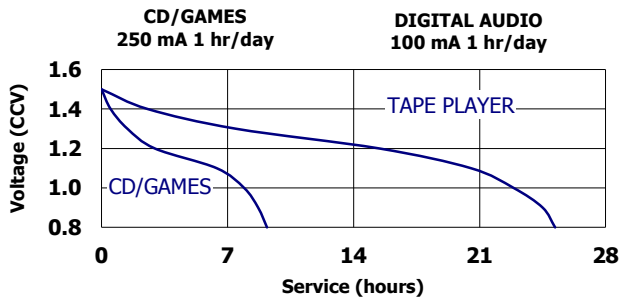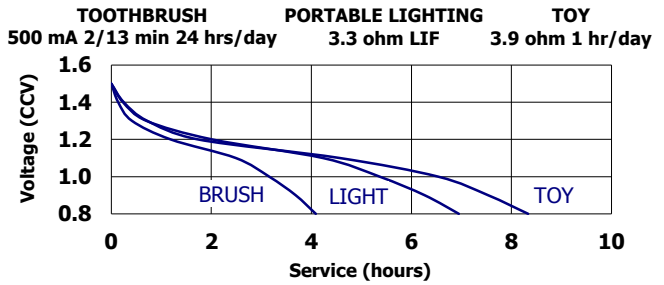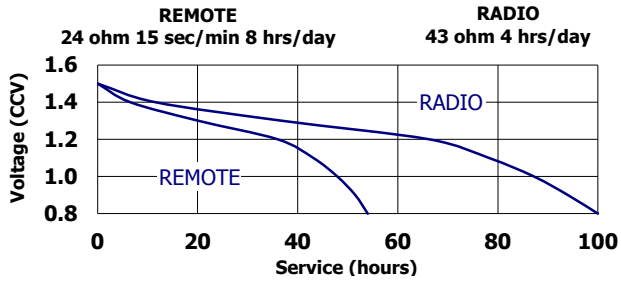

Pack Quantity : 24  
 Manufacturers Part Number : E300173100