

## SMD terminal block with push-buttons in tape-and-reel packing; 2-pole; Pin spacing 4 mm / 0.157 in

Item No.: 2060-402/998-404



SMD terminal block with push-buttons in tape-and-reel packing; 2-pole; Pin spacing 4 mm / 0.157 in

### Marking

RoHS ✓  
Compliant

### Business data

Supplier	WAGO
Item no.	2060-402/998-404
GTIN / EAN	4050821377863
Content	1
Order amount	1,000
Customer item number	

### Notes

SMD terminal blocks with Push-in CAGE CLAMP® and push-buttons Height of just 4.5 mm minimizes on-board LED shadowing Available in tape-and-reel packaging for automated assembly For new designs please only use the new white version of 2060 series! [CLICK HERE!](#)

### Technical data


#### Miscellaneous


No. of poles	2
Pin Spacing	4 mm (0.157 in %)
Total number of connection points	2
Total number of potentials	2
Color	white
Ratings according to 1	IEC/EN 60664-1
Overvoltage category EN 1	III

<b>Technical data</b>	
<i>Pollution degree (1)</i>	2
<i>Rated voltage EN (1) [V]</i>	160 [V]
<i>Rated surge voltage (1) [kV]</i>	2.5 [kV]
<i>Nominal current [A]</i>	9 [A]
<i>Overvoltage category EN 2</i>	II
<i>Degree of pollution (2)</i>	2
<i>Rated voltage EN (2) [V]</i>	320 [V]
<i>Rated surge voltage (2) [kV]</i>	2.5 [kV]
<i>Nominal current (2) [A]</i>	9 [A]
<i>Overvoltage category EN 3</i>	III
<i>Degree of pollution (3)</i>	3
<i>Rated voltage EN (3) [V]</i>	63 [V]
<i>Rated surge voltage (3) [kV]</i>	2.5 [kV]
<i>Nominal current (3) [A]</i>	9 [A]
<i>Number of individual connection objects at the product</i>	1
<i>Connection technology (1)</i>	Push-in CAGE CLAMP®
<i>Solid sizes 1</i>	0.2 ... 0.75 mm <sup>2</sup> / 24 ... 18 AWG
<i>Fine-stranded wires 1</i>	0.2 ... 0.75 mm <sup>2</sup> / 24 ... 18 AWG
<i>Fine-stranded wires with insulated ferrule 1</i>	0.25 ... 0.34 mm <sup>2</sup> / ...
<i>Fine-stranded wires with uninsulated ferrule 1</i>	0.25 ... 0.34 mm <sup>2</sup> / ...
<i>Strip length 1</i>	6 ... 7 mm / 0.24 ... 0.28 in
<i>Solder pad dimensions [mm]</i>	6 x 2 [mm]
<i>Spulendurchmesser der Gurtverpackung [mm]</i>	330 [mm]
<i>Gurtbreite [mm]</i>	24 [mm]
<i>Material group</i>	I
<i>Insulating material</i>	Polyphthalamid (PPA GF)
<i>Flammability rating per UL 94</i>	V0
<i>Limit temperature range</i>	-60 C ... 105 C
<i>Contact material</i>	Copper alloy
<i>Contact plating</i>	tin-plated
<i>Weight [g]</i>	0.88 [g]
<i>Width</i>	7.9 mm / 0.311 in
<i>Height</i>	4.5 mm / 0.177 in
<i>Length</i>	13.1 mm / 0.516 in

Images & drawings



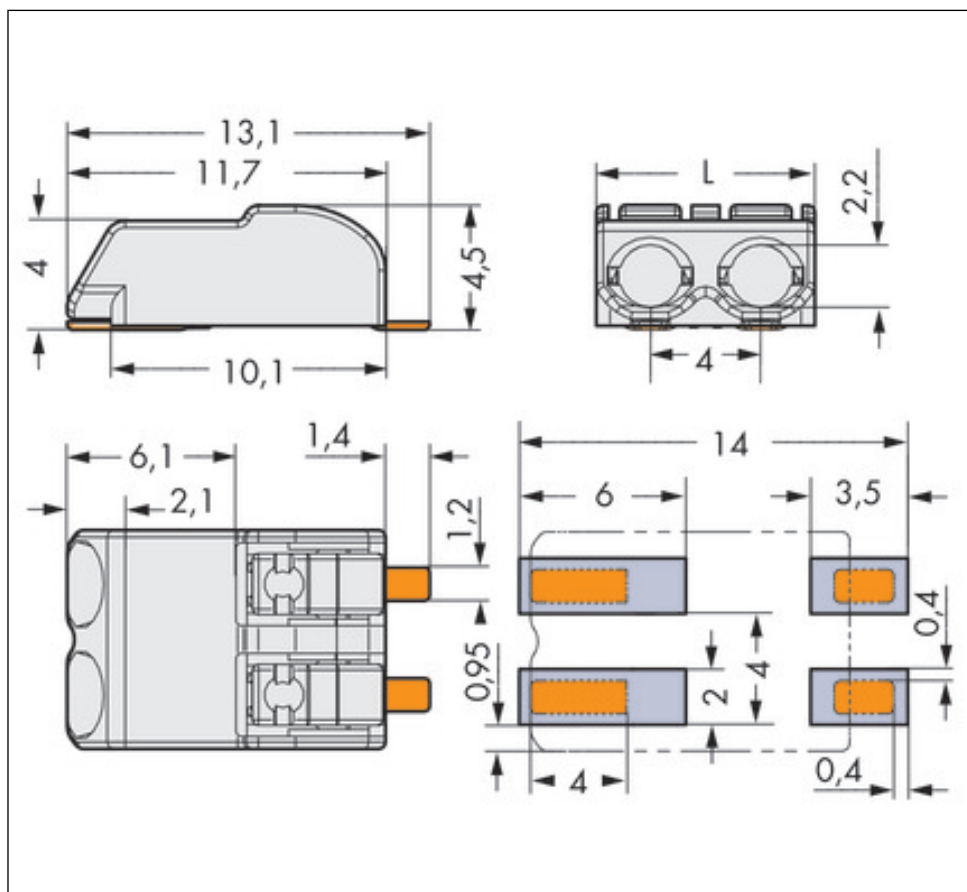

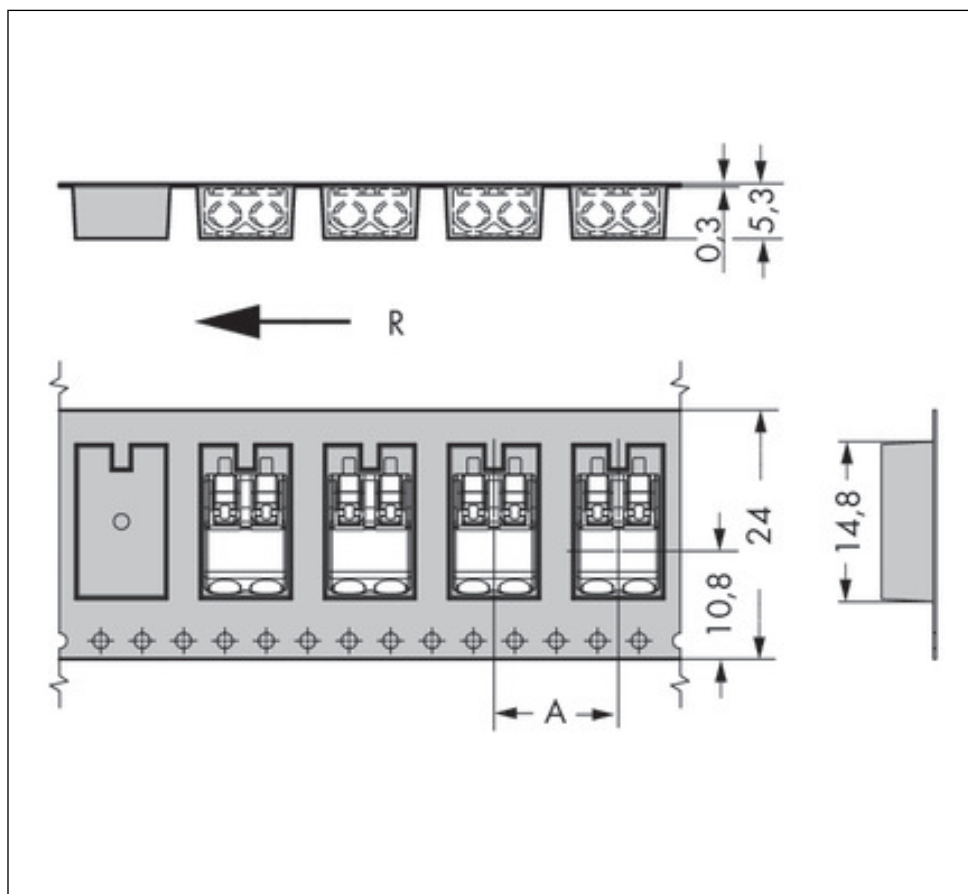

#### Address

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Telefon: 0571/887-0

Fax: 0571/887-169

<http://www.wago.com>

© WAGO Kontakttechnik GmbH & Co. KG

Technische Änderungen und Irrtümer vorbehalten.