

**Triple-deck terminal block; Ground conductor/through/through terminal block; PE/N/L; without marker carrier; gray housing; suitable for Ex e II applications**

Item No.: 2002-3217



*Triple-deck terminal block; Ground conductor/through/through terminal block; PE/N/L; without marker carrier; gray housing; suitable for Ex e II applications*

### Marking

RoHS ✓  
Compliant

### Business data

Supplier	WAGO
Item no.	2002-3217
GTIN / EAN	4044918691208
Content	1
Order amount	50
Customer item number	

### Notes



### Technical data


#### Miscellaneous

Total number of connection points	6
Total number of potentials	3
Potentialkennzeichnung	PE/N/L
Number of levels	3
Color	gray
Ratings according to 1	IEC/EN 60947-7-1
Pollution degree (1)	3
Rated voltage EN (1) [V]	500 [V]

<b>Technical data</b>	
<i>Rated surge voltage (1) [kV]</i>	<i>6 [kV]</i>
<i>Nominal current [A]</i>	<i>24 [A]</i>
<i>Nominal current (2) [A]</i>	<i>28 [A]</i>
<i>Rated voltage EN (Ex e II) [V]</i>	<i>440 [V]</i>
<i>Nominal current (Ex e II) [A]</i>	<i>19 [A]</i>
<i>Nominal current (Ex e II) with jumper [A]</i>	<i>17 [A]</i>
<i>Connection technology (1)</i>	<i>Push-in CAGE CLAMP®</i>
<i>Nominal cross section 1</i>	<i>2.5 mm<sup>2</sup></i>
<i>Solid sizes 1</i>	<i>0.25 ... 4 mm<sup>2</sup> / 22 ... 12 AWG</i>
<i>solid, directly pluggable 1</i>	<i>0.75 ... 4 mm<sup>2</sup> / 18 ... 12 AWG</i>
<i>Fine-stranded wires 1</i>	<i>0.25 ... 4 mm<sup>2</sup> / 22 ... 12 AWG</i>
<i>min. fine-stranded with insulated ferrule, push-in terminati</i>	<i>0.75 mm<sup>2</sup> / 18 AWG</i>
<i>Strip length 1</i>	<i>10 ... 12 mm / 0.39 ... 0.47 in</i>
<i>Type of wiring</i>	<i>Front-entry wiring</i>
<i>Design</i>	<i>horizontal</i>
<i>Marking level</i>	<i>Center/Side marking</i>
<i>Insulating material</i>	<i>Polyamide 66 (PA 66)</i>
<i>Fire load [MJ]</i>	<i>0.306 [MJ]</i>
<i>Weight [g]</i>	<i>19.673 [g]</i>
<i>Width</i>	<i>5.2 mm / 0.205 in</i>
<i>Height from upper-edge of DIN-rail [mm]</i>	<i>69.5 [mm]</i>
<i>Height from upper-edge of DIN-rail</i>	<i>69.5 mm / 2.736 in</i>
<i>Length</i>	<i>93.3 mm / 3.673 in</i>
<i>Type of mounting</i>	<i>DIN 35 rail</i>

Images & drawings

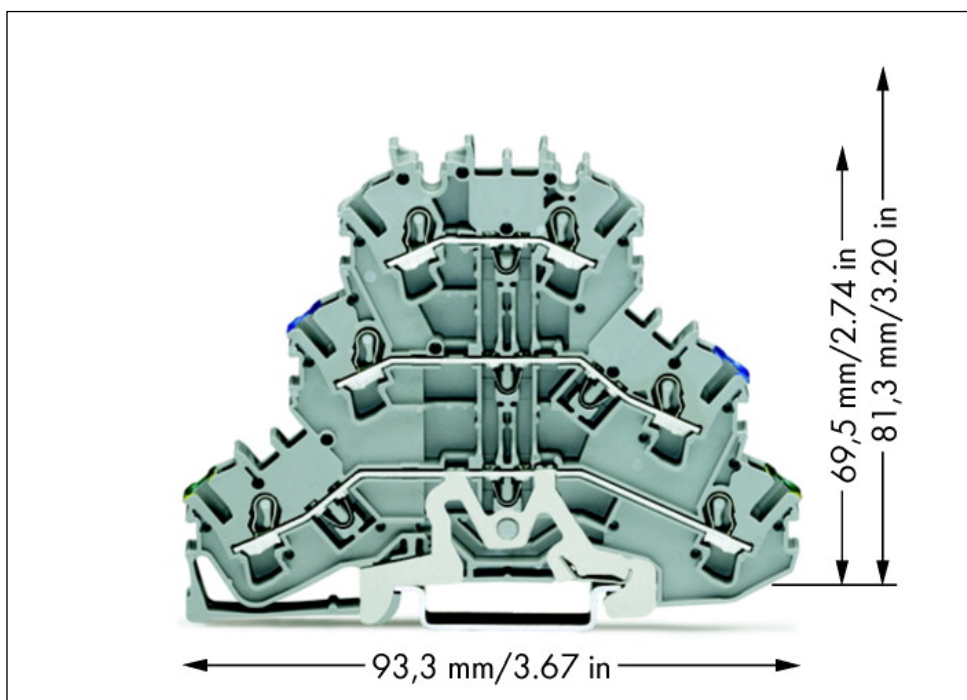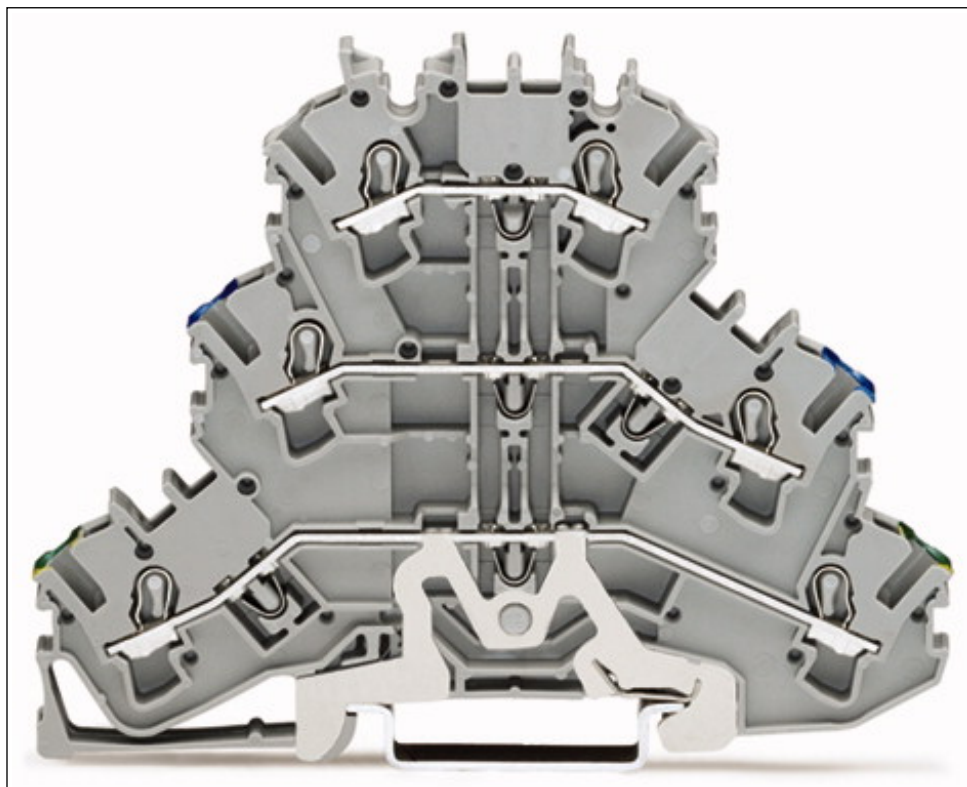

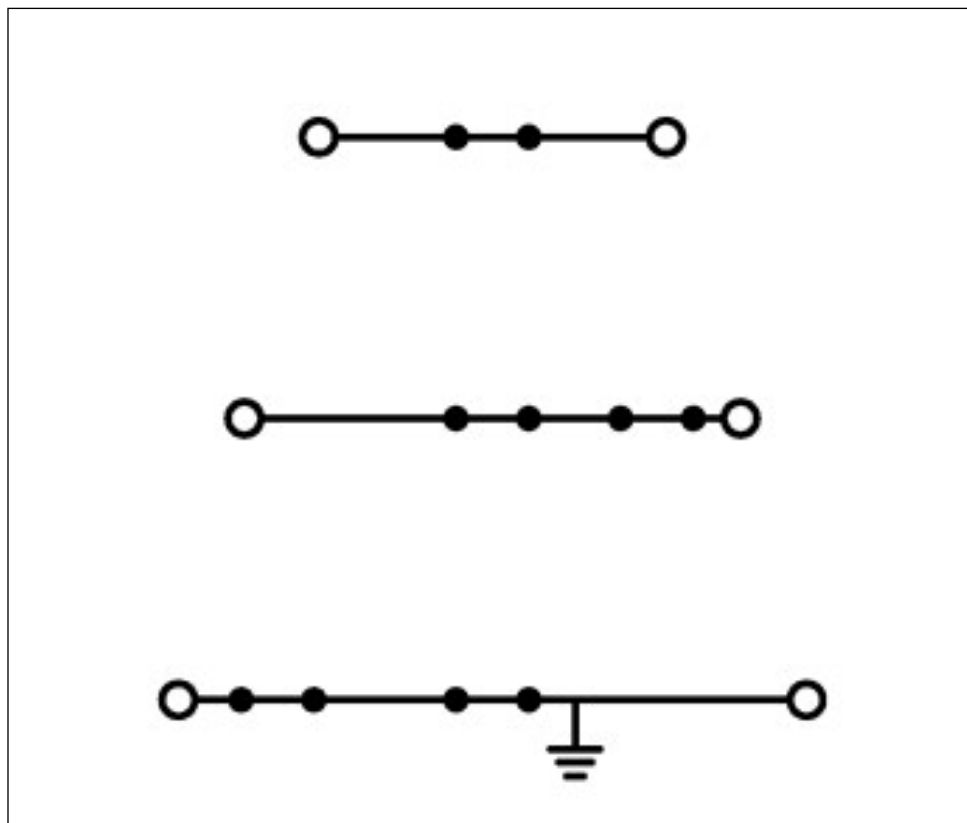

#### Address

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Telefon: 0571/887-0

Fax: 0571/887-169

<http://www.wago.com>

© WAGO Kontakttechnik GmbH & Co. KG

Technische Änderungen und Irrtümer vorbehalten.