

Available
September 2015



Han® standard metal hoods and housings for industrial applications


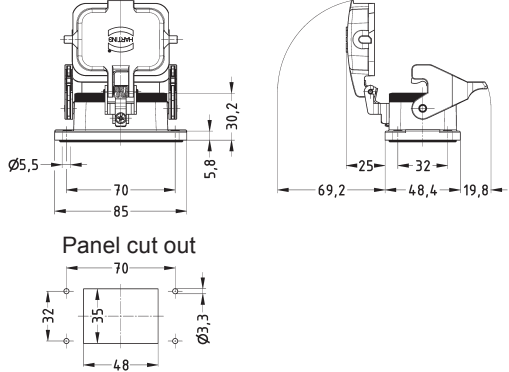

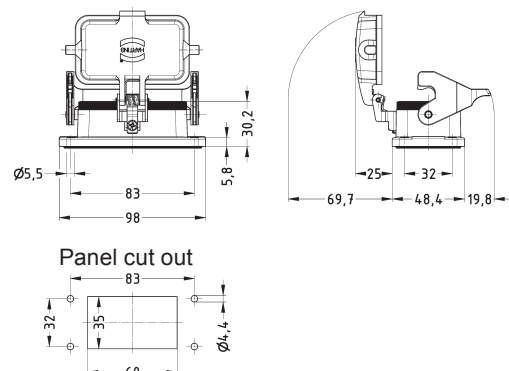

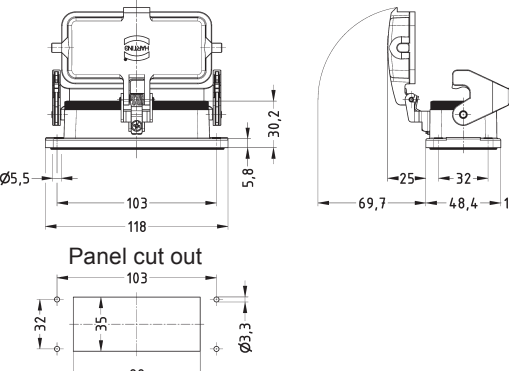

Features

- Compatible with all standard hoods and housings
- Proven locking system Han-Easy Lock®
- Automatic closing mechanism
- Protection degree IP66 und IP67
- Protective collar keeps the seal in place

Technical characteristics

Hoods / housings

Material	aluminium die cast
Colour	RAL 7037 (blue)
Surface	powder coated
Locking element	stainless steel
Lever type	Han-Easy Lock®
Seal	NBR
Limiting temperatures	-40 °C ... +125 °C
Protection degree acc. to DIN EN 60 529 in locked position	IP66 / IP67
Protection degree acc. to DIN EN 60 529 in unlocked position	IP44

Identification	Part number	Drawing	Dimensions in mm
<p>Housing, bulkhead mounting 6 B with self-closing cap</p> 	<p>09 30 006 1306</p>		
<p>Housing, bulkhead mounting 10 B with self-closing cap</p> 	<p>09 30 010 1306</p>		
<p>Housing, bulkhead mounting 16 B with self-closing cap</p> 	<p>09 30 016 1306</p>		
<p>Housing, bulkhead mounting 24 B with self-closing cap</p> 	<p>09 30 024 1306</p>	