



AT-4000 SERIES ATTENUATORS



Ergonomically designed with precision control


AT-4000 Series Attenuators

Designed with ergonomics of the human hand in mind, AT-4000 Series Attenuators' control knob comes in a size that provides comfortable grip and excellent control with every turn. Consisting of 8 steps attenuation, the series is built to provide precision volume control with a difference of 3dB in every step. The built-in overriding relay feature allows emergency paging which is indicated by the LED light when activated.

AT-4000 Series Attenuators come in 4 different ratings - 12 watts, 30 watts, 60 watts and 120 watts.

Features

- 8-step attenuation level control (+/- 3dB)
- Ergonomic control knob with better grip for easy turn
- 24VDC overriding relay with red LED indicator
- Terminal block for thicker diameter cable
- Clip-on face plate
- 2 / 3 / 4 wire system
- Surface or flush mount
- Glossy finish in white

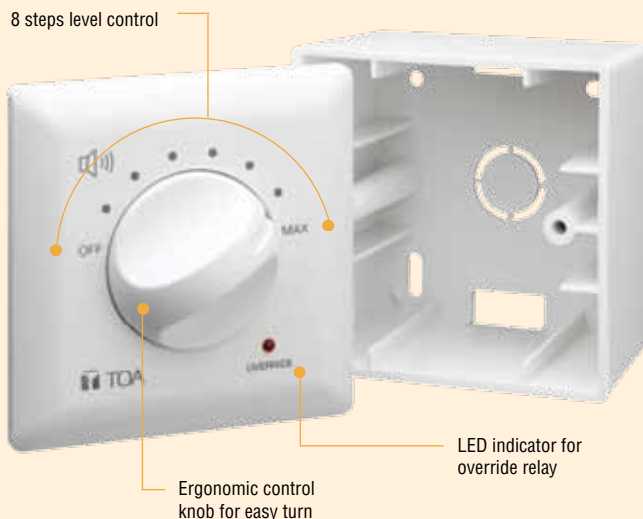

* AT-4012 AS does not come with back box

Specifications

Model	AT-4012 AS	AT-4030 AS	AT-4060 AS	AT-4120 AS
Input Capacity	12 Watt	30 Watt	60 Watt	120 Watt
Attenuation	8 Steps (0dB, -3dB, -9dB, -12dB, -15dB, -18dB, OFF)			
Override Indicator	Red LED (4-wire connection only)			
Overriding Voltage	24V, 11mA DC (4-wire connection only)			
Dimension	86 (W) x 86 (H) x 24 (D) mm	86 (W) x 86 (H) x 51 (D) mm		
Weight	0.12 kg	0.45 kg	0.46 kg	0.48 kg
Color	White (RAL 9016 or equivalent)			
Finish	Knob, Cover Panel: ABS Resin, White (RAL 9016 or equivalent) Front Panel (Plate): Surface treated steel plate			
Terminal	Screw type x 5 (Terminal)			
Usable Cable	Cable range 22 - 14 AWG			
Accessories	Not Available	Black Box 85.5 (W) x 85.5 (H) x 60 (D) mm Plate mounting screw 2		



Human Society with
Sound & Communication

TOA Electronics Pte Ltd

www.toa.com.sg

Specifications are subject to change without notice.
Printed in Singapore (65) 865-0713-01A