

Ferrule; sleeve for 6 mm² / awg 10; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90

Item No.: 216-208



Ferrule; sleeve for 6 mm² / awg 10; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90

Marking

RoHS ✓
Compliant

Business data

Supplier	WAGO
Item no.	216-208
GTIN / EAN	4017332277532
Content	1
Order amount	100
Customer item number	

Notes

Technical data

Miscellaneous

Color	yellow
Strip length 1	14 mm / 0.55 in
Fire load [MJ]	0.004 [MJ]
Weight [g]	0.4 [g]
Diameter [mm]	6.8 [mm]
Diameter 1 [mm]	6.3 [mm]
Diameter 2 [mm]	3.5 [mm]
Length [mm]	20 [mm]

Printview: Ferrule; sleeve for 6 mm² / awg 10; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90 - Item No.: 216-208

Technical data


Length 1 [mm]

12 [mm]

Printview: Ferrule; sleeve for 6 mm² / awg 10; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90 - Item No.: 216-208

Images & drawings



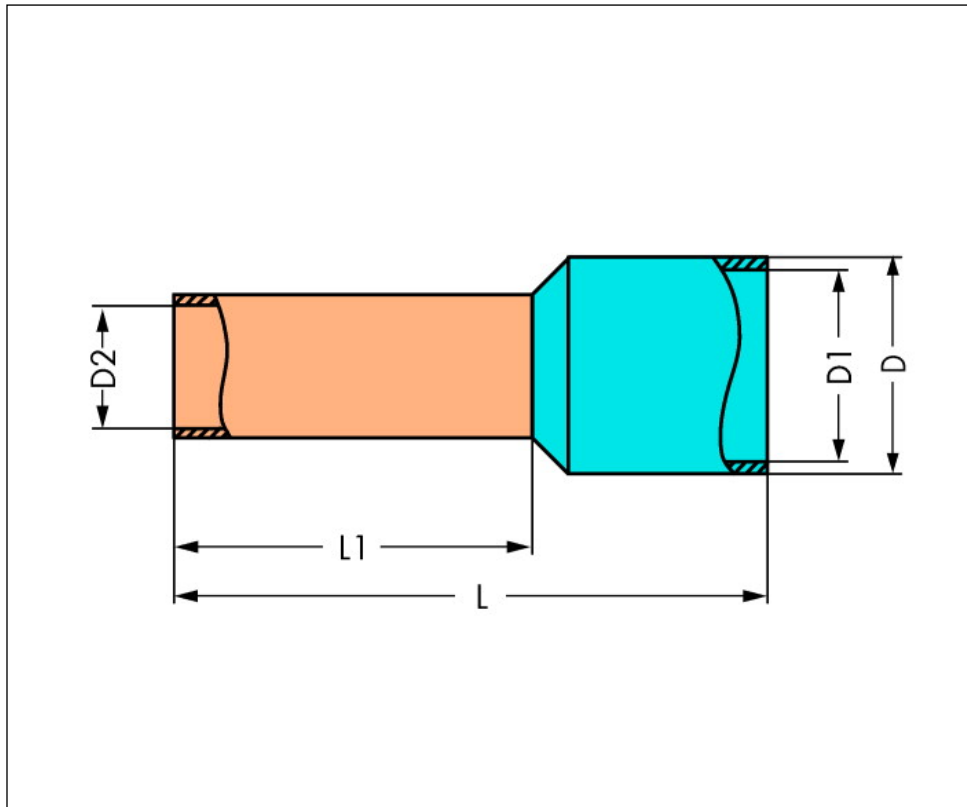

Address

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Telefon: 0571/887-0

Fax: 0571/887-169

<http://www.wago.com>

© WAGO Kontakttechnik GmbH & Co. KG

Technische Änderungen und Irrtümer vorbehalten.