

Printview: Ferrule; sleeve for 2.5 mm² / awg 14; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90 - Item No.: 216-206

WAGO® online catalog / eShop

Ferrule; sleeve for 2.5 mm² / awg 14; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90

Item No.: 216-206



Ferrule; sleeve for 2.5 mm² / awg 14; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90

Marking

RoHS ✓
Compliant

Business data

Supplier	WAGO
Item no.	216-206
GTIN / EAN	4017332277518
Content	1
Order amount	100
Customer item number	

Notes

Technical data

Miscellaneous

Color	blue
Strip length 1	10 mm / 0.39 in
Fire load [MJ]	0.002 [MJ]
Weight [g]	0.158 [g]
Diameter [mm]	4.8 [mm]
Diameter 1 [mm]	4.2 [mm]
Diameter 2 [mm]	2.3 [mm]
Length [mm]	15 [mm]

Printview: Ferrule; sleeve for 2.5 mm² / awg 14; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90 - Item No.: 216-206


Technical data

<i>Length 1 [mm]</i>	<i>8 [mm]</i>
----------------------	---------------

Printview: Ferrule; sleeve for 2.5 mm² / awg 14; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90 - Item No.: 216-206

Images & drawings



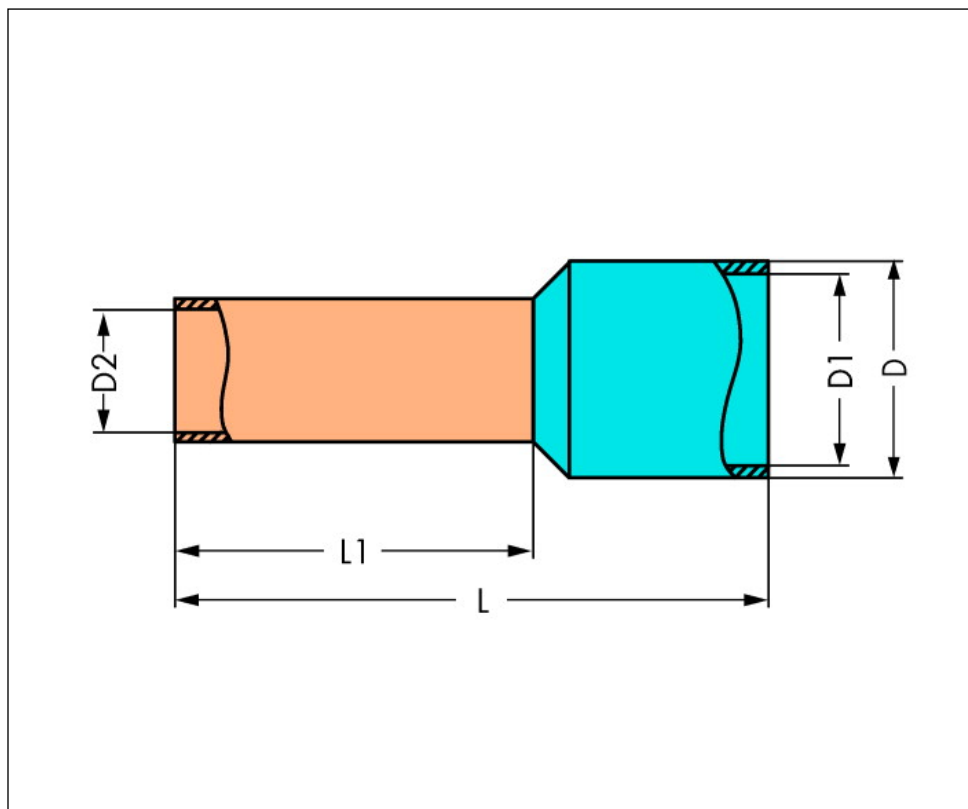

Address

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Telefon: 0571/887-0

Fax: 0571/887-169

<http://www.wago.com>

© WAGO Kontakttechnik GmbH & Co. KG

Technische Änderungen und Irrtümer vorbehalten.