

Printview: Interface module; with D-subminiature female connector; 50-pole; for mating connectors with solder connection; Vertical mounting - Item No.: 289-559

WAGO® online catalog / eShop

Interface module; with D-subminiature female connector; 50-pole; for mating connectors with solder connection; Vertical mounting

Item No.: 289-559



Interface module; with D-subminiature female connector; 50-pole; for mating connectors with solder connection;
Vertical mounting

Marking

RoHS ✓
Compliant

Business data

Supplier	WAGO
Item no.	289-559
GTIN / EAN	4045454409746
Content	1
Order amount	1
Customer item number	

Notes

Technical data


Miscellaneous

No. of poles	50
Pollution degree (1)	2
Rated voltage EN (1) [V]	125 [V]
Rated surge voltage (1) [kV]	0.8 [kV]
Wire connection 1	WAGO 236 Series
Operating voltage	125 V AC / DC
Nominal current [A]	2 [A]
Ambient operating temperature	-20 °C ... +50 °C

Printview: Interface module; with D-subminiature female connector; 50-pole; for mating connectors with solder connection; Vertical mounting - Item No.: 289-559

Technical data	
Connector contact	Au over Ni
Contact resistance [m]	30 [m]
Performance level	2 / 200 mating cycles
Connection technology (1)	CAGE CLAMP®
Solid sizes 1	0.08 ... 2.5 mm ² / 28 ... 12 AWG
Strip length 1	5 ... 6 mm / 0.2 ... 0.24 in
Weight [g]	121.894 [g]
Width	94 mm / 3.701 in
Height from upper-edge of DIN-rail [mm]	34 [mm]
Height from upper-edge of DIN-rail	34 mm / 1.339 in
Length	85 mm / 3.346 in
Storage temperature	-40 °C ... +70 °C
Type of mounting	DIN 35 rail

Images & drawings

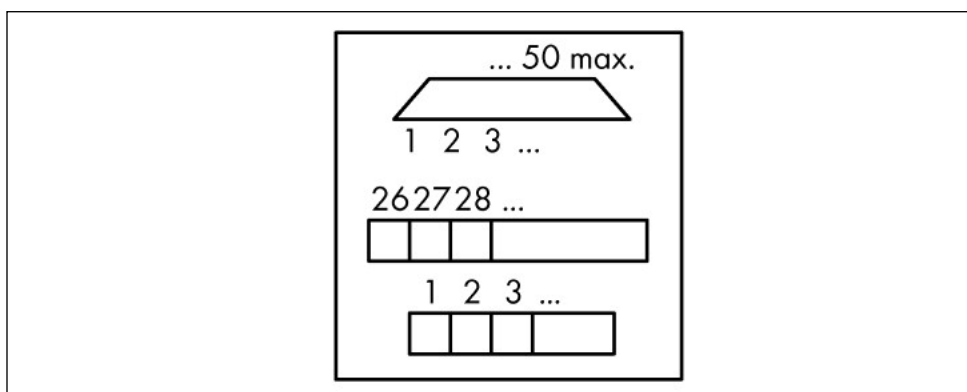

Address

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Telefon: 0571/887-0

Fax: 0571/887-169

<http://www.wago.com>

© WAGO Kontakttechnik GmbH & Co. KG

Technische Änderungen und Irrtümer vorbehalten.