

Socket without relay; Switching relay RT 25, 1 changeover contact

Item No.: 788-100



Socket without relay; Switching relay RT 25, 1 changeover contact

Marking

RoHS ✓
Compliant

Business data

Supplier	WAGO
Item no.	788-100
GTIN / EAN	4050821591764
Content	1
Order amount	1
Customer item number	

Notes



Technical data


Miscellaneous

Color	gray
Pollution degree (1)	3
Rated voltage EN (1) [V]	250 [V]
Rated surge voltage (1) [kV]	4 [kV]
Dielectric strength	5 kVrms (depending on relay)
Max. switching voltage	250 V AC
Max. switching power (resistive)	4 kVA / 2 x 2 kVA AC
Nominal operating mode	continious duty
Nominal input voltage VN	depending on relay; max. 250 V AC
Max. continuous current	16 A / 2 x 8 A

Technical data	
<i>Ambient operating temperature</i>	<i>-25 °C ... +70 °C (depending on relay)</i>
<i>Degree of protection</i>	<i>IP20</i>
<i>Connection technology (1)</i>	<i>Push-in CAGE CLAMP®</i>
<i>Solid sizes 1</i>	<i>0.34 ... 2.5 mm² / 22 ... 14 AWG</i>
<i>Strip length 1</i>	<i>9 ... 10 mm / 0.35 ... 0.39 in</i>
<i>Fire load [MJ]</i>	<i>0.633 [MJ]</i>
<i>Weight [g]</i>	<i>31.25 [g]</i>
<i>Width</i>	<i>15 mm / 0.591 in</i>
<i>Height from upper-edge of DIN-rail [mm]</i>	<i>54 [mm]</i>
<i>Height from upper-edge of DIN-rail</i>	<i>54 mm / 2.126 in</i>
<i>Length</i>	<i>86 mm / 3.386 in</i>
<i>Storage temperature</i>	<i>-40 °C ... +80 °C</i>
<i>Standards/specifications</i>	<i>EN 60664-1</i>
<i>Type of mounting</i>	<i>DIN 35 rail</i>

Images & drawings

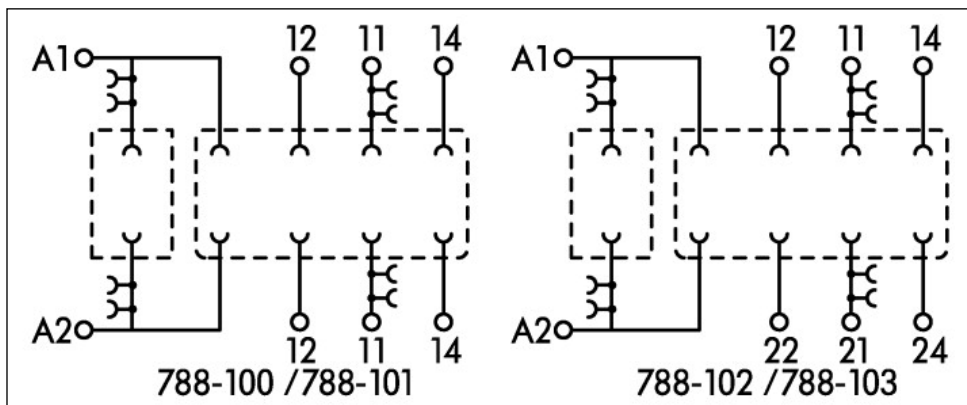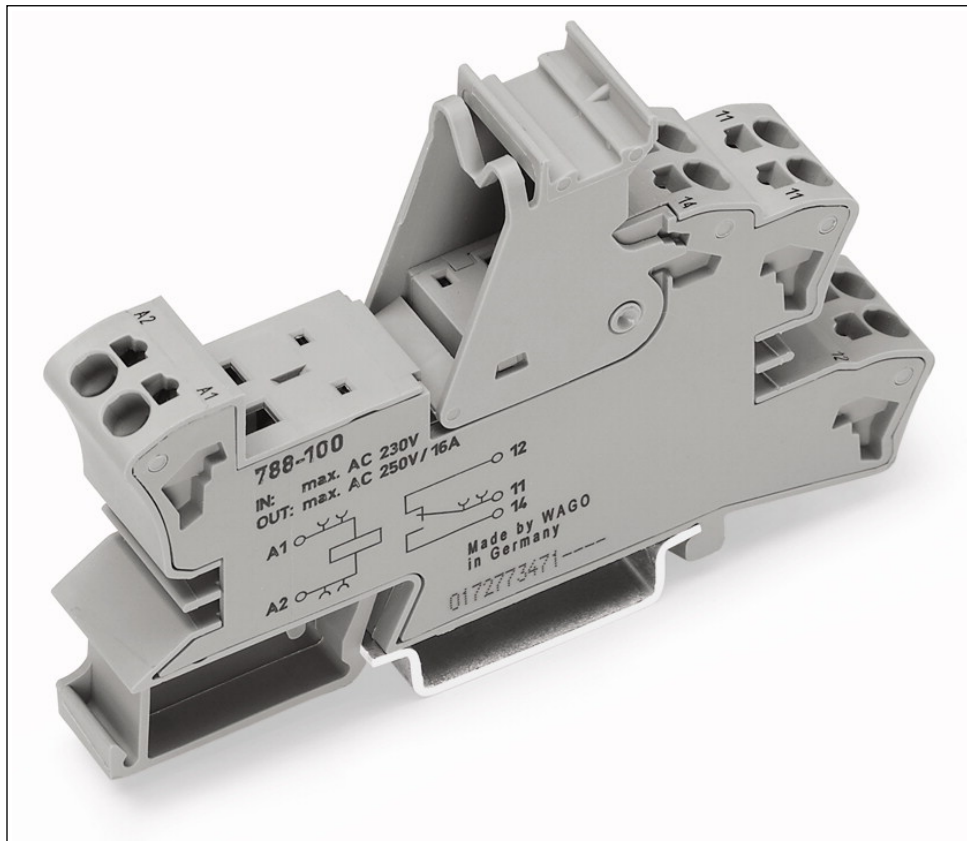

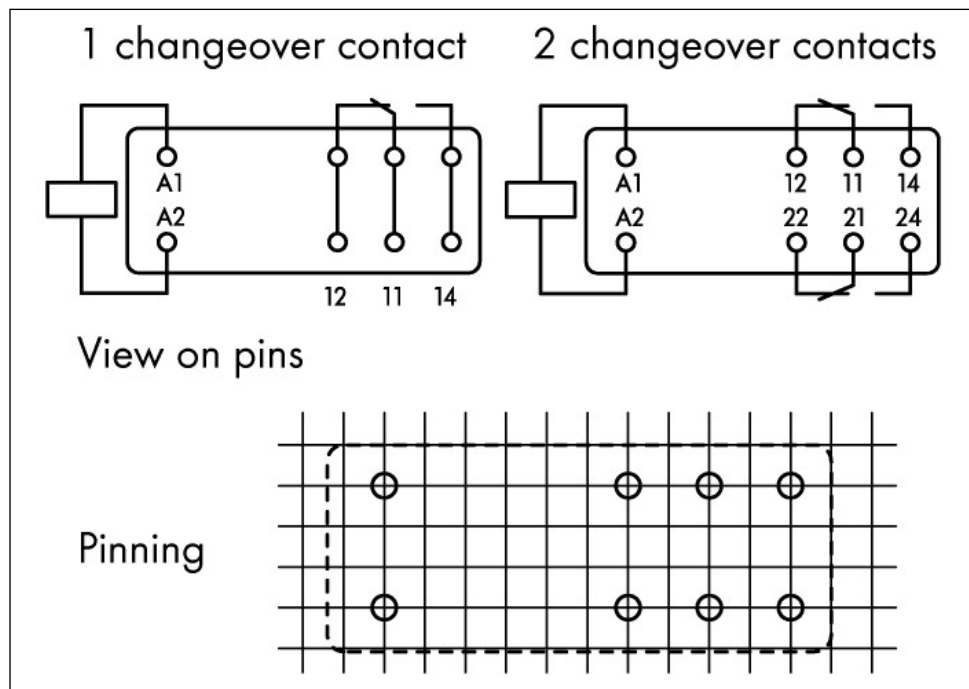

Address

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Telefon: 0571/887-0

Fax: 0571/887-169

<http://www.wago.com>

© WAGO Kontakttechnik GmbH & Co. KG

Technische Änderungen und Irrtümer vorbehalten.