

Data & Signal, Plug, 7.5 mm, 4-pole, solder terminal, insulated, brown



Description

- Solder terminal:
for cable mounting
- Data and Signal transfer
- Data and Signal Connectors 4-pole, insulated, straight

Weblinks


[pdf-datasheet](#), [html-datasheet](#), [General Product Information](#), [RoHS](#), [CHINA-RoHS](#), [REACH](#), [Mating Connectors](#), [e-Shop](#), [SCHURTER-Stock-Check](#), [Distributor-Stock-Check](#)

Technical Data

Diameter	7.5 mm
Number of Poles	4-pole
Ratings DC	2 A / 12VDC
Ratings AC	2 A / 12 VAC
Dielectric Strength	1000VDC
Insulation Resistance	> 10000 MΩ @ 500VDC
Material: Housing	brown

Allowable Operation Temp.	-20 °C to 70 °C
Terminal	solder terminal
Housing	insulated
Style	straight
Lifetime	50000 Insertions

Dimensions

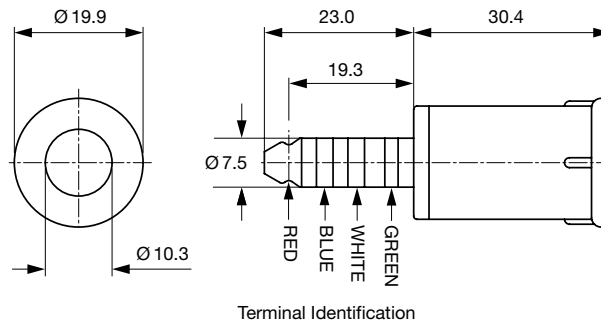

All Variants

Product group	Diameter [mm]	Number of Poles	Terminal	Order Number
Data and Signal Plug/Sockets	7.5	4-pole	solder terminal	4804.1401

Most Popular.

Availability for all products can be searched real-time: <http://www.schurter.com/en/Stock-Check/Stock-Check-SCHURTER>

Packaging unit 100 Pcs

Accessories

Description



4804.0002
 Sleeve brown, 5.6 mm



4804.0053
 Sleeve brown, 4.8 mm



4804.0054
 Sleeve brown, 4.2 mm

Mating Outlets/Connectors

Category / Description



[Data and Signal Plug/Socket Overview complete](#)

Kabeltülle PG12, Socket, solder terminal, screened, 7.5 mm, 4-pole, straight, UK-Connector	4804.2400
--------------------------------------------------------------------------------------------	-----------

Kabeltülle PG12, Socket, solder terminal, insulated, 7.5 mm, 4-pole, straight, UK-Connector	4804.2410
---------------------------------------------------------------------------------------------	-----------

[Data and Signal Plug/Socket further types to 4804.1401](#)