


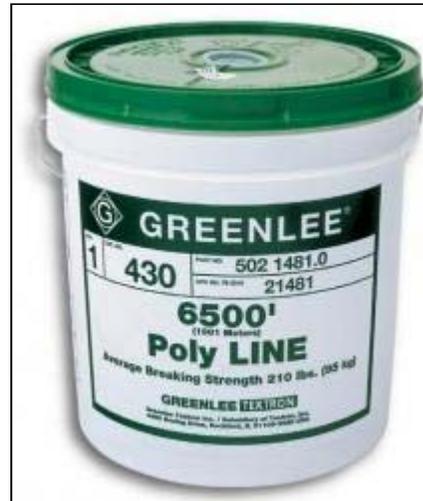

PRODUCT SEARCH

[HOME](#)[WHAT'S NEW](#)[SERVICE / SUPPORT](#)[WHERE TO BUY](#)[INSTRUCTION MANUALS](#)[CO](#)**TERMINATION**[Hand Tools](#)[Holemaking](#)[Bending](#)[Fishing](#)[Cable Pulling](#)[Wire & Cable Termination](#)[Voice Data Video](#)[Testing & Measurement](#)[Storage & Material Handling](#)[Hydraulic Pumps & Miscellaneous](#)**Name:**

Poly Line 6500' (1981 m)

Cat #:

430

UPC #:

21481

Spec:

Size- 6500' (1981 m) Capacity- 210 lbs. (934 N) average breaking strength Weight - 11 lbs. (5 kg)

Description:

Ready-to-use, pre-punched hole in lid with resealable cap.

- Use with power fishing systems directly from the container.
- Resists tangling when dispensing.
- Rot and mildew resistant.
- Handy reusable plastic dispenser pail with handle keeps the line dry.
- Use to pull rope through conduit.

