


SPORT HEADPHONES HA-EBT5

Wireless, Bluetooth, inner ear sport headphones with flat-fitting design

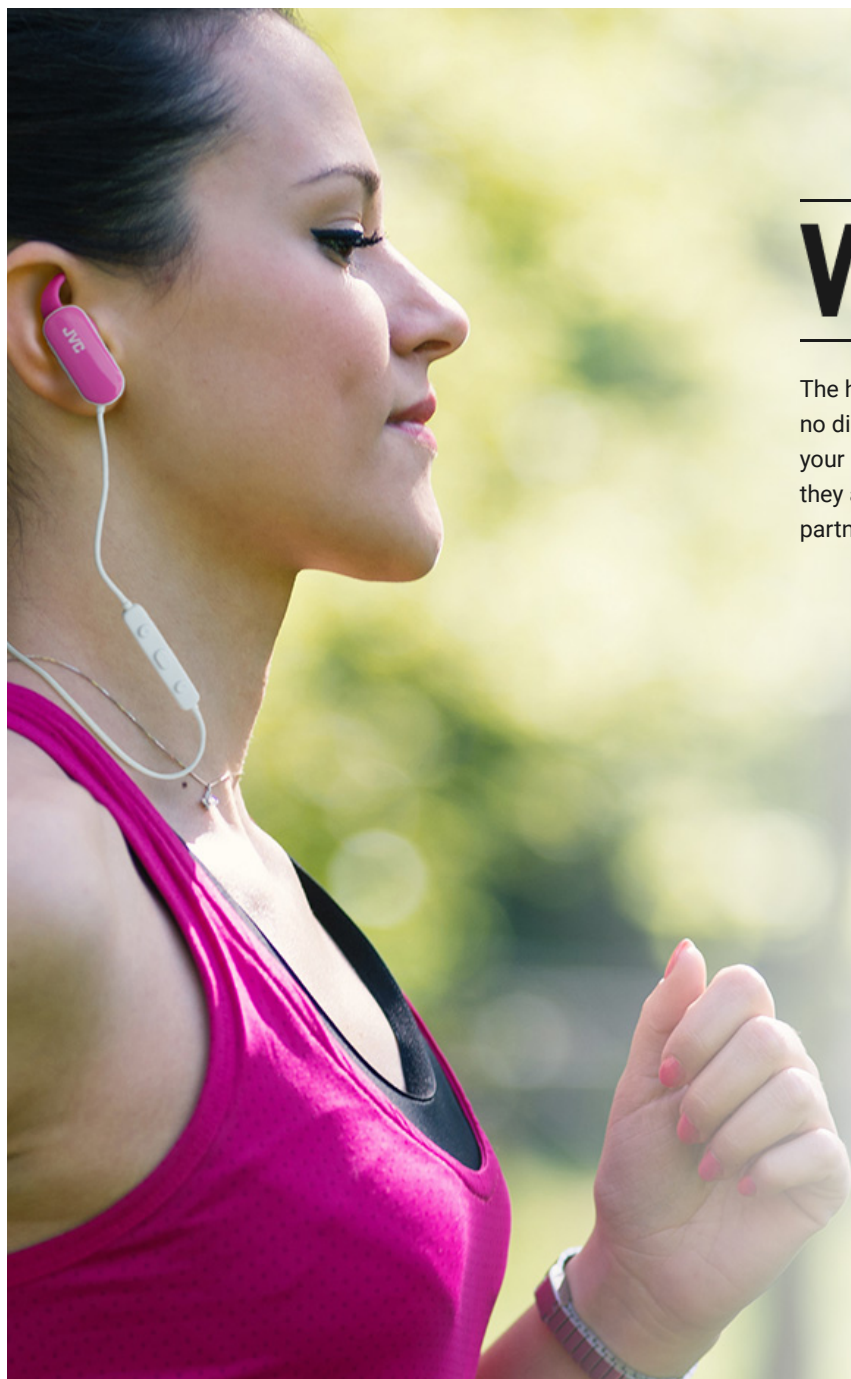

WIRELESS

The headphones featuring Bluetooth technology, no wires, no distraction, simply pair it with your device and focus on your running or work out. Not only are they wireless design, they are compact, lightweight, sheer pleasure as a sporting partner.

PIVOT MOTION FIT

Featuring a soft rubber rotating hook for secure and comfortable fit.

Since the hook doesn't go over the ear, there is no problem if you wear glasses or shades. Just put on the earphones and you are all set to go.



OPEN TYPE EARPIECE

To ensure your safety on the road when running, the open type ear piece allows ambient noise such as of an approaching vehicle to be heard for you act quickly. Optional regular earpieces are included so for enjoying dynamic sound.




THREE BUTTON REMOTE & MIC

A Three button remote with integrated mic provides easy operation to play, stop, skip tracks plus answer that important call.

SWEAT PROOF





The HA-EBT5 headphones are rated IPX4 Sweat / Splash proof, making them ideal for sport use.

JVC

HA-EBT5

WIRELESS

PIVOT MOTION FIT

REMOTE&MIC

SPECS

SPORT HEADPHONES

≡ LINEUP

SPECIFICATION

| | |
|-----------------------|--|
| Model | HA-EBT5 |
| Driver Unit | 10mm |
| Magnet | Neodymium |
| Frequency Response | 20-20,000Hz |
| Weight (with cord) | 15g |
| 3 button remote & mic | yes |
| Accessory | <ul style="list-style-type: none">• Silicone earpieces S/M/L• Open type earpieces S/M/L• Charging cord |
| Bluetooth | ver. 3.0 (class 2) |
| Supporting profile | AVRCP, A2DP, HSP, HFP |
| Supporting codec | SBC |
| Power supply | Built-in rechargeable battery |
| Battery life | 4.5 hours |
| Charging time | 2.5 hours |