

8p8c 2 Part FTP Plug for XXL Cables



8p8c FTP plug (PGSXL)

High performance shielded connector suitable for termination of extra large outer diameter cables for Category 6 and Category 6A

Features

- Designed for Category 6 and 6A performance
- Able to accommodate Category 6A and 7 cable with overall cable O.D. up to 8mm
- Suitable for inner cores up to 1.5mm O.D.
- 3 prong contacts for solid and stranded cable
- 2 part plug
- Shielded
- No soldering required
- Suitable with TUK's specialist crimp tool T2079
http://www.tuk.co.uk/tuk_live/product_details.php?category_id=3&pid=288

Specifications


- Housing colour: Transparent
- Material:
 - Housing: Polycarbonate UL 94V-0
 - Contact: 50 μ "/1.27 μ m gold plated phosphor bronze
 - Shell: Brass



PS2CLR8

Transparent PVC Strain Relief Boot
designed for use with PGSXL

ROHS Compliant

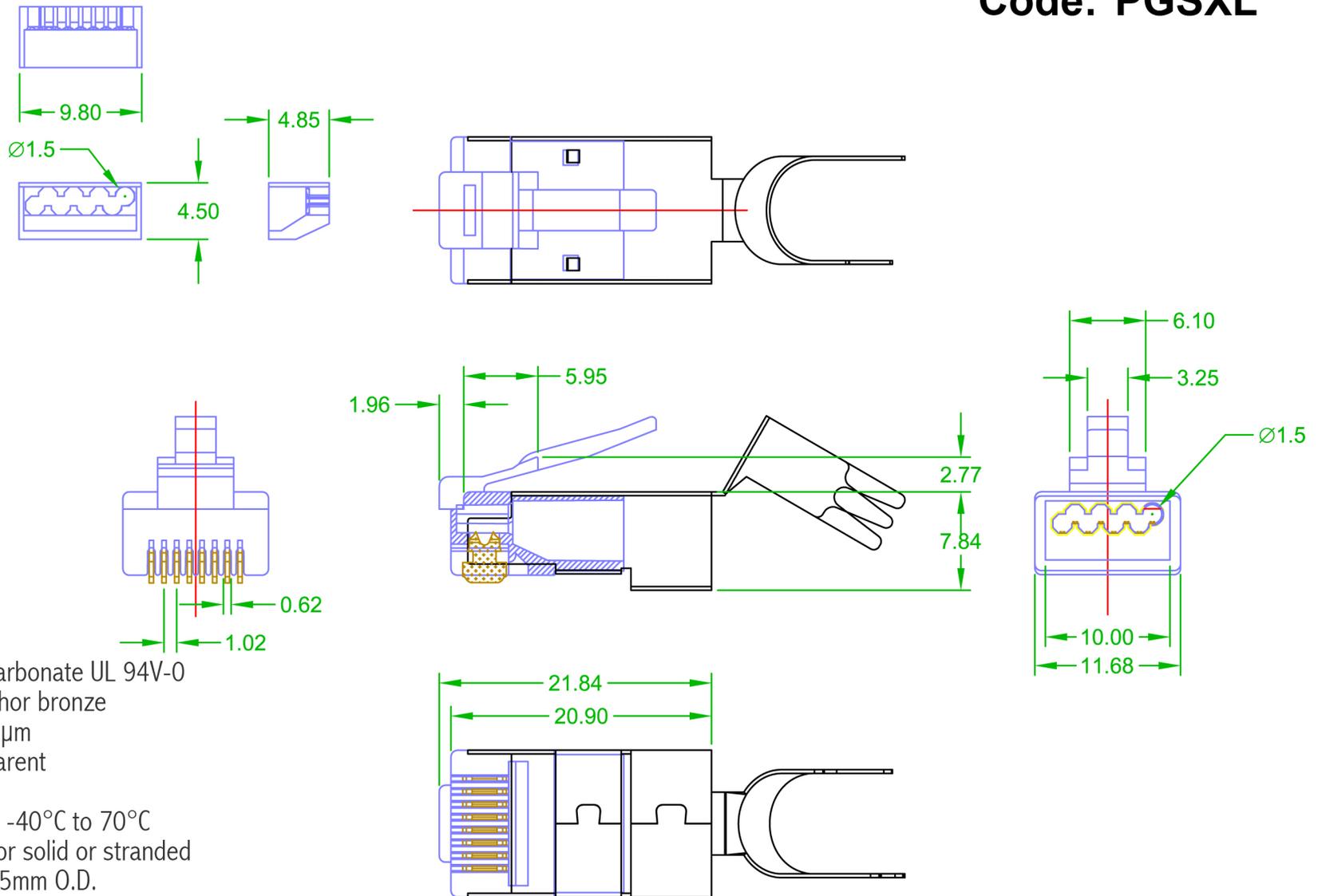

1. Housing Material: Polycarbonate UL 94V-0
2. Material Contact: Phosphor bronze
3. Gold Plating: $50\mu\text{m}/1.27\mu\text{m}$
4. Housing Colour: Transparent
5. Material Shell: Brass
6. Operating Temperature: -40°C to 70°C
7. 3 prong contact blade for solid or stranded
8. For inner cores up to 1.5mm O.D.
9. For overall cable O.D. up to 8mm

