

## Vinyl Material for Industrial Labeling (B-439)

Colored outdoor grade vinyl material for thermal transfer printing. Ideal for general labeling of equipment, panels, shelves, bins and tools in industrial and production areas.

 



Figure 33

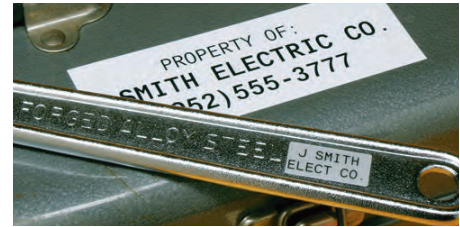

Fits Printer Models	Diagram	Part Number	B-#	Material	Color	Label Width A Inch (mm)	Label Height B Inch (mm)	Labels Per Row	Labels Per Roll	Rec. Ribbon
TLS, BMP71*	Fig. 33	PTL-8-439	B-439	Vinyl	White	0.500 (12.7)	50 ft. (15.2 m)	1	1 Roll Cont.	R6010
TLS, BMP71*	Fig. 33	PTL-42-439	B-439	Vinyl	White	1.000 (25.4)	50 ft. (15.2 m)	1	1 Roll Cont.	R6010
TLS, BMP71*	Fig. 33	PTL-43-439	B-439	Vinyl	White	1.900 (48.3)	50 ft. (15.2 m)	1	1 Roll Cont.	R6010
TLS, BMP71*	Fig. 33	PTL-8-439-YL	B-439	Vinyl	Yellow	0.500 (12.7)	50 ft. (15.2 m)	1	1 Roll Cont.	R6010
TLS, BMP71*	Fig. 33	PTL-42-439-YL	B-439	Vinyl	Yellow	1.000 (25.4)	50 ft. (15.2 m)	1	1 Roll Cont.	R6010
TLS, BMP71*	Fig. 33	PTL-43-439-YL	B-439	Vinyl	Yellow	1.900 (48.3)	50 ft. (15.2 m)	1	1 Roll Cont.	R6010
TLS, BMP71*	Fig. 33	PTL-8-439-BK	B-439	Vinyl	Black	0.500 (12.7)	50 ft. (15.2 m)	1	1 Roll Cont.	R4410-WT
TLS, BMP71*	Fig. 33	PTL-42-439-BK	B-439	Vinyl	Black	1.000 (25.4)	50 ft. (15.2 m)	1	1 Roll Cont.	R4410-WT
TLS, BMP71*	Fig. 33	PTL-43-439-BK	B-439	Vinyl	Black	1.900 (48.3)	50 ft. (15.2 m)	1	1 Roll Cont.	R4410-WT
TLS, BMP71*	Fig. 33	PTL-8-439-BL	B-439	Vinyl	Blue	0.500 (12.7)	50 ft. (15.2 m)	1	1 Roll Cont.	R4410-WT
TLS, BMP71*	Fig. 33	PTL-42-439-BL	B-439	Vinyl	Blue	1.000 (25.4)	50 ft. (15.2 m)	1	1 Roll Cont.	R4410-WT
TLS, BMP71*	Fig. 33	PTL-43-439-BL	B-439	Vinyl	Blue	1.900 (48.3)	50 ft. (15.2 m)	1	1 Roll Cont.	R4410-WT
TLS, BMP71*	Fig. 33	PTL-8-439-GR	B-439	Vinyl	Green	0.500 (12.7)	50 ft. (15.2 m)	1	1 Roll Cont.	R6010
TLS, BMP71*	Fig. 33	PTL-42-439-GR	B-439	Vinyl	Green	1.000 (25.4)	50 ft. (15.2 m)	1	1 Roll Cont.	R6010
TLS, BMP71*	Fig. 33	PTL-43-439-GR	B-439	Vinyl	Green	1.900 (48.3)	50 ft. (15.2 m)	1	1 Roll Cont.	R6010
TLS, BMP71*	Fig. 33	PTL-8-439-OR	B-439	Vinyl	Orange	0.500 (12.7)	50 ft. (15.2 m)	1	1 Roll Cont.	R6010
TLS, BMP71*	Fig. 33	PTL-42-439-OR	B-439	Vinyl	Orange	1.000 (25.4)	50 ft. (15.2 m)	1	1 Roll Cont.	R6010
TLS, BMP71*	Fig. 33	PTL-43-439-OR	B-439	Vinyl	Orange	1.900 (48.3)	50 ft. (15.2 m)	1	1 Roll Cont.	R6010
TLS, BMP71*	Fig. 33	PTL-8-439-RD	B-439	Vinyl	Red	0.500 (12.7)	50 ft. (15.2 m)	1	1 Roll Cont.	R6010
TLS, BMP71*	Fig. 33	PTL-42-439-RD	B-439	Vinyl	Red	1.000 (25.4)	50 ft. (15.2 m)	1	1 Roll Cont.	R6010
TLS, BMP71*	Fig. 33	PTL-43-439-RD	B-439	Vinyl	Red	1.900 (48.3)	50 ft. (15.2 m)	1	1 Roll Cont.	R6010

## Repositionable Vinyl Cloth Labels for General ID (B-498)

Repositionable vinyl cloth material for wire, cable, and component marking as well as general ID. Adhesive offers excellent holding power, while easily being repositioned and removed.

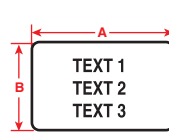


Figure 29

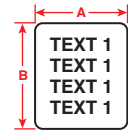


Figure 31

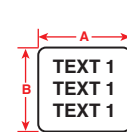


Figure 37



Fits Printer Models	Diagram	Part Number	B-#	Material	Color	Approx. Wire Gauge	Label Width A Inch (mm)	Label Height B Inch (mm)	Labels Per Row	Labels Per Roll	Rec. Ribbon
TLS, BMP71*	Fig. 37	PTL-7-499	B-499	Nylon	White	22 to 16	0.500 (12.7)	0.500 (12.7)	1	500	R4310
TLS, BMP71*	Fig. 31	BM71-11-499	B-499	Nylon	White	16 to 10	0.500 (12.7)	0.750 (19.1)	1	5000	R4310
TLS, BMP71*	Fig. 31	PTL-11-499	B-499	Nylon	White	16 to 10	0.500 (12.7)	0.750 (19.1)	1	500	R4310
TLS, BMP71*	Fig. 31	PTL-16-499	B-499	Nylon	White	12 to 10	0.375 (9.5)	1.000 (25.4)	1	500	R4310
TLS, BMP71*	Fig. 31	PTL-18-499	B-499	Nylon	White	12 to 10	0.750 (19.1)	1.000 (25.4)	1	250	R4310
TLS, BMP71*	Fig. 37	PTL-19-499	B-499	Nylon	White	12 to 10	1.000 (25.4)	1.000 (25.4)	1	250	R4310
TLS, BMP71*	Fig. 31	PTL-28-499	B-499	Nylon	White	10 to 4	0.250 (6.4)	1.500 (38.1)	1	750	R4310
TLS, BMP71*	Fig. 31	PTL-29-498	B-499	Nylon	White	10 to 4	0.500 (12.7)	1.500 (38.1)	1	500	R6210
TLS, BMP71*	Fig. 31	PTL-29-499	B-499	Nylon	White	10 to 4	0.500 (12.7)	1.500 (38.1)	1	500	R4310
TLS, BMP71*	Fig. 31	PTL-30-499	B-499	Nylon	White	10 to 4	0.750 (19.1)	1.500 (38.1)	1	250	R4310
TLS, BMP71*	Fig. 31	PTL-31-499	B-499	Nylon	White	10 to 4	1.000 (25.4)	1.500 (38.1)	1	250	R4310
TLS, BMP71*	Fig. 31	PTL-21-499	B-499	Nylon	White	Cables	1.000 (25.4)	2.500 (63.5)	1	100	R4310
TLS, BMP71*	Fig. 31	PTL-23-499	B-499	Nylon	White	Cables	1.000 (25.4)	4.000 (101.6)	1	100	R4310
TLS, BMP71*	Fig. 29	PTL-84-499	B-499	Nylon	White	-	0.900 (22.9)	0.500 (12.7)	1	500	R4310
TLS, BMP71*	Fig. 31	PTL-87-499	B-499	Nylon	White	-	1.000 (25.4)	1.750 (44.5)	1	250	R4310
TLS, BMP71*	Fig. 31	PTL-160-499	B-499	Nylon	White	-	1.750 (44.5)	1.875 (47.6)	1	100	R4310
TLS, BMP71*	Fig. 29	PTL-78-499	B-499	Nylon	White	-	1.900 (48.3)	1.000 (25.4)	1	250	R4310
TLS, BMP71*	Fig. 31	PTL-161-499	B-499	Nylon	White	-	1.930 (49.0)	3.000 (76.2)	1	100	R4310
TLS, BMP71*	Fig. 29	PTL-81-499	B-499	Nylon	White	-	1.900 (48.3)	0.250 (6.3)	1	750	R4310

See all TLS2200® and PC Link™ Ribbon parts on page 323.

\* Yellow media adaptor required for use in the BMP®71 printer. See page 324.

