
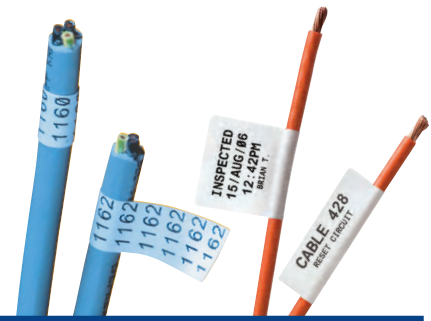


Adhesive Cloth Wire & Cable Wraps (B-498)


Adhesive cloth material for wire, cable, and component marking. Repositionable cloth variety offers excellent holding power, while easily being repositioned and removed.

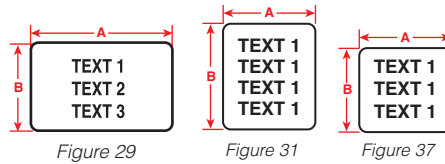

Fits Printer Models	Diagram	Part Number	B-#	Material	Color	Approx. Wire Gauge	Label Width A Inch (mm)	Label Height B Inch (mm)	Labels Per Row	Labels Per Roll	Rec. Ribbon
Repositionable Vinyl Cloth (B-498)											
TLS, BMP71*	Fig. 37	PTL-15-498	B-498	Vinyl Cloth	White	22 to 16	1.000 (25.4)	0.275 (7.0)	1	750	R6210
TLS, BMP71*	Fig. 37	PTL-7-498	B-498	Vinyl Cloth	White	22 to 16	0.500 (12.7)	0.500 (12.7)	1	500	R6210
TLS, BMP71*	Fig. 37	PTL-17-498	B-498	Vinyl Cloth	White	12 to 10	1.000 (25.4)	0.500 (12.7)	1	500	R6210
TLS, BMP71*	Fig. 31	PTL-10-498	B-498	Vinyl Cloth	White	16 to 10	0.250 (6.4)	0.750 (19.1)	1	750	R6210
TLS, BMP71*	Fig. 31	BM71-11-498	B-498	Vinyl Cloth	White	16 to 10	0.500 (12.7)	0.750 (19.1)	1	5000	R6210
TLS, BMP71*	Fig. 31	PTL-11-498	B-498	Vinyl Cloth	White	16 to 10	0.500 (12.7)	0.750 (19.1)	1	500	R6210
TLS, BMP71*	Fig. 31	PTL-16-498	B-498	Vinyl Cloth	White	12 to 10	0.375 (9.5)	1.000 (25.4)	1	500	R6210
TLS, BMP71*	Fig. 31	BM71-18-498	B-498	Vinyl Cloth	White	12 to 10	0.750 (19.1)	1.000 (25.4)	1	2500	R6210
TLS, BMP71*	Fig. 31	PTL-18-498	B-498	Vinyl Cloth	White	12 to 10	0.750 (19.1)	1.000 (25.4)	1	250	R6210
TLS, BMP71*	Fig. 37	BM71-19-498	B-498	Vinyl Cloth	White	12 to 10	1.000 (25.4)	1.000 (25.4)	1	2500	R6210
TLS, BMP71*	Fig. 37	PTL-19-498	B-498	Vinyl Cloth	White	12 to 10	1.000 (25.4)	1.000 (25.4)	1	250	R6210
TLS, BMP71*	Fig. 31	PTL-28-498	B-498	Vinyl Cloth	White	10 to 4	0.250 (6.4)	1.500 (38.1)	1	750	R6210
TLS, BMP71*	Fig. 31	BM71-29-498	B-498	Vinyl Cloth	White	10 to 4	0.500 (12.7)	1.500 (38.1)	1	5000	R6210
TLS, BMP71*	Fig. 31	PTL-30-498	B-498	Vinyl Cloth	White	10 to 4	0.750 (19.1)	1.500 (38.1)	1	250	R6210
TLS, BMP71*	Fig. 31	PTL-31-498	B-498	Vinyl Cloth	White	10 to 4	1.000 (25.4)	1.500 (38.1)	1	250	R6210
TLS, BMP71*	Fig. 37	PTL-32-498	B-498	Vinyl Cloth	White	10 to 4	1.500 (38.1)	1.500 (38.1)	1	250	R6210
TLS, BMP71*	Fig. 31	PTL-21-498	B-498	Vinyl Cloth	White	Cables	1.000 (25.4)	2.500 (63.5)	1	100	R6210
TLS, BMP71*	Fig. 31	PTL-23-498	B-498	Vinyl Cloth	White	Cables	1.000 (25.4)	4.000 (101.6)	1	100	R6210
TLS, BMP71*	Fig. 31	PTL-33-498	B-498	Vinyl Cloth	White	Cables	1.500 (38.1)	4.000 (101.6)	1	100	R6210
TLS, BMP71*	Fig. 31	PTL-34-498	B-498	Vinyl Cloth	White	Cables	1.500 (38.1)	6.000 (152.4)	1	50	R6210
Permanent Adhesive Nylon Cloth (B-499)											
TLS, BMP71*	Fig. 37	PTL-7-499	B-499	Nylon Cloth	White	22 to 16	0.500 (12.7)	0.500 (12.7)	1	500	R4310
TLS, BMP71*	Fig. 31	BM71-11-499	B-499	Nylon Cloth	White	16 to 10	0.500 (12.7)	0.750 (19.1)	1	5000	R4310
TLS, BMP71*	Fig. 31	PTL-11-499	B-499	Nylon Cloth	White	16 to 10	0.500 (12.7)	0.750 (19.1)	1	500	R4310
TLS, BMP71*	Fig. 31	PTL-16-499	B-499	Nylon Cloth	White	12 to 10	0.375 (9.5)	1.000 (25.4)	1	500	R4310
TLS, BMP71*	Fig. 31	PTL-18-499	B-499	Nylon Cloth	White	12 to 10	0.750 (19.1)	1.000 (25.4)	1	250	R4310
TLS, BMP71*	Fig. 37	PTL-19-499	B-499	Nylon Cloth	White	12 to 10	1.000 (25.4)	1.000 (25.4)	1	250	R4310
TLS, BMP71*	Fig. 31	PTL-28-499	B-499	Nylon Cloth	White	10 to 4	0.250 (6.4)	1.500 (38.1)	1	750	R4310
TLS, BMP71*	Fig. 31	PTL-29-498	B-499	Nylon Cloth	White	10 to 4	0.500 (12.7)	1.500 (38.1)	1	500	R6210
TLS, BMP71*	Fig. 31	PTL-29-499	B-499	Nylon Cloth	White	10 to 4	0.500 (12.7)	1.500 (38.1)	1	500	R4310
TLS, BMP71*	Fig. 31	PTL-30-499	B-499	Nylon Cloth	White	10 to 4	0.750 (19.1)	1.500 (38.1)	1	250	R4310
TLS, BMP71*	Fig. 31	PTL-31-499	B-499	Nylon Cloth	White	10 to 4	1.000 (25.4)	1.500 (38.1)	1	250	R4310
TLS, BMP71*	Fig. 31	PTL-21-499	B-499	Nylon Cloth	White	Cables	1.000 (25.4)	2.500 (63.5)	1	100	R4310
TLS, BMP71*	Fig. 31	PTL-23-499	B-499	Nylon Cloth	White	Cables	1.000 (25.4)	4.000 (101.6)	1	100	R4310
TLS, BMP71*	Fig. 29	PTL-84-499	B-499	Nylon Cloth	White	-	0.900 (22.9)	0.500 (12.7)	1	500	R4310
TLS, BMP71*	Fig. 29	PTL-78-499	B-499	Nylon Cloth	White	-	1.900 (48.3)	1.000 (25.4)	1	250	R4310
TLS, BMP71*	Fig. 29	PTL-81-499	B-499	Nylon Cloth	White	-	1.900 (48.3)	0.250 (6.3)	1	750	R4310

Terminal Block Adhesive Strips (B-498)

 Repositionable vinyl cloth material for wire, cable, and component marking. Adhesive and cloth backing offers excellent holding power, while easily being repositioned and removed.



Fits Printer Models	Diagram	Part Number	B-#	Material	Color	Label Width A Inch (mm)	Label Height B Inch (mm)	Labels Per Row	Labels Per Roll	Rec. Ribbon
TLS, BMP71*	Fig. 30	PTLTB-498-318	B-498	Vinyl	White	0.318 (8.1)	30 ft. (9.1 m)	1	1 Roll Cont.	R6210
TLS, BMP71*	Fig. 30	PTLTB-498-375	B-498	Vinyl	White	0.375 (9.5)	30 ft. (9.1 m)	1	1 Roll Cont.	R6210
TLS, BMP71*	Fig. 30	BPTLTB-498-240	B-498	Vinyl	White	0.240 (6.1)	300 ft. (91.4 m)	1	1 Roll Cont.	R6210
TLS, BMP71*	Fig. 30	BPTLTB-498-318	B-498	Vinyl	White	0.318 (8.1)	300 ft. (91.4 m)	1	1 Roll Cont.	R6210
TLS, BMP71*	Fig. 30	BPTLTB-498-375	B-498	Vinyl	White	0.375 (9.5)	300 ft. (91.4 m)	1	1 Roll Cont.	R6210

*Approx. wire gauge based on AWG for THHN wire.

See all TLS2200® and PC Link™ Ribbon parts on page 323.
* Yellow media adaptor required for use in the BMP®71 printer. See page 324.