


# Thick Film Chip Resistor 0402

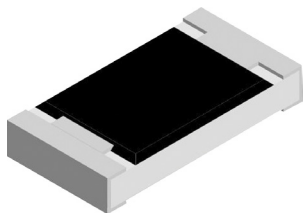

RoHS  
Compliant




## Features

- Small size and light weight
- Suitable for both wave and reflow soldering
- Reduction of assembly costs



## Performance Specification

Temperature Coefficient	: 0Ω1 to 0Ω99	±800PPM/°C
	: 1Ω to 10Ω	±400PPM/°C
	: 10.1Ω to 100Ω	±200PPM/°C
	: 101Ω to 10MΩ	±100PPM/°C
Short Time Overload	: ±1% : ±(1% +0.1Ω)Max.	
Insulation Resistance	: Min. 1,000MΩ	
Dielectric Withstanding Voltage	: No evidence of flashover, mechanical damage, arcing or insulation breakdown.	
Terminal Bending	: ±(1% +0.05Ω) Max.	
Soldering Heat	: ±(1% +0.05Ω) Max.	
Solderability	: Min. 95% coverage	
Temperature Cycling	: ±1% : ±(0.5% +0.05Ω) Max.	
Humidity (Steady State)	: ±1% : ±(0.5% +0.1Ω) Max.	
Load Life in Humidity	: ±1% : ±(1% +0.1Ω) Max.	
Load Life	: ±1% : ±(1% +0.1Ω) Max.	

## Derating Curve

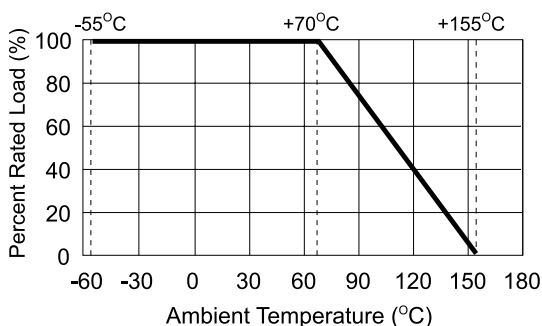

## Dimension

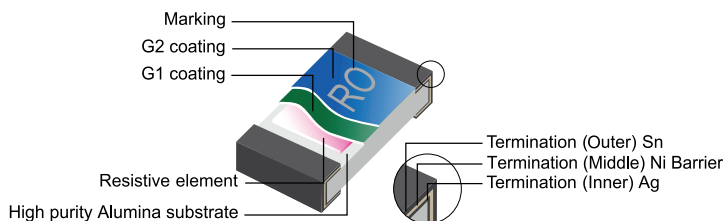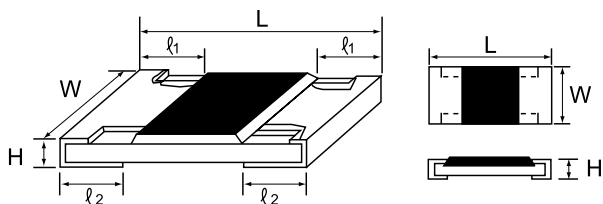

# Thick Film Chip Resistor 0402



Type	Dimension (mm)				
	L	W	H	ℓ <sub>1</sub>	ℓ <sub>2</sub>
0402	1 ±0.1	0.5 ±0.05	0.35 ±0.05	0.2 ±0.1	0.25 ±0.1

Type	Power Rating at 70°C	Max. Working Voltage/Current	Max. Overload Voltage/Current	Dielectric Withstanding Voltage	Tolerance %	Resistance Range
0402	1/16W	1A	2A	-	Jumper	<50mΩ
		50V	100V	100V	±1%	1Ω to 10MΩ

## Part Number Table

Description	Part Number	Description	Part Number
Resistor, Thick Film, 0R, 0.063W, 0402	MC00625W040210R	Resistor, Thick Film, 11R5, 1%, 0.0625W, 0402	MC00625W0402111R5
Resistor, Thick Film, 100K, 1%, 0.0625W, 0402	MC00625W04021100K	Resistor, Thick Film, 120K, 1%, 0.0625W, 0402	MC00625W04021120K
Resistor, Thick Film, 100R, 1%, 0.0625W, 0402	MC00625W04021100R	Resistor, Thick Film, 120R, 1%, 0.0625W, 0402	MC00625W04021120R
Resistor, Thick Film, 102K, 1%, 0.0625W, 0402	MC00625W04021102K	Resistor, Thick Film, 121K, 1%, 0.0625W, 0402	MC00625W04021121K
Resistor, Thick Film, 102R, 1%, 0.0625W, 0402	MC00625W04021102R	Resistor, Thick Film, 121R, 1%, 0.0625W, 0402	MC00625W04021121R
Resistor, Thick Film, 105K, 1%, 0.0625W, 0402	MC00625W04021105K	Resistor, Thick Film, 121R, 1%, 0.0625W, 0402	MC00625W04021121R..
Resistor, Thick Film, 105R, 1%, 0.0625W, 0402	MC00625W04021105R	Resistor, Thick Film, 124K, 1%, 0.0625W, 0402	MC00625W04021124K
Resistor, Thick Film, 107K, 1%, 0.0625W, 0402	MC00625W04021107K	Resistor, Thick Film, 124R, 1%, 0.0625W, 0402	MC00625W04021124R
Resistor, Thick Film, 107R, 1%, 0.0625W, 0402	MC00625W04021107R	Resistor, Thick Film, 127K, 1%, 0.0625W, 0402	MC00625W04021127K
Resistor, Thick Film, 10K, 1%, 0.0625W, 0402	MC00625W0402110K	Resistor, Thick Film, 127R, 1%, 0.0625W, 0402	MC00625W04021127R
Resistor, Thick Film, 10K2, 1%, 0.0625W, 0402	MC00625W0402110K2	Resistor, Thick Film, 127R, 1%, 0.0625W, 0402	MC00625W04021127R..
Resistor, Thick Film, 10K5, 1%, 0.0625W, 0402	MC00625W0402110K5	Resistor, Thick Film, 12K, 1%, 0.0625W, 0402	MC00625W0402112K
Resistor, Thick Film, 10K7, 1%, 0.0625W, 0402	MC00625W0402110K7	Resistor, Thick Film, 12K1, 1%, 0.0625W, 0402	MC00625W0402112K1
Resistor, Thick Film, 10M, 1%, 0.0625W, 0402	MC00625W0402110M0	Resistor, Thick Film, 12K4, 1%, 0.0625W, 0402	MC00625W0402112K4
Resistor, Thick Film, 10R, 1%, 0.0625W, 0402	MC00625W0402110R	Resistor, Thick Film, 12K7, 1%, 0.0625W, 0402	MC00625W0402112K7
Resistor, Thick Film, 10R2, 1%, 0.0625W, 0402	MC00625W0402110R2	Resistor, Thick Film, 12R, 1%, 0.0625W, 0402	MC00625W0402112R
Resistor, Thick Film, 10R5, 1%, 0.0625W, 0402	MC00625W0402110R5	Resistor, Thick Film, 12R1, 1%, 0.0625W, 0402	MC00625W0402112R1
Resistor, Thick Film, 110K, 1%, 0.0625W, 0402	MC00625W04021110K	Resistor, Thick Film, 12R7, 1%, 0.0625W, 0402	MC00625W0402112R7
Resistor, Thick Film, 110R, 1%, 0.0625W, 0402	MC00625W04021110R	Resistor, Thick Film, 130K, 1%, 0.0625W, 0402	MC00625W04021130K
Resistor, Thick Film, 113K, 1%, 0.0625W, 0402	MC00625W04021113K	Resistor, Thick Film, 130R, 1%, 0.0625W, 0402	MC00625W04021130R
Resistor, Thick Film, 113R, 1%, 0.0625W, 0402	MC00625W04021113R	Resistor, Thick Film, 133K, 1%, 0.0625W, 0402	MC00625W04021133K
Resistor, Thick Film, 115K, 1%, 0.0625W, 0402	MC00625W04021115K	Resistor, Thick Film, 133R, 1%, 0.0625W, 0402	MC00625W04021133R
Resistor, Thick Film, 115R, 1%, 0.0625W, 0402	MC00625W04021115R	Resistor, Thick Film, 137K, 1%, 0.0625W, 0402	MC00625W04021137K
Resistor, Thick Film, 118K, 1%, 0.0625W, 0402	MC00625W04021118K	Resistor, Thick Film, 137R, 1%, 0.0625W, 0402	MC00625W04021137R
Resistor, Thick Film, 118R, 1%, 0.0625W, 0402	MC00625W04021118R	Resistor, Thick Film, 13K, 1%, 0.0625W, 0402	MC00625W0402113K
Resistor, Thick Film, 11K, 1%, 0.0625W, 0402	MC00625W0402111K	Resistor, Thick Film, 13K3, 1%, 0.0625W, 0402	MC00625W0402113K3
Resistor, Thick Film, 11K3, 1%, 0.0625W, 0402	MC00625W0402111K3	Resistor, Thick Film, 13K7, 1%, 0.0625W, 0402	MC00625W0402113K7
Resistor, Thick Film, 11K5, 1%, 0.0625W, 0402	MC00625W0402111K5	Resistor, Thick Film, 13R, 1%, 0.0625W, 0402	MC00625W0402113R
Resistor, Thick Film, 11K8, 1%, 0.0625W, 0402	MC00625W0402111K8	Resistor, Thick Film, 13R3, 1%, 0.0625W, 0402	MC00625W0402113R3
Resistor, Thick Film, 11R, 1%, 0.0625W, 0402	MC00625W0402111R	Resistor, Thick Film, 140K, 1%, 0.0625W, 0402	MC00625W04021140K

# Thick Film Chip Resistor 0402



Description	Part Number	Description	Part Number
Resistor, Thick Film, 140R, 1%, 0.0625W, 0402	MC00625W04021140R	Resistor, Thick Film, 17R8, 1%, 0.0625W, 0402	MC00625W0402117R8
Resistor, Thick Film, 143K, 1%, 0.0625W, 0402	MC00625W04021143K	Resistor, Thick Film, 180K, 1%, 0.0625W, 0402	MC00625W04021180K
Resistor, Thick Film, 147K, 1%, 0.0625W, 0402	MC00625W04021147K	Resistor, Thick Film, 180R, 1%, 0.0625W, 0402	MC00625W04021180R
Resistor, Thick Film, 147R, 1%, 0.0625W, 0402	MC00625W04021147R	Resistor, Thick Film, 182K, 1%, 0.0625W, 0402	MC00625W04021182K
Resistor, Thick Film, 14K, 1%, 0.0625W, 0402	MC00625W0402114K	Resistor, Thick Film, 182R, 1%, 0.0625W, 0402	MC00625W04021182R
Resistor, Thick Film, 14K3, 1%, 0.0625W, 0402	MC00625W0402114K3	Resistor, Thick Film, 187K, 1%, 0.0625W, 0402	MC00625W04021187K
Resistor, Thick Film, 14K7, 1%, 0.0625W, 0402	MC00625W0402114K7	Resistor, Thick Film, 187R, 1%, 0.0625W, 0402	MC00625W04021187R
Resistor, Thick Film, 14R, 1%, 0.0625W, 0402	MC00625W0402114R	Resistor, Thick Film, 18K, 1%, 0.0625W, 0402	MC00625W0402118K
Resistor, Thick Film, 14R7, 1%, 0.0625W, 0402	MC00625W0402114R7	Resistor, Thick Film, 18K2, 1%, 0.0625W, 0402	MC00625W0402118K2
Resistor, Thick Film, 150K, 1%, 0.0625W, 0402	MC00625W04021150K	Resistor, Thick Film, 18K7, 1%, 0.0625W, 0402	MC00625W0402118K7
Resistor, Thick Film, 150R, 1%, 0.0625W, 0402	MC00625W04021150R	Resistor, Thick Film, 18R, 1%, 0.0625W, 0402	MC00625W0402118R
Resistor, Thick Film, 154K, 1%, 0.0625W, 0402	MC00625W04021154K	Resistor, Thick Film, 18R7, 1%, 0.0625W, 0402	MC00625W0402118R7
Resistor, Thick Film, 154R, 1%, 0.0625W, 0402	MC00625W04021154R	Resistor, Thick Film, 191K, 1%, 0.0625W, 0402	MC00625W04021191K
Resistor, Thick Film, 158K, 1%, 0.0625W, 0402	MC00625W04021158K	Resistor, Thick Film, 191R, 1%, 0.0625W, 0402	MC00625W04021191R
Resistor, Thick Film, 158R, 1%, 0.0625W, 0402	MC00625W04021158R	Resistor, Thick Film, 196K, 1%, 0.0625W, 0402	MC00625W04021196K
Resistor, Thick Film, 15K, 1%, 0.0625W, 0402	MC00625W0402115K	Resistor, Thick Film, 196R, 1%, 0.0625W, 0402	MC00625W04021196R
Resistor, Thick Film, 15K4, 1%, 0.0625W, 0402	MC00625W0402115K4	Resistor, Thick Film, 19K1, 1%, 0.0625W, 0402	MC00625W0402119K1
Resistor, Thick Film, 15K8, 1%, 0.0625W, 0402	MC00625W0402115K8	Resistor, Thick Film, 19K6, 1%, 0.0625W, 0402	MC00625W0402119K6
Resistor, Thick Film, 15R, 1%, 0.0625W, 0402	MC00625W0402115R	Resistor, Thick Film, 19R1, 1%, 0.0625W, 0402	MC00625W0402119R1
Resistor, Thick Film, 15R4, 1%, 0.0625W, 0402	MC00625W0402115R4	Resistor, Thick Film, 19R6, 1%, 0.0625W, 0402	MC00625W0402119R6
Resistor, Thick Film, 160K, 1%, 0.0625W, 0402	MC00625W04021160K	Resistor, Thick Film, 1K, 1%, 0.0625W, 0402	MC00625W040211K
Resistor, Thick Film, 160R, 1%, 0.0625W, 0402	MC00625W04021160R	Resistor, Thick Film, 1K02, 1%, 0.0625W, 0402	MC00625W040211K02
Resistor, Thick Film, 162K, 1%, 0.0625W, 0402	MC00625W04021162K	Resistor, Thick Film, 1K05, 1%, 0.0625W, 0402	MC00625W040211K05
Resistor, Thick Film, 162R, 1%, 0.0625W, 0402	MC00625W04021162R	Resistor, Thick Film, 1K07, 1%, 0.0625W, 0402	MC00625W040211K07
Resistor, Thick Film, 165K, 1%, 0.0625W, 0402	MC00625W04021165K	Resistor, Thick Film, 1K1, 1%, 0.0625W, 0402	MC00625W040211K1
Resistor, Thick Film, 165R, 1%, 0.0625W, 0402	MC00625W04021165R	Resistor, Thick Film, 1K13, 1%, 0.0625W, 0402	MC00625W040211K13
Resistor, Thick Film, 169K, 1%, 0.0625W, 0402	MC00625W04021169K	Resistor, Thick Film, 1K15, 1%, 0.0625W, 0402	MC00625W040211K15
Resistor, Thick Film, 169R, 1%, 0.0625W, 0402	MC00625W04021169R	Resistor, Thick Film, 1K18, 1%, 0.0625W, 0402	MC00625W040211K18
Resistor, Thick Film, 16K, 1%, 0.0625W, 0402	MC00625W0402116K	Resistor, Thick Film, 1K2, 1%, 0.0625W, 0402	MC00625W040211K2
Resistor, Thick Film, 16K2, 1%, 0.0625W, 0402	MC00625W0402116K2	Resistor, Thick Film, 1K21, 1%, 0.0625W, 0402	MC00625W040211K21
Resistor, Thick Film, 16K5, 1%, 0.0625W, 0402	MC00625W0402116K5	Resistor, Thick Film, 1K24, 1%, 0.0625W, 0402	MC00625W040211K24
Resistor, Thick Film, 16K9, 1%, 0.0625W, 0402	MC00625W0402116K9	Resistor, Thick Film, 1K27, 1%, 0.0625W, 0402	MC00625W040211K27
Resistor, Thick Film, 16K9, 1%, 0.0625W, 0402	MC00625W0402116K9..	Resistor, Thick Film, 1K3, 1%, 0.0625W, 0402	MC00625W040211K3
Resistor, Thick Film, 16R, 1%, 0.0625W, 0402	MC00625W0402116R	Resistor, Thick Film, 1K33, 1%, 0.0625W, 0402	MC00625W040211K33
Resistor, Thick Film, 16R2, 1%, 0.0625W, 0402	MC00625W0402116R2	Resistor, Thick Film, 1K37, 1%, 0.0625W, 0402	MC00625W040211K37
Resistor, Thick Film, 16R5, 1%, 0.0625W, 0402	MC00625W0402116R5	Resistor, Thick Film, 1K4, 1%, 0.0625W, 0402	MC00625W040211K4
Resistor, Thick Film, 16R9, 1%, 0.0625W, 0402	MC00625W0402116R9	Resistor, Thick Film, 1K43, 1%, 0.0625W, 0402	MC00625W040211K43
Resistor, Thick Film, 174K, 1%, 0.0625W, 0402	MC00625W04021174K	Resistor, Thick Film, 1K47, 1%, 0.0625W, 0402	MC00625W040211K47
Resistor, Thick Film, 174R, 1%, 0.0625W, 0402	MC00625W04021174R	Resistor, Thick Film, 1K5, 1%, 0.0625W, 0402	MC00625W040211K5
Resistor, Thick Film, 178K, 1%, 0.0625W, 0402	MC00625W04021178K	Resistor, Thick Film, 1K54, 1%, 0.0625W, 0402	MC00625W040211K54
Resistor, Thick Film, 178R, 1%, 0.0625W, 0402	MC00625W04021178R	Resistor, Thick Film, 1K58, 1%, 0.0625W, 0402	MC00625W040211K58
Resistor, Thick Film, 17K4, 1%, 0.0625W, 0402	MC00625W0402117K4	Resistor, Thick Film, 1K6, 1%, 0.0625W, 0402	MC00625W040211K6
Resistor, Thick Film, 17K8, 1%, 0.0625W, 0402	MC00625W0402117K8	Resistor, Thick Film, 1K62, 1%, 0.0625W, 0402	MC00625W040211K62

www.element14.com  
www.farnell.com  
www.newark.com



# Thick Film Chip Resistor 0402



Description	Part Number
Resistor, Thick Film, 1K65, 1%, 0.0625W, 0402	MC00625W040211K65
Resistor, Thick Film, 1K69, 1%, 0.0625W, 0402	MC00625W040211K69
Resistor, Thick Film, 1K74, 1%, 0.0625W, 0402	MC00625W040211K74
Resistor, Thick Film, 1K78, 1%, 0.0625W, 0402	MC00625W040211K78
Resistor, Thick Film, 1K8, 1%, 0.0625W, 0402	MC00625W040211K8
Resistor, Thick Film, 1K82, 1%, 0.0625W, 0402	MC00625W040211K82
Resistor, Thick Film, 1K87, 1%, 0.0625W, 0402	MC00625W040211K87
Resistor, Thick Film, 1K91, 1%, 0.0625W, 0402	MC00625W040211K91
Resistor, Thick Film, 1K96, 1%, 0.0625W, 0402	MC00625W040211K96
Resistor, Thick Film, 1M, 1%, 0.0625W, 0402	MC00625W040211M
Resistor, Thick Film, 1M05, 1%, 0.0625W, 0402	MC00625W040211M05
Resistor, Thick Film, 1M1, 1%, 0.0625W, 0402	MC00625W040211M10
Resistor, Thick Film, 1M2, 1%, 0.0625W, 0402	MC00625W040211M20
Resistor, Thick Film, 1M21, 1%, 0.0625W, 0402	MC00625W040211M21
Resistor, Thick Film, 1M27, 1%, 0.0625W, 0402	MC00625W040211M27
Resistor, Thick Film, 1M3, 1%, 0.0625W, 0402	MC00625W040211M30
Resistor, Thick Film, 1M4, 1%, 0.0625W, 0402	MC00625W040211M40
Resistor, Thick Film, 1M47, 1%, 0.0625W, 0402	MC00625W040211M47
Resistor, Thick Film, 1M5, 1%, 0.0625W, 0402	MC00625W040211M50
Resistor, Thick Film, 1M6, 1%, 0.0625W, 0402	MC00625W040211M60
Resistor, Thick Film, 1M69, 1%, 0.0625W, 0402	MC00625W040211M69
Resistor, Thick Film, 1M8, 1%, 0.0625W, 0402	MC00625W040211M80
Resistor, Thick Film, 1R, 1%, 0.0625W, 0402	MC00625W040211R0
Resistor, Thick Film, 1R1, 1%, 0.0625W, 0402	MC00625W040211R10
Resistor, Thick Film, 1R2, 1%, 0.0625W, 0402	MC00625W040211R20
Resistor, Thick Film, 1R3, 1%, 0.0625W, 0402	MC00625W040211R30
Resistor, Thick Film, 1R5, 1%, 0.0625W, 0402	MC00625W040211R5
Resistor, Thick Film, 1R54, 1%, 0.0625W, 0402	MC00625W040211R54
Resistor, Thick Film, 1R6, 1%, 0.0625W, 0402	MC00625W040211R60
Resistor, Thick Film, 1R8, 1%, 0.0625W, 0402	MC00625W040211R80
Resistor, Thick Film, 200K, 1%, 0.0625W, 0402	MC00625W04021200K
Resistor, Thick Film, 200R, 1%, 0.0625W, 0402	MC00625W04021200R
Resistor, Thick Film, 205K, 1%, 0.0625W, 0402	MC00625W04021205K
Resistor, Thick Film, 205R, 1%, 0.0625W, 0402	MC00625W04021205R
Resistor, Thick Film, 20K, 1%, 0.0625W, 0402	MC00625W0402120K
Resistor, Thick Film, 20K5, 1%, 0.0625W, 0402	MC00625W0402120K5
Resistor, Thick Film, 20R, 1%, 0.0625W, 0402	MC00625W0402120R
Resistor, Thick Film, 20R5, 1%, 0.0625W, 0402	MC00625W0402120R5
Resistor, Thick Film, 210K, 1%, 0.0625W, 0402	MC00625W04021210K
Resistor, Thick Film, 210R, 1%, 0.0625W, 0402	MC00625W04021210R
Resistor, Thick Film, 215K, 1%, 0.0625W, 0402	MC00625W04021215K
Resistor, Thick Film, 215K, 1%, 0.0625W, 0402	MC00625W04021215K..
Resistor, Thick Film, 215R, 1%, 0.0625W, 0402	MC00625W04021215R

Description	Part Number
Resistor, Thick Film, 21K, 1%, 0.0625W, 0402	MC00625W0402121K
Resistor, Thick Film, 21K5, 1%, 0.0625W, 0402	MC00625W0402121K5
Resistor, Thick Film, 21R, 1%, 0.0625W, 0402	MC00625W0402121R
Resistor, Thick Film, 21R5, 1%, 0.0625W, 0402	MC00625W0402121R5
Resistor, Thick Film, 220K, 1%, 0.0625W, 0402	MC00625W04021220K
Resistor, Thick Film, 220R, 1%, 0.0625W, 0402	MC00625W04021220R
Resistor, Thick Film, 221K, 1%, 0.0625W, 0402	MC00625W04021221K
Resistor, Thick Film, 221R, 1%, 0.0625W, 0402	MC00625W04021221R
Resistor, Thick Film, 226K, 1%, 0.0625W, 0402	MC00625W04021226K
Resistor, Thick Film, 226R, 1%, 0.0625W, 0402	MC00625W04021226R
Resistor, Thick Film, 22K, 1%, 0.0625W, 0402	MC00625W0402122K
Resistor, Thick Film, 22K1, 1%, 0.0625W, 0402	MC00625W0402122K1
Resistor, Thick Film, 22K6, 1%, 0.0625W, 0402	MC00625W0402122K6
Resistor, Thick Film, 22R, 1%, 0.0625W, 0402	MC00625W0402122R
Resistor, Thick Film, 22R1, 1%, 0.0625W, 0402	MC00625W0402122R1
Resistor, Thick Film, 22R6, 1%, 0.0625W, 0402	MC00625W0402122R6
Resistor, Thick Film, 232K, 1%, 0.0625W, 0402	MC00625W04021232K
Resistor, Thick Film, 232R, 1%, 0.0625W, 0402	MC00625W04021232R
Resistor, Thick Film, 237K, 1%, 0.0625W, 0402	MC00625W04021237K
Resistor, Thick Film, 237R, 1%, 0.0625W, 0402	MC00625W04021237R
Resistor, Thick Film, 23K2, 1%, 0.0625W, 0402	MC00625W0402123K2
Resistor, Thick Film, 23K7, 1%, 0.0625W, 0402	MC00625W0402123K7
Resistor, Thick Film, 23R7, 1%, 0.0625W, 0402	MC00625W0402123R7
Resistor, Thick Film, 240K, 1%, 0.0625W, 0402	MC00625W04021240K
Resistor, Thick Film, 240R, 1%, 0.0625W, 0402	MC00625W04021240R
Resistor, Thick Film, 240R, 1%, 0.0625W, 0402	MC00625W04021240R..
Resistor, Thick Film, 243K, 1%, 0.0625W, 0402	MC00625W04021243K
Resistor, Thick Film, 243R, 1%, 0.0625W, 0402	MC00625W04021243R
Resistor, Thick Film, 249K, 1%, 0.0625W, 0402	MC00625W04021249K
Resistor, Thick Film, 249R, 1%, 0.0625W, 0402	MC00625W04021249R
Resistor, Thick Film, 24K, 1%, 0.0625W, 0402	MC00625W0402124K
Resistor, Thick Film, 24K3, 1%, 0.0625W, 0402	MC00625W0402124K3
Resistor, Thick Film, 24K9, 1%, 0.0625W, 0402	MC00625W0402124K9
Resistor, Thick Film, 24R, 1%, 0.0625W, 0402	MC00625W0402124R
Resistor, Thick Film, 24R3, 1%, 0.0625W, 0402	MC00625W0402124R3
Resistor, Thick Film, 24R9, 1%, 0.0625W, 0402	MC00625W0402124R9
Resistor, Thick Film, 255K, 1%, 0.0625W, 0402	MC00625W04021255K
Resistor, Thick Film, 255R, 1%, 0.0625W, 0402	MC00625W04021255R
Resistor, Thick Film, 25K5, 1%, 0.0625W, 0402	MC00625W0402125K5
Resistor, Thick Film, 25R5, 1%, 0.0625W, 0402	MC00625W0402125R5
Resistor, Thick Film, 261K, 1%, 0.0625W, 0402	MC00625W04021261K
Resistor, Thick Film, 261R, 1%, 0.0625W, 0402	MC00625W04021261R
Resistor, Thick Film, 267K, 1%, 0.0625W, 0402	MC00625W04021267K

www.element14.com  
www.farnell.com  
www.newark.com



# Thick Film Chip Resistor 0402



Description	Part Number
Resistor, Thick Film, 267R, 1%, 0.0625W, 0402	MC00625W04021267R
Resistor, Thick Film, 26K1, 1%, 0.0625W, 0402	MC00625W0402126K1
Resistor, Thick Film, 26K7, 1%, 0.0625W, 0402	MC00625W0402126K7
Resistor, Thick Film, 26R1, 1%, 0.0625W, 0402	MC00625W0402126R1
Resistor, Thick Film, 270K, 1%, 0.0625W, 0402	MC00625W04021270K
Resistor, Thick Film, 270R, 1%, 0.0625W, 0402	MC00625W04021270R
Resistor, Thick Film, 274K, 1%, 0.0625W, 0402	MC00625W04021274K
Resistor, Thick Film, 274R, 1%, 0.0625W, 0402	MC00625W04021274R
Resistor, Thick Film, 27K, 1%, 0.0625W, 0402	MC00625W0402127K
Resistor, Thick Film, 27K4, 1%, 0.0625W, 0402	MC00625W0402127K4
Resistor, Thick Film, 27R, 1%, 0.0625W, 0402	MC00625W0402127R
Resistor, Thick Film, 27R4, 1%, 0.0625W, 0402	MC00625W0402127R4
Resistor, Thick Film, 280R, 1%, 0.0625W, 0402	MC00625W04021280R
Resistor, Thick Film, 287K, 1%, 0.0625W, 0402	MC00625W04021287K
Resistor, Thick Film, 287R, 1%, 0.0625W, 0402	MC00625W04021287R
Resistor, Thick Film, 28K, 1%, 0.0625W, 0402	MC00625W0402128K
Resistor, Thick Film, 28K7, 1%, 0.0625W, 0402	MC00625W0402128K7
Resistor, Thick Film, 28R, 1%, 0.0625W, 0402	MC00625W0402128R
Resistor, Thick Film, 28R7, 1%, 0.0625W, 0402	MC00625W0402128R7
Resistor, Thick Film, 294K, 1%, 0.0625W, 0402	MC00625W04021294K
Resistor, Thick Film, 294R, 1%, 0.0625W, 0402	MC00625W04021294R
Resistor, Thick Film, 29K4, 1%, 0.0625W, 0402	MC00625W0402129K4
Resistor, Thick Film, 2K, 1%, 0.0625W, 0402	MC00625W040212K
Resistor, Thick Film, 2K05, 1%, 0.0625W, 0402	MC00625W040212K05
Resistor, Thick Film, 2K1, 1%, 0.0625W, 0402	MC00625W040212K1
Resistor, Thick Film, 2K15, 1%, 0.0625W, 0402	MC00625W040212K15
Resistor, Thick Film, 2K2, 1%, 0.0625W, 0402	MC00625W040212K2
Resistor, Thick Film, 2K21, 1%, 0.0625W, 0402	MC00625W040212K21
Resistor, Thick Film, 2K26, 1%, 0.0625W, 0402	MC00625W040212K26
Resistor, Thick Film, 2K32, 1%, 0.0625W, 0402	MC00625W040212K32
Resistor, Thick Film, 2K37, 1%, 0.0625W, 0402	MC00625W040212K37
Resistor, Thick Film, 2K4, 1%, 0.0625W, 0402	MC00625W040212K4
Resistor, Thick Film, 2K43, 1%, 0.0625W, 0402	MC00625W040212K43
Resistor, Thick Film, 2K49, 1%, 0.0625W, 0402	MC00625W040212K49
Resistor, Thick Film, 2K55, 1%, 0.0625W, 0402	MC00625W040212K55
Resistor, Thick Film, 2K61, 1%, 0.0625W, 0402	MC00625W040212K61
Resistor, Thick Film, 2K67, 1%, 0.0625W, 0402	MC00625W040212K67
Resistor, Thick Film, 2K7, 1%, 0.0625W, 0402	MC00625W040212K7
Resistor, Thick Film, 2K74, 1%, 0.0625W, 0402	MC00625W040212K74
Resistor, Thick Film, 2K8, 1%, 0.0625W, 0402	MC00625W040212K8
Resistor, Thick Film, 2K87, 1%, 0.0625W, 0402	MC00625W040212K87
Resistor, Thick Film, 2K94, 1%, 0.0625W, 0402	MC00625W040212K94
Resistor, Thick Film, 2M, 1%, 0.0625W, 0402	MC00625W040212M00

Description	Part Number
Resistor, Thick Film, 2M2, 1%, 0.0625W, 0402	MC00625W040212M20
Resistor, Thick Film, 2M4, 1%, 0.0625W, 0402	MC00625W040212M40
Resistor, Thick Film, 2M7, 1%, 0.0625W, 0402	MC00625W040212M70
Resistor, Thick Film, 2M87, 1%, 0.0625W, 0402	MC00625W040212M87
Resistor, Thick Film, 2R, 1%, 0.0625W, 0402	MC00625W040212R0
Resistor, Thick Film, 2R2, 1%, 0.0625W, 0402	MC00625W040212R2
Resistor, Thick Film, 2R4, 1%, 0.0625W, 0402	MC00625W040212R40
Resistor, Thick Film, 2R49, 1%, 0.0625W, 0402	MC00625W040212R49
Resistor, Thick Film, 2R61, 1%, 0.0625W, 0402	MC00625W040212R61
Resistor, Thick Film, 2R7, 1%, 0.0625W, 0402	MC00625W040212R70
Resistor, Thick Film, 2R74, 1%, 0.0625W, 0402	MC00625W040212R74
Resistor, Thick Film, 300K, 1%, 0.0625W, 0402	MC00625W04021300K
Resistor, Thick Film, 300R, 1%, 0.0625W, 0402	MC00625W04021300R
Resistor, Thick Film, 301K, 1%, 0.0625W, 0402	MC00625W04021301K
Resistor, Thick Film, 301R, 1%, 0.0625W, 0402	MC00625W04021301R
Resistor, Thick Film, 309K, 1%, 0.0625W, 0402	MC00625W04021309K
Resistor, Thick Film, 309R, 1%, 0.0625W, 0402	MC00625W04021309R
Resistor, Thick Film, 30K, 1%, 0.0625W, 0402	MC00625W0402130K
Resistor, Thick Film, 30K1, 1%, 0.0625W, 0402	MC00625W0402130K1
Resistor, Thick Film, 30K9, 1%, 0.0625W, 0402	MC00625W0402130K9
Resistor, Thick Film, 30R, 1%, 0.0625W, 0402	MC00625W0402130R
Resistor, Thick Film, 30R1, 1%, 0.0625W, 0402	MC00625W0402130R1
Resistor, Thick Film, 30R9, 1%, 0.0625W, 0402	MC00625W0402130R9
Resistor, Thick Film, 316K, 1%, 0.0625W, 0402	MC00625W04021316K
Resistor, Thick Film, 316R, 1%, 0.0625W, 0402	MC00625W04021316R
Resistor, Thick Film, 31K6, 1%, 0.0625W, 0402	MC00625W0402131K6
Resistor, Thick Film, 31R6, 1%, 0.0625W, 0402	MC00625W0402131R6
Resistor, Thick Film, 324K, 1%, 0.0625W, 0402	MC00625W04021324K
Resistor, Thick Film, 324R, 1%, 0.0625W, 0402	MC00625W04021324R
Resistor, Thick Film, 32K4, 1%, 0.0625W, 0402	MC00625W0402132K4
Resistor, Thick Film, 330K, 1%, 0.0625W, 0402	MC00625W04021330K
Resistor, Thick Film, 330R, 1%, 0.0625W, 0402	MC00625W04021330R
Resistor, Thick Film, 332K, 1%, 0.0625W, 0402	MC00625W04021332K
Resistor, Thick Film, 332R, 1%, 0.0625W, 0402	MC00625W04021332R
Resistor, Thick Film, 33K, 1%, 0.0625W, 0402	MC00625W0402133K
Resistor, Thick Film, 33K2, 1%, 0.0625W, 0402	MC00625W0402133K2
Resistor, Thick Film, 33R, 1%, 0.0625W, 0402	MC00625W0402133R
Resistor, Thick Film, 33R2, 1%, 0.0625W, 0402	MC00625W0402133R2
Resistor, Thick Film, 340K, 1%, 0.0625W, 0402	MC00625W04021340K
Resistor, Thick Film, 340R, 1%, 0.0625W, 0402	MC00625W04021340R
Resistor, Thick Film, 348K, 1%, 0.0625W, 0402	MC00625W04021348K
Resistor, Thick Film, 348R, 1%, 0.0625W, 0402	MC00625W04021348R
Resistor, Thick Film, 34K, 1%, 0.0625W, 0402	MC00625W0402134K

www.element14.com  
www.farnell.com  
www.newark.com



# Thick Film Chip Resistor 0402



Description	Part Number	Description	Part Number
Resistor, Thick Film, 34K8, 1%, 0.0625W, 0402	MC00625W0402134K8	Resistor, Thick Film, 3K74, 1%, 0.0625W, 0402	MC00625W040213K74
Resistor, Thick Film, 34R8, 1%, 0.0625W, 0402	MC00625W0402134R8	Resistor, Thick Film, 3K83, 1%, 0.0625W, 0402	MC00625W040213K83
Resistor, Thick Film, 357K, 1%, 0.0625W, 0402	MC00625W04021357K	Resistor, Thick Film, 3K9, 1%, 0.0625W, 0402	MC00625W040213K9
Resistor, Thick Film, 357R, 1%, 0.0625W, 0402	MC00625W04021357R	Resistor, Thick Film, 3K92, 1%, 0.0625W, 0402	MC00625W040213K92
Resistor, Thick Film, 35K7, 1%, 0.0625W, 0402	MC00625W0402135K7	Resistor, Thick Film, 3M, 1%, 0.0625W, 0402	MC00625W040213M00
Resistor, Thick Film, 35R7, 1%, 0.0625W, 0402	MC00625W0402135R7	Resistor, Thick Film, 3M01, 1%, 0.0625W, 0402	MC00625W040213M01
Resistor, Thick Film, 360K, 1%, 0.0625W, 0402	MC00625W04021360K	Resistor, Thick Film, 3M3, 1%, 0.0625W, 0402	MC00625W040213M30
Resistor, Thick Film, 360R, 1%, 0.0625W, 0402	MC00625W04021360R	Resistor, Thick Film, 3M32, 1%, 0.0625W, 0402	MC00625W040213M32
Resistor, Thick Film, 365K, 1%, 0.0625W, 0402	MC00625W04021365K	Resistor, Thick Film, 3M6, 1%, 0.0625W, 0402	MC00625W040213M60
Resistor, Thick Film, 365R, 1%, 0.0625W, 0402	MC00625W04021365R	Resistor, Thick Film, 3M9, 1%, 0.0625W, 0402	MC00625W040213M90
Resistor, Thick Film, 36K, 1%, 0.0625W, 0402	MC00625W0402136K	Resistor, Thick Film, 3R, 1%, 0.0625W, 0402	MC00625W040213R0
Resistor, Thick Film, 36K5, 1%, 0.0625W, 0402	MC00625W0402136K5	Resistor, Thick Film, 3R16, 1%, 0.0625W, 0402	MC00625W040213R16
Resistor, Thick Film, 36R, 1%, 0.0625W, 0402	MC00625W0402136R	Resistor, Thick Film, 3R3, 1%, 0.0625W, 0402	MC00625W040213R3
Resistor, Thick Film, 36R5, 1%, 0.0625W, 0402	MC00625W0402136R5	Resistor, Thick Film, 3R32, 1%, 0.0625W, 0402	MC00625W040213R32
Resistor, Thick Film, 374K, 1%, 0.0625W, 0402	MC00625W04021374K	Resistor, Thick Film, 3R6, 1%, 0.0625W, 0402	MC00625W040213R60
Resistor, Thick Film, 37K4, 1%, 0.0625W, 0402	MC00625W0402137K4	Resistor, Thick Film, 3R83, 1%, 0.0625W, 0402	MC00625W040213R83
Resistor, Thick Film, 37R4, 1%, 0.0625W, 0402	MC00625W0402137R4	Resistor, Thick Film, 3R9, 1%, 0.0625W, 0402	MC00625W040213R90
Resistor, Thick Film, 383K, 1%, 0.0625W, 0402	MC00625W04021383K	Resistor, Thick Film, 402K, 1%, 0.0625W, 0402	MC00625W04021402K
Resistor, Thick Film, 383R, 1%, 0.0625W, 0402	MC00625W04021383R	Resistor, Thick Film, 402R, 1%, 0.0625W, 0402	MC00625W04021402R
Resistor, Thick Film, 383R, 1%, 0.0625W, 0402	MC00625W04021383R..	Resistor, Thick Film, 40K2, 1%, 0.0625W, 0402	MC00625W0402140K2
Resistor, Thick Film, 38K3, 1%, 0.0625W, 0402	MC00625W0402138K3	Resistor, Thick Film, 40R2, 1%, 0.0625W, 0402	MC00625W0402140R2
Resistor, Thick Film, 38R3, 1%, 0.0625W, 0402	MC00625W0402138R3	Resistor, Thick Film, 412K, 1%, 0.0625W, 0402	MC00625W04021412K
Resistor, Thick Film, 390K, 1%, 0.0625W, 0402	MC00625W04021390K	Resistor, Thick Film, 412R, 1%, 0.0625W, 0402	MC00625W04021412R
Resistor, Thick Film, 390R, 1%, 0.0625W, 0402	MC00625W04021390R	Resistor, Thick Film, 41K2, 1%, 0.0625W, 0402	MC00625W0402141K2
Resistor, Thick Film, 392K, 1%, 0.0625W, 0402	MC00625W04021392K	Resistor, Thick Film, 422K, 1%, 0.0625W, 0402	MC00625W04021422K
Resistor, Thick Film, 392R, 1%, 0.0625W, 0402	MC00625W04021392R	Resistor, Thick Film, 422R, 1%, 0.0625W, 0402	MC00625W04021422R
Resistor, Thick Film, 39K, 1%, 0.0625W, 0402	MC00625W0402139K	Resistor, Thick Film, 42K2, 1%, 0.0625W, 0402	MC00625W0402142K2
Resistor, Thick Film, 39K2, 1%, 0.0625W, 0402	MC00625W0402139K2	Resistor, Thick Film, 42R2, 1%, 0.0625W, 0402	MC00625W0402142R2
Resistor, Thick Film, 39R, 1%, 0.0625W, 0402	MC00625W0402139R	Resistor, Thick Film, 430K, 1%, 0.0625W, 0402	MC00625W04021430K
Resistor, Thick Film, 39R2, 1%, 0.0625W, 0402	MC00625W0402139R2	Resistor, Thick Film, 430R, 1%, 0.0625W, 0402	MC00625W04021430R
Resistor, Thick Film, 3K, 1%, 0.0625W, 0402	MC00625W040213K	Resistor, Thick Film, 432K, 1%, 0.0625W, 0402	MC00625W04021432K
Resistor, Thick Film, 3K01, 1%, 0.0625W, 0402	MC00625W040213K01	Resistor, Thick Film, 432R, 1%, 0.0625W, 0402	MC00625W04021432R
Resistor, Thick Film, 3K09, 1%, 0.0625W, 0402	MC00625W040213K09	Resistor, Thick Film, 43K, 1%, 0.0625W, 0402	MC00625W0402143K
Resistor, Thick Film, 3K16, 1%, 0.0625W, 0402	MC00625W040213K16	Resistor, Thick Film, 43K2, 1%, 0.0625W, 0402	MC00625W0402143K2
Resistor, Thick Film, 3K24, 1%, 0.0625W, 0402	MC00625W040213K24	Resistor, Thick Film, 43R, 1%, 0.0625W, 0402	MC00625W0402143R
Resistor, Thick Film, 3K3, 1%, 0.0625W, 0402	MC00625W040213K3	Resistor, Thick Film, 442K, 1%, 0.0625W, 0402	MC00625W04021442K
Resistor, Thick Film, 3K32, 1%, 0.0625W, 0402	MC00625W040213K32	Resistor, Thick Film, 442R, 1%, 0.0625W, 0402	MC00625W04021442R
Resistor, Thick Film, 3K32, 1%, 0.0625W, 0402	MC00625W040213K32..	Resistor, Thick Film, 44K2, 1%, 0.0625W, 0402	MC00625W0402144K2
Resistor, Thick Film, 3K4, 1%, 0.0625W, 0402	MC00625W040213K4	Resistor, Thick Film, 44R2, 1%, 0.0625W, 0402	MC00625W0402144R2
Resistor, Thick Film, 3K48, 1%, 0.0625W, 0402	MC00625W040213K48	Resistor, Thick Film, 453K, 1%, 0.0625W, 0402	MC00625W04021453K
Resistor, Thick Film, 3K57, 1%, 0.0625W, 0402	MC00625W040213K57	Resistor, Thick Film, 453R, 1%, 0.0625W, 0402	MC00625W04021453R
Resistor, Thick Film, 3K6, 1%, 0.0625W, 0402	MC00625W040213K6	Resistor, Thick Film, 45K3, 1%, 0.0625W, 0402	MC00625W0402145K3
Resistor, Thick Film, 3K65, 1%, 0.0625W, 0402	MC00625W040213K65	Resistor, Thick Film, 45R3, 1%, 0.0625W, 0402	MC00625W0402145R3

www.element14.com  
www.farnell.com  
www.newark.com



# Thick Film Chip Resistor 0402



Description	Part Number
Resistor, Thick Film, 464K, 1%, 0.0625W, 0402	MC00625W04021464K
Resistor, Thick Film, 464R, 1%, 0.0625W, 0402	MC00625W04021464R
Resistor, Thick Film, 46K4, 1%, 0.0625W, 0402	MC00625W0402146K4
Resistor, Thick Film, 46R4, 1%, 0.0625W, 0402	MC00625W0402146R4
Resistor, Thick Film, 470K, 1%, 0.0625W, 0402	MC00625W04021470K
Resistor, Thick Film, 470R, 1%, 0.0625W, 0402	MC00625W04021470R
Resistor, Thick Film, 475K, 1%, 0.0625W, 0402	MC00625W04021475K
Resistor, Thick Film, 475R, 1%, 0.0625W, 0402	MC00625W04021475R
Resistor, Thick Film, 47K, 1%, 0.0625W, 0402	MC00625W0402147K
Resistor, Thick Film, 47K5, 1%, 0.0625W, 0402	MC00625W0402147K5
Resistor, Thick Film, 47R, 1%, 0.0625W, 0402	MC00625W0402147R
Resistor, Thick Film, 47R5, 1%, 0.0625W, 0402	MC00625W0402147R5
Resistor, Thick Film, 487K, 1%, 0.0625W, 0402	MC00625W04021487K
Resistor, Thick Film, 487R, 1%, 0.0625W, 0402	MC00625W04021487R
Resistor, Thick Film, 48K7, 1%, 0.0625W, 0402	MC00625W0402148K7
Resistor, Thick Film, 48R7, 1%, 0.0625W, 0402	MC00625W0402148R7
Resistor, Thick Film, 499K, 1%, 0.0625W, 0402	MC00625W04021499K
Resistor, Thick Film, 499R, 1%, 0.0625W, 0402	MC00625W04021499R
Resistor, Thick Film, 49K9, 1%, 0.0625W, 0402	MC00625W0402149K9
Resistor, Thick Film, 49R9, 1%, 0.0625W, 0402	MC00625W0402149R9
Resistor, Thick Film, 4K02, 1%, 0.0625W, 0402	MC00625W040214K02
Resistor, Thick Film, 4K12, 1%, 0.0625W, 0402	MC00625W040214K12
Resistor, Thick Film, 4K22, 1%, 0.0625W, 0402	MC00625W040214K22
Resistor, Thick Film, 4K3, 1%, 0.0625W, 0402	MC00625W040214K3
Resistor, Thick Film, 4K32, 1%, 0.0625W, 0402	MC00625W040214K32
Resistor, Thick Film, 4K42, 1%, 0.0625W, 0402	MC00625W040214K42
Resistor, Thick Film, 4K53, 1%, 0.0625W, 0402	MC00625W040214K53
Resistor, Thick Film, 4K64, 1%, 0.0625W, 0402	MC00625W040214K64
Resistor, Thick Film, 4K7, 1%, 0.0625W, 0402	MC00625W040214K7
Resistor, Thick Film, 4K75, 1%, 0.0625W, 0402	MC00625W040214K75
Resistor, Thick Film, 4K87, 1%, 0.0625W, 0402	MC00625W040214K87
Resistor, Thick Film, 4K99, 1%, 0.0625W, 0402	MC00625W040214K99
Resistor, Thick Film, 4M02, 1%, 0.0625W, 0402	MC00625W040214M02
Resistor, Thick Film, 4M3, 1%, 0.0625W, 0402	MC00625W040214M30
Resistor, Thick Film, 4M7, 1%, 0.0625W, 0402	MC00625W040214M70
Resistor, Thick Film, 4M87, 1%, 0.0625W, 0402	MC00625W040214M87
Resistor, Thick Film, 4R22, 1%, 0.0625W, 0402	MC00625W040214R22
Resistor, Thick Film, 4R3, 1%, 0.0625W, 0402	MC00625W040214R30
Resistor, Thick Film, 4R7, 1%, 0.0625W, 0402	MC00625W040214R7
Resistor, Thick Film, 510K, 1%, 0.0625W, 0402	MC00625W04021510K
Resistor, Thick Film, 510R, 1%, 0.0625W, 0402	MC00625W04021510R
Resistor, Thick Film, 511K, 1%, 0.0625W, 0402	MC00625W04021511K
Resistor, Thick Film, 511R, 1%, 0.0625W, 0402	MC00625W04021511R

Description	Part Number
Resistor, Thick Film, 51K, 1%, 0.0625W, 0402	MC00625W0402151K
Resistor, Thick Film, 51K1, 1%, 0.0625W, 0402	MC00625W0402151K1
Resistor, Thick Film, 51R, 1%, 0.0625W, 0402	MC00625W0402151R
Resistor, Thick Film, 51R1, 1%, 0.0625W, 0402	MC00625W0402151R1
Resistor, Thick Film, 523K, 1%, 0.0625W, 0402	MC00625W04021523K
Resistor, Thick Film, 523R, 1%, 0.0625W, 0402	MC00625W04021523R
Resistor, Thick Film, 52K3, 1%, 0.0625W, 0402	MC00625W0402152K3
Resistor, Thick Film, 52R3, 1%, 0.0625W, 0402	MC00625W0402152R3
Resistor, Thick Film, 536K, 1%, 0.0625W, 0402	MC00625W04021536K
Resistor, Thick Film, 536R, 1%, 0.0625W, 0402	MC00625W04021536R
Resistor, Thick Film, 53K6, 1%, 0.0625W, 0402	MC00625W0402153K6
Resistor, Thick Film, 53R6, 1%, 0.0625W, 0402	MC00625W0402153R6
Resistor, Thick Film, 549K, 1%, 0.0625W, 0402	MC00625W04021549K
Resistor, Thick Film, 549R, 1%, 0.0625W, 0402	MC00625W04021549R
Resistor, Thick Film, 54K9, 1%, 0.0625W, 0402	MC00625W0402154K9
Resistor, Thick Film, 54R9, 1%, 0.0625W, 0402	MC00625W0402154R9
Resistor, Thick Film, 560K, 1%, 0.0625W, 0402	MC00625W04021560K
Resistor, Thick Film, 560R, 1%, 0.0625W, 0402	MC00625W04021560R
Resistor, Thick Film, 562K, 1%, 0.0625W, 0402	MC00625W04021562K
Resistor, Thick Film, 562R, 1%, 0.0625W, 0402	MC00625W04021562R
Resistor, Thick Film, 56K, 1%, 0.0625W, 0402	MC00625W0402156K
Resistor, Thick Film, 56K2, 1%, 0.0625W, 0402	MC00625W0402156K2
Resistor, Thick Film, 56R, 1%, 0.0625W, 0402	MC00625W0402156R
Resistor, Thick Film, 56R2, 1%, 0.0625W, 0402	MC00625W0402156R2
Resistor, Thick Film, 576K, 1%, 0.0625W, 0402	MC00625W04021576K
Resistor, Thick Film, 576R, 1%, 0.0625W, 0402	MC00625W04021576R
Resistor, Thick Film, 57K6, 1%, 0.0625W, 0402	MC00625W0402157K6
Resistor, Thick Film, 57R6, 1%, 0.0625W, 0402	MC00625W0402157R6
Resistor, Thick Film, 590K, 1%, 0.0625W, 0402	MC00625W04021590K
Resistor, Thick Film, 590R, 1%, 0.0625W, 0402	MC00625W04021590R
Resistor, Thick Film, 59K, 1%, 0.0625W, 0402	MC00625W0402159K
Resistor, Thick Film, 59R, 1%, 0.0625W, 0402	MC00625W0402159R
Resistor, Thick Film, 5K1, 1%, 0.0625W, 0402	MC00625W040215K1
Resistor, Thick Film, 5K11, 1%, 0.0625W, 0402	MC00625W040215K11
Resistor, Thick Film, 5K23, 1%, 0.0625W, 0402	MC00625W040215K23
Resistor, Thick Film, 5K36, 1%, 0.0625W, 0402	MC00625W040215K36
Resistor, Thick Film, 5K49, 1%, 0.0625W, 0402	MC00625W040215K49
Resistor, Thick Film, 5K6, 1%, 0.0625W, 0402	MC00625W040215K6
Resistor, Thick Film, 5K62, 1%, 0.0625W, 0402	MC00625W040215K62
Resistor, Thick Film, 5K76, 1%, 0.0625W, 0402	MC00625W040215K76
Resistor, Thick Film, 5K9, 1%, 0.0625W, 0402	MC00625W040215K9
Resistor, Thick Film, 5M1, 1%, 0.0625W, 0402	MC00625W040215M10
Resistor, Thick Film, 5M36, 1%, 0.0625W, 0402	MC00625W040215M36

www.element14.com  
www.farnell.com  
www.newark.com



# Thick Film Chip Resistor 0402



Description	Part Number	Description	Part Number
Resistor, Thick Film, 5M6, 1%, 0.0625W, 0402	MC00625W040215M60	Resistor, Thick Film, 6K2, 1%, 0.0625W, 0402	MC00625W040216K2
Resistor, Thick Film, 5R1, 1%, 0.0625W, 0402	MC00625W040215R10	Resistor, Thick Film, 6K34, 1%, 0.0625W, 0402	MC00625W040216K34
Resistor, Thick Film, 5R11, 1%, 0.0625W, 0402	MC00625W040215R11	Resistor, Thick Film, 6K49, 1%, 0.0625W, 0402	MC00625W040216K49
Resistor, Thick Film, 5R36, 1%, 0.0625W, 0402	MC00625W040215R36	Resistor, Thick Film, 6K65, 1%, 0.0625W, 0402	MC00625W040216K65
Resistor, Thick Film, 5R6, 1%, 0.0625W, 0402	MC00625W040215R60	Resistor, Thick Film, 6K8, 1%, 0.0625W, 0402	MC00625W040216K8
Resistor, Thick Film, 5R62, 1%, 0.0625W, 0402	MC00625W040215R62	Resistor, Thick Film, 6K81, 1%, 0.0625W, 0402	MC00625W040216K81
Resistor, Thick Film, 604K, 1%, 0.0625W, 0402	MC00625W04021604K	Resistor, Thick Film, 6K98, 1%, 0.0625W, 0402	MC00625W040216K98
Resistor, Thick Film, 604R, 1%, 0.0625W, 0402	MC00625W04021604R	Resistor, Thick Film, 6M2, 1%, 0.0625W, 0402	MC00625W040216M20
Resistor, Thick Film, 60K4, 1%, 0.0625W, 0402	MC00625W0402160K4	Resistor, Thick Film, 6M8, 1%, 0.0625W, 0402	MC00625W040216M80
Resistor, Thick Film, 60R4, 1%, 0.0625W, 0402	MC00625W0402160R4	Resistor, Thick Film, 6R2, 1%, 0.0625W, 0402	MC00625W040216R20
Resistor, Thick Film, 619K, 1%, 0.0625W, 0402	MC00625W04021619K	Resistor, Thick Film, 6R8, 1%, 0.0625W, 0402	MC00625W040216R8
Resistor, Thick Film, 619R, 1%, 0.0625W, 0402	MC00625W04021619R	Resistor, Thick Film, 715K, 1%, 0.0625W, 0402	MC00625W04021715K
Resistor, Thick Film, 61K9, 1%, 0.0625W, 0402	MC00625W0402161K9	Resistor, Thick Film, 715R, 1%, 0.0625W, 0402	MC00625W04021715R
Resistor, Thick Film, 61R9, 1%, 0.0625W, 0402	MC00625W0402161R9	Resistor, Thick Film, 71K5, 1%, 0.0625W, 0402	MC00625W0402171K5
Resistor, Thick Film, 620K, 1%, 0.0625W, 0402	MC00625W04021620K	Resistor, Thick Film, 71R5, 1%, 0.0625W, 0402	MC00625W0402171R5
Resistor, Thick Film, 620R, 1%, 0.0625W, 0402	MC00625W04021620R	Resistor, Thick Film, 732K, 1%, 0.0625W, 0402	MC00625W04021732K
Resistor, Thick Film, 62K, 1%, 0.0625W, 0402	MC00625W0402162K	Resistor, Thick Film, 732R, 1%, 0.0625W, 0402	MC00625W04021732R
Resistor, Thick Film, 62R, 1%, 0.0625W, 0402	MC00625W0402162R	Resistor, Thick Film, 73K2, 1%, 0.0625W, 0402	MC00625W0402173K2
Resistor, Thick Film, 634K, 1%, 0.0625W, 0402	MC00625W04021634K	Resistor, Thick Film, 73R2, 1%, 0.0625W, 0402	MC00625W0402173R2
Resistor, Thick Film, 634R, 1%, 0.0625W, 0402	MC00625W04021634R	Resistor, Thick Film, 750K, 1%, 0.0625W, 0402	MC00625W04021750K
Resistor, Thick Film, 63K4, 1%, 0.0625W, 0402	MC00625W0402163K4	Resistor, Thick Film, 750R, 1%, 0.0625W, 0402	MC00625W04021750R
Resistor, Thick Film, 63R4, 1%, 0.0625W, 0402	MC00625W0402163R4	Resistor, Thick Film, 75K, 1%, 0.0625W, 0402	MC00625W0402175K
Resistor, Thick Film, 649K, 1%, 0.0625W, 0402	MC00625W04021649K	Resistor, Thick Film, 75R, 1%, 0.0625W, 0402	MC00625W0402175R
Resistor, Thick Film, 649R, 1%, 0.0625W, 0402	MC00625W04021649R	Resistor, Thick Film, 768K, 1%, 0.0625W, 0402	MC00625W04021768K
Resistor, Thick Film, 64K9, 1%, 0.0625W, 0402	MC00625W0402164K9	Resistor, Thick Film, 768R, 1%, 0.0625W, 0402	MC00625W04021768R
Resistor, Thick Film, 64R9, 1%, 0.0625W, 0402	MC00625W0402164R9	Resistor, Thick Film, 76K8, 1%, 0.0625W, 0402	MC00625W0402176K8
Resistor, Thick Film, 665K, 1%, 0.0625W, 0402	MC00625W04021665K	Resistor, Thick Film, 76R8, 1%, 0.0625W, 0402	MC00625W0402176R8
Resistor, Thick Film, 665R, 1%, 0.0625W, 0402	MC00625W04021665R	Resistor, Thick Film, 787K, 1%, 0.0625W, 0402	MC00625W04021787K
Resistor, Thick Film, 66K5, 1%, 0.0625W, 0402	MC00625W0402166K5	Resistor, Thick Film, 787R, 1%, 0.0625W, 0402	MC00625W04021787R
Resistor, Thick Film, 66R5, 1%, 0.0625W, 0402	MC00625W0402166R5	Resistor, Thick Film, 78K7, 1%, 0.0625W, 0402	MC00625W0402178K7
Resistor, Thick Film, 680K, 1%, 0.0625W, 0402	MC00625W04021680K	Resistor, Thick Film, 78R7, 1%, 0.0625W, 0402	MC00625W0402178R7
Resistor, Thick Film, 680R, 1%, 0.0625W, 0402	MC00625W04021680R	Resistor, Thick Film, 7K15, 1%, 0.0625W, 0402	MC00625W040217K15
Resistor, Thick Film, 681K, 1%, 0.0625W, 0402	MC00625W04021681K	Resistor, Thick Film, 7K32, 1%, 0.0625W, 0402	MC00625W040217K32
Resistor, Thick Film, 681R, 1%, 0.0625W, 0402	MC00625W04021681R	Resistor, Thick Film, 7K5, 1%, 0.0625W, 0402	MC00625W040217K5
Resistor, Thick Film, 68K, 1%, 0.0625W, 0402	MC00625W0402168K	Resistor, Thick Film, 7K68, 1%, 0.0625W, 0402	MC00625W040217K68
Resistor, Thick Film, 68K1, 1%, 0.0625W, 0402	MC00625W0402168K1	Resistor, Thick Film, 7K87, 1%, 0.0625W, 0402	MC00625W040217K87
Resistor, Thick Film, 68R, 1%, 0.0625W, 0402	MC00625W0402168R	Resistor, Thick Film, 7M5, 1%, 0.0625W, 0402	MC00625W040217M50
Resistor, Thick Film, 68R1, 1%, 0.0625W, 0402	MC00625W0402168R1	Resistor, Thick Film, 7R5, 1%, 0.0625W, 0402	MC00625W040217R50
Resistor, Thick Film, 698K, 1%, 0.0625W, 0402	MC00625W04021698K	Resistor, Thick Film, 806K, 1%, 0.0625W, 0402	MC00625W04021806K
Resistor, Thick Film, 698R, 1%, 0.0625W, 0402	MC00625W04021698R	Resistor, Thick Film, 806R, 1%, 0.0625W, 0402	MC00625W04021806R
Resistor, Thick Film, 69K8, 1%, 0.0625W, 0402	MC00625W0402169K8	Resistor, Thick Film, 80K6, 1%, 0.0625W, 0402	MC00625W0402180K6
Resistor, Thick Film, 6K04, 1%, 0.0625W, 0402	MC00625W040216K04	Resistor, Thick Film, 80R6, 1%, 0.0625W, 0402	MC00625W0402180R6
Resistor, Thick Film, 6K19, 1%, 0.0625W, 0402	MC00625W040216K19	Resistor, Thick Film, 820K, 1%, 0.0625W, 0402	MC00625W04021820K

www.element14.com  
www.farnell.com  
www.newark.com





# Thick Film Chip Resistor 0402



Description	Part Number
Resistor, Thick Film, 820R, 1%, 0.0625W, 0402	MC00625W04021820R
Resistor, Thick Film, 825K, 1%, 0.0625W, 0402	MC00625W04021825K
Resistor, Thick Film, 825R, 1%, 0.0625W, 0402	MC00625W04021825R
Resistor, Thick Film, 82K, 1%, 0.0625W, 0402	MC00625W0402182K
Resistor, Thick Film, 82K5, 1%, 0.0625W, 0402	MC00625W0402182K5
Resistor, Thick Film, 82R, 1%, 0.0625W, 0402	MC00625W0402182R
Resistor, Thick Film, 82R5, 1%, 0.0625W, 0402	MC00625W0402182R5
Resistor, Thick Film, 845K, 1%, 0.0625W, 0402	MC00625W04021845K
Resistor, Thick Film, 845R, 1%, 0.0625W, 0402	MC00625W04021845R
Resistor, Thick Film, 84K5, 1%, 0.0625W, 0402	MC00625W0402184K5
Resistor, Thick Film, 84R5, 1%, 0.0625W, 0402	MC00625W0402184R5
Resistor, Thick Film, 866K, 1%, 0.0625W, 0402	MC00625W04021866K
Resistor, Thick Film, 866R, 1%, 0.0625W, 0402	MC00625W04021866R
Resistor, Thick Film, 86K6, 1%, 0.0625W, 0402	MC00625W0402186K6
Resistor, Thick Film, 86R6, 1%, 0.0625W, 0402	MC00625W0402186R6
Resistor, Thick Film, 887K, 1%, 0.0625W, 0402	MC00625W04021887K
Resistor, Thick Film, 887R, 1%, 0.0625W, 0402	MC00625W04021887R
Resistor, Thick Film, 88K7, 1%, 0.0625W, 0402	MC00625W0402188K7
Resistor, Thick Film, 88R7, 1%, 0.0625W, 0402	MC00625W0402188R7
Resistor, Thick Film, 8K06, 1%, 0.0625W, 0402	MC00625W040218K06
Resistor, Thick Film, 8K2, 1%, 0.0625W, 0402	MC00625W040218K2
Resistor, Thick Film, 8K25, 1%, 0.0625W, 0402	MC00625W040218K25
Resistor, Thick Film, 8K45, 1%, 0.0625W, 0402	MC00625W040218K45
Resistor, Thick Film, 8K66, 1%, 0.0625W, 0402	MC00625W040218K66
Resistor, Thick Film, 8K87, 1%, 0.0625W, 0402	MC00625W040218K87
Resistor, Thick Film, 8M2, 1%, 0.0625W, 0402	MC00625W040218M20
Resistor, Thick Film, 8R2, 1%, 0.0625W, 0402	MC00625W040218R20

Description	Part Number
Resistor, Thick Film, 909K, 1%, 0.0625W, 0402	MC00625W04021909K
Resistor, Thick Film, 909R, 1%, 0.0625W, 0402	MC00625W04021909R
Resistor, Thick Film, 90K9, 1%, 0.0625W, 0402	MC00625W0402190K9
Resistor, Thick Film, 90R9, 1%, 0.0625W, 0402	MC00625W0402190R9
Resistor, Thick Film, 910K, 1%, 0.0625W, 0402	MC00625W04021910K
Resistor, Thick Film, 910R, 1%, 0.0625W, 0402	MC00625W04021910R
Resistor, Thick Film, 91K, 1%, 0.0625W, 0402	MC00625W0402191K
Resistor, Thick Film, 91R, 1%, 0.0625W, 0402	MC00625W0402191R
Resistor, Thick Film, 931K, 1%, 0.0625W, 0402	MC00625W04021931K
Resistor, Thick Film, 931R, 1%, 0.0625W, 0402	MC00625W04021931R
Resistor, Thick Film, 93K1, 1%, 0.0625W, 0402	MC00625W0402193K1
Resistor, Thick Film, 93R1, 1%, 0.0625W, 0402	MC00625W0402193R1
Resistor, Thick Film, 953K, 1%, 0.0625W, 0402	MC00625W04021953K
Resistor, Thick Film, 953R, 1%, 0.0625W, 0402	MC00625W04021953R
Resistor, Thick Film, 95K3, 1%, 0.0625W, 0402	MC00625W0402195K3
Resistor, Thick Film, 95R3, 1%, 0.0625W, 0402	MC00625W0402195R3
Resistor, Thick Film, 976K, 1%, 0.0625W, 0402	MC00625W04021976K
Resistor, Thick Film, 976R, 1%, 0.0625W, 0402	MC00625W04021976R
Resistor, Thick Film, 97K6, 1%, 0.0625W, 0402	MC00625W0402197K6
Resistor, Thick Film, 97R6, 1%, 0.0625W, 0402	MC00625W0402197R6
Resistor, Thick Film, 9K09, 1%, 0.0625W, 0402	MC00625W040219K09
Resistor, Thick Film, 9K1, 1%, 0.0625W, 0402	MC00625W040219K1
Resistor, Thick Film, 9K53, 1%, 0.0625W, 0402	MC00625W040219K53
Resistor, Thick Film, 9K76, 1%, 0.0625W, 0402	MC00625W040219K76
Resistor, Thick Film, 9M1, 1%, 0.0625W, 0402	MC00625W040219M10
Resistor, Thick Film, 9R1, 1%, 0.0625W, 0402	MC00625W040219R10

**Important Notice** : This data sheet and its contents (the "Information") belong to the members of the Premier Farnell group of companies (the "Group") or are licensed to it. No licence is granted for the use of it other than for information purposes in connection with the products to which it relates. No licence of any intellectual property rights is granted. The Information is subject to change without notice and replaces all data sheets previously supplied. The Information supplied is believed to be accurate but the Group assumes no responsibility for its accuracy or completeness, any error in or omission from it or for any use made of it. Users of this data sheet should check for themselves the Information and the suitability of the products for their purpose and not make any assumptions based on information included or omitted. Liability for loss or damage resulting from any reliance on the Information or use of it (including liability resulting from negligence or where the Group was aware of the possibility of such loss or damage arising) is excluded. This will not operate to limit or restrict the Group's liability for death or personal injury resulting from its negligence. Multicomp is the registered trademark of the Group. © Premier Farnell plc 2012.

www.element14.com  
www.farnell.com  
www.newark.com

