





## OYN-X | 9 PORT, 10AMP, 12V BOX PSU

### FEATURES:

- EXCLUSIVE A-DATA PRODUCT
- PTC Technology
- Built In Redundancy
- Lockable Box Cover
- LEDs for Each Input

### DIAGRAM:

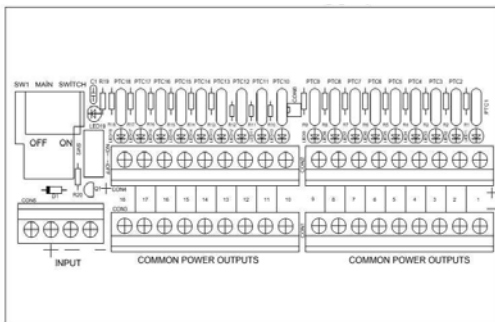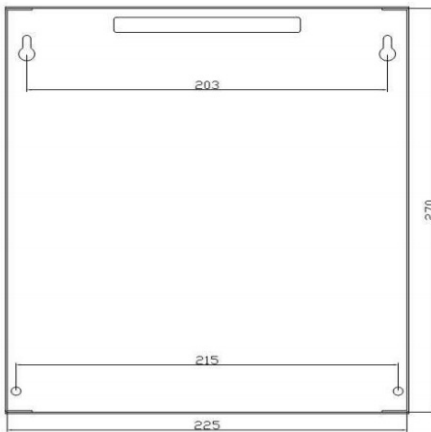

SPECIFICATION	PSU10-B
Work Temperature	0°C - +40°C
Storage Temperature	0°C - +70°C
Humidity	95RH
Elevation	≤3500m
<b>INPUT</b>	
Rated Input Voltage	220VAC
Input Voltage Range	190-264 VAC
Input Current	1.2A
Input Frequency Range	50-60Hz
Efficiency	>78%
<b>OUTPUT</b>	
Voltage without load	12VDC
Voltage regulation	12v -5%
Voltage with full load	12v -5% +5%
Current regulation	1%
Current Range	0.3-10A
Ripple and Noise	<100mV
Peak	<250mV
Start Time	<3s
Hold Up Time	<20ms
Over Current Protection	Rated Current 110% - 160%
Short Circuit Protection	Yes
Dimension	L275*W230*H90
Weight	2400g