

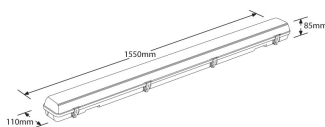
**Product Description:**

The IP65 LinearPac™ LED anti-corrosive is an ideal solution for both interior and exterior applications, allowing for an energy reduction compared to traditional linear fluorescent fittings. Popular for car parks, service areas, warehouses or retail applications, LinearPac creates the needed lighting levels while providing the energy savings desired.

**Product Image:****Product Features:**

- IP65 vandal resistant polycarbonate body and diffuser
- Efficacy up to 100 lm/W
- Ideal for both interior and exterior applications e.g. car parks
- Anti-tamper stainless steel clips supplied as standard
- Diffuser permanently attached by two clips for ease of installation
- Gear tray restraints for ease of installation and maintenance
- Through cable wiring with multiple drill-out conduit entry points for quick and easy installation
- Adjustable detection range, hold time and lux level settings for microwave version
- Microwave sensor detection range up to 12 metres
- IK08 impact rating

1500mm 54W IP65 Polycarbonate LED Anti-Corrosive

**Line Drawing Image****Product Specs:**

<b>Technology</b>	LED	<b>Number of LEDs</b>	320
<b>Lifetime L70 (hrs)</b>	40000	<b>Input Voltage</b>	100~240V AC
<b>Input Frequency</b>	50/60HZ	<b>Surge Protection (kV)</b>	1.5
<b>Power Factor</b>	0.95	<b>Dimmable</b>	No
<b>IP Rating</b>	IP65	<b>IK Rating</b>	IK08
<b>Optic Material</b>	PC	<b>Length (mm)</b>	1550
<b>Width (mm)</b>	110	<b>Height (mm)</b>	85
<b>Overall Height (mm)</b>	85		

## SKU Table and Ordering

Cat No.(SKU Code)	Wattage	Lumens	Lumens/Watt	Colour	Ra	Beam Angle	SDCM
EN-ANT1554/40	54W	5000lm	92.59	4000K	80	120°	6
EN-ANT1554/60	54W	5400lm	100	6000K	80	120°	6
EN-ANT1554/60EM	54W	5400lm	100	6000K	80	120°	6
EN-ANT1554/40EM	54W	5000lm	92.59	4000K	80	120°	6
EN-ANT1554/60MS	54W	5400lm	100	6000K	80	120°	6
EN-ANT1554/40MS	54W	5000lm	92.59	4000K	80	120°	6
EN-ANT1554/40EMR	54W	5000lm	92.59	4000K	80	120°	6
EN-ANT1554/60EMR	54W	5400lm	100	6000K	80	120°	6

## Compliance & Approvals:



## Warranty

Please contact Aurora for specifics concerning warranty on this product. The warranty is invalid in the case of improper use, installation, tampering, and removal of the Q.C. date label; installation in an improper working environment or installation not according to the current edition of the National Electric Code. Should this product fail during the warranty period it will be replaced free of charge, subject to the correct installation of the original product and subsequent return of the faulty unit. Aurora does not accept responsibility for any installation costs associated with the replacement of this product and Aurora reserves the right to alter specifications without prior notice.

### UK Enlite Sales

16 Alban Park Hatfield Road St. Albans  
AL4 0JJ

United Kingdom

Tel : +44 (0) 1727 83 66 11

Fax : +44 (0) 1727 83 66 22

### UK Enlite Distribution

Apex Park 6 Little Burrow Welwyn  
Garden City AL7 4SW

United Kingdom

Tel : +44 (0) 1707 35 18 20

Fax : +44 (0) 1727 35 18 21