



ELECTRONIC TECHNOLOGY SYSTEMS
DR. GENZ GMBH
COMPETENT BODY / ACCREDITED TEST HOUSE

EC DECLARATION OF CONFORMITY

This certifies that the following designated product

DC REGULATED POWER SUPPLY
MODEL No. : 650.652

(Product identification)

complies with the essential protection requirements of Council Directive 89/336/EEC on the approximation of the laws of the Member States relating to electromagnetic compatibility.

This declaration applies to all specimens manufactured in accordance with the attached manufacturing drawings which form part of this declaration.

Assessment of compliance of the product with the requirements relating to electromagnetic compatibility was based on the following standards:

EN 50081-1 /1993: EN 55014, EN 61000-3-2 /3
EN 50082-1 /1997: EN 55014-2 (EN 61000-4-2 /-4 /-5 /-6 /-11)

(Identification of regulations / standards)

This declaration is the responsibility of the manufacturer / importer

SKY TRONIC B.V.
MARCONISTRAAT 9 ,
7442 DD NIJVERDAL, THE NETHERLANDS

(Name / Address)



THIS DOC IS ONLY VALID IN CONNECTION WITH TEST REPORT NUMBER : G3M20110-1272-E-16

MANUFACTURER / IMPORTER

TEST LABORATORY

This is the result of test, that was carried out from the submitted type-samples of a product in conformity with the specification of the respective standards.
 The certificate holder has the right to fix the CE-mark for EMC on the product complying with the inspection sample.

(Date)

(Surname, forename)
 (Company stamp)



January 24, 2002

(Date)

Dr. Genz

Dr. Genz

ELECTRONIC TECHNOLOGY SYSTEMS DR. GENZ GMBH
 STORKOWER STRASSE 38C D-15526 REICHENWALDE H. BERLIN GERMANY PHONE + 49 33631-858 100 FAX + 49 33631 858 660



**ELECTRONIC TECHNOLOGY SYSTEMS
DR. GENZ GMBH**

**ACCREDITED TEST HOUSE - LVD, GS-MARK, TOY SAFETY -
NOTIFIED BODY / GS-CERTIFICATION BODY**

EC DECLARATION OF CONFORMITY

- LOW VOLTAGE DIRECTIVE -

Page 1 of 2

This certifies that the following designated product

**DC REGULATED POWER SUPPLY
MODEL NO. : 650.652**

(Product identification)

complies with the requirements of the European Community Directive 73/23/EEC and 93/68/EEC. This declaration applies to all specimens manufactured in accordance with the attached manufacturing drawings which form part of this declaration. Assessment of compliance of the product with the requirements relating to the Low Voltage Directive (LVD) was based on the following standards:

**EN 60950: 2000 (3RD EDITION)
EN 61204:1995**

(Identification of regulations / standards)

This declaration is the responsibility of the manufacturer / importer

**SKY TRONIC B.V.
MARCONISTRAAT 9
7442 DD NIJVERDAL, THE NETHERLANDS**

(Name / Address)



THE CERTIFICATION IS A MULTILISTING BASED ON THE MODEL NO. LLA14050 WPT WITH THE TESTREPORT NR. G3M20110-1273-L
THE CONFIRMATION IS ONLY VALID IF THE NON-CONFIRMATION ITEMS ARE ELIMINATED

MANUFACTURER / IMPORTER

TEST LABORATORY

This is the result of test, that was carried out from the submitted type-samples of a product in conformity with the specification of the respective standards. The certificate holder has the right to fix the CE-mark for LVD on the product complying with the inspection sample.

(Date)

(Surname, forename)
(Company stamp)



January 23, 2002

(Date)

Dr. Genz

Dr. Genz

ELECTRONIC TECHNOLOGY SYSTEMS DR. GENZ GMBH

STORKOWER STRASSE 38C, D-15526 REICHENWALDE B. BERLIN, GERMANY, PHONE + 49 33631-888 00 FAX + 49 33631-888 660

REGULATED BENCH TOP POWER SUPPLIES


65

REGULATED 13.8V POWER SUPPLY


Regulated 13.8Vdc power supply featuring an electronic control and a protection circuit. Short-circuit resistant 'FOLD BACK' current protection. Housed in a sturdy case fitted with an earthed mains plug. Power 230V/50Hz (fuse protected). ON/OFF switch with indicator. Output via red and black 4mm terminals.



	650.651	650.652	650.654	650.657
Cont. current	3A	5A	7A	10A
Peak current	5A	7A	9A	12A
Output voltage	13.8Vdc	13.8Vdc	13.8Vdc	13.8Vdc
Input voltage	230Vac/50Hz	230Vac/50Hz	230Vac/50Hz	230Vac/50Hz
Dimensions	70 x 125 x 110mm	70 x 125 x 110mm	100 x 140 x 240mm	100 x 160 x 175mm
Weight	2.5kg	2.8kg	3.0kg	3.5kg

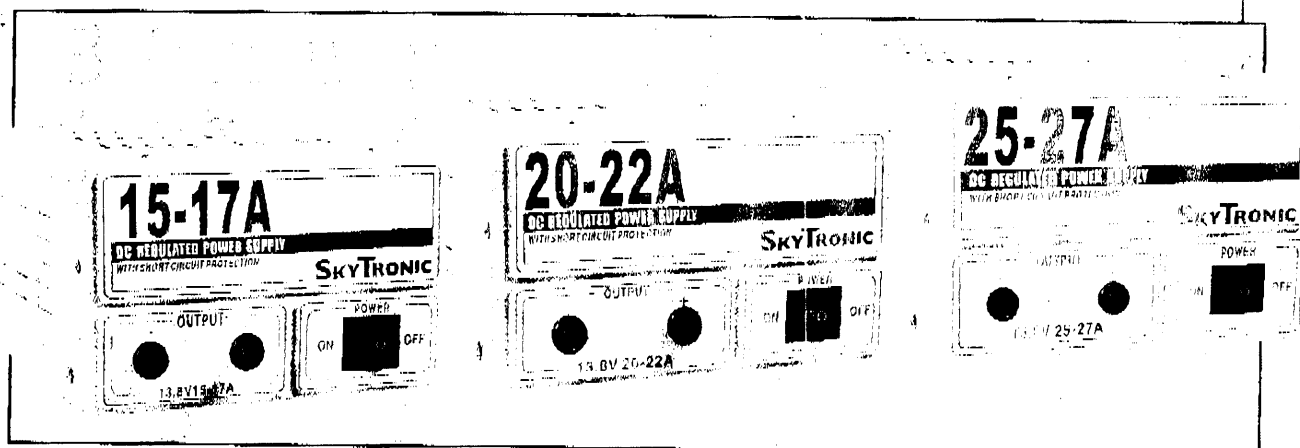

	650.660	650.663	650.667
Cont. current	15A	20A	25A
Peak current	17A	22A	27A
Output voltage	13.8Vdc	13.8Vdc	13.8Vdc
Input voltage	230Vac/50Hz	230Vac/50Hz	230Vac/50Hz
Dimensions	165 x 170 x 195mm	165 x 170 x 195mm	165 x 200 x 290mm
Weight	4.9kg	6.0kg	7.0kg

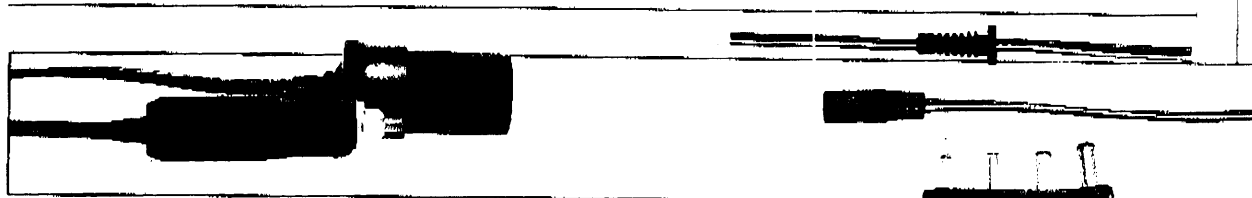

Ref.No. 660.459

NEW

CIGAR LIGHTER EXTENSION

Cigar lighter DC extension lead cigar plug to cigar socket. Length 2.0m.

Ref.No. 660.456

NEW

DC POWER LEAD

Universal DC power lead with 4 detachable plugs. Length 1.8m.

Red Power Supplies