

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1552200235](#)
Status: **Active**
Overview: Flamar Standard Cables for Industrial Automation
Description: Flamar Control Cable, WSOR Jacket, Unshielded, 5 Circuits, 16 AWG with Green/
 Yellow Ground, 8.60mm Diameter, 200.0m Length, Black

Documents:

[Product Specification 1552200001-P1E \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

[Product Literature \(PDF\)](#)

General

Product Family	Cable
Series	155220
Bending Radius - Minimum	> 7.5xOD
Color - Cable Jacket	Black
Crimp Quality Equipment	Yes
Geographic Area	Global
Material - Outer Jacket	WSOR
Outer Jacket Diameter	8.60mm (.339")
Overview	Flamar Standard Cables for Industrial Automation
Product Literature Order No	987651-3992
Product Name	Flamar
UPC	889056461290

Physical

Cable Length	200.0m
Circuits (Loaded)	5
Insulation	TPE
Net Weight	0.010/g
Packaging Type	Reel
Temperature Range - Operating	-25°C to +80°C
Wire Size AWG	16
Wire Size mm ²	1.50
Wire/Cable Type	Signal and Control, UL AWM 21215 / CSA

Electrical


Current - Maximum per Contact	Contact Molex
Voltage - Maximum	600V

Material Info

Engineering Number	1X200M
--------------------	--------

Reference - Drawing Numbers

Product Specification	1552200001-P1E
-----------------------	----------------

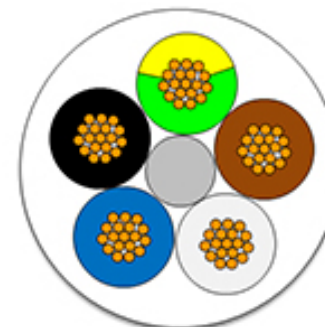

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

China RoHS

Search Parts in this Series

[155220](#) Series

Use With

DIN Valve Connectors [121201](#) ,
[121202](#) , [121207](#) , [121208](#) , [121205](#)
 , [121211](#)
Micro-Change® (M12)
[120071](#)
Ultra-Lock® (M12) [120085](#)

GWconnect® Heavy Duty Connectors
[93601](#)