

HSK-EMC cable glands

HSK-M-EMV-D


Metr., Metr.-elongated




Material	Nickel plated brass
Clamping insert	Metalised polyamide
Seal	Buna-N
O-Ring	Buna-N
Protection	IP 68 – 10 bar / IP 69K (NEMA 6 – 150 PSIG) within the specified clamping range
Operating Temperature	-40 °C – 100 °C (-40 °F – 212 °F)



Advice:
- Other sealing material e.g. Silicone upon request

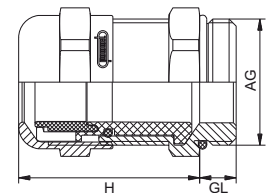

AG	$\varnothing k$ mm	GL mm	H mm	\varnothing mm	Number	GL mm	Number long
M 12 x 1,5	3 – 6,5	6,5	25	14	1.631.1200.50	10	1.631.1200.30
M 16 x 1,5	4 – 8	6	29	17 / 19	1.631.1609.50	10	1.631.1609.30
M 16 x 1,5	5 – 10	6	32	20	1.631.1600.50	10	1.631.1600.30
M 20 x 1,5	6 – 12	6	32,5	22	1.631.2013.50	10	1.631.2013.30
M 20 x 1,5	10 – 14	6	33	24	1.631.2000.50	10	1.631.2000.30
M 25 x 1,5	13 – 18	7	39	30	1.631.2500.50	12	1.631.2500.30
M 32 x 1,5	18 – 25	8	45	40	1.631.3200.50	12	1.631.3200.30
M 40 x 1,5	24 – 32	8	51	50	1.631.4000.50	15	1.631.4000.30
M 50 x 1,5	32 – 38	9	57,5	57	1.631.5000.50	15	1.631.5000.30
M 63 x 1,5	37 – 44	10	52	64 / 68	1.631.6300.50	15	1.631.6300.30

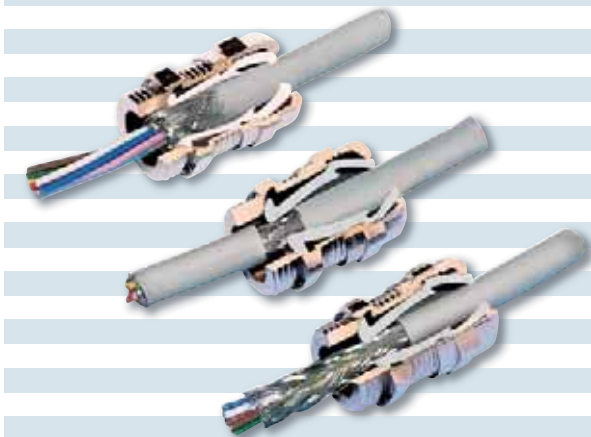

➔ Accessories see page 71