

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1300140061](#)
Status: **Active**
Overview: [Brad® Mini-Change® Connectors](#)
Description: Mini-Change® B-Size Receptacle, 8 Poles, 1/2" - 14 NPT Threads, Female (Straight) to 16 AWG Leads, 0.305m (1.0') Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837
UL E152210

General

Product Family Industrial Receptacles
Series [130014](#)
Comments B-Size (1" - 16 UN-2A)
IP Rating IP67
NEMA Rating NEMA 6
Overview [Brad® Mini-Change® Connectors](#)
Product Name Mini-Change®
Type Single Ended (pigtail)
UPC 78678844077

Physical

Coupling Type External Thread
Gender Female
Keyway Single
Length 0.305m
Material - Component Zinc Die-Cast with Black Epoxy
Mounting Thread Size 1/2" - 14 NPT
Orientation Straight
Panel Mount N/A
Poles 8
Temperature Range - Operating -20°C to +105°C
Wire Size AWG 16
Wire/Cable Type UL 1015

Electrical


Current - Maximum per Contact 7.0A
Voltage - Maximum 600V AC/DC

Material Info

Old Part Number 2R8004A20A120

Reference - Drawing Numbers

Sales Drawing SD-130014-007

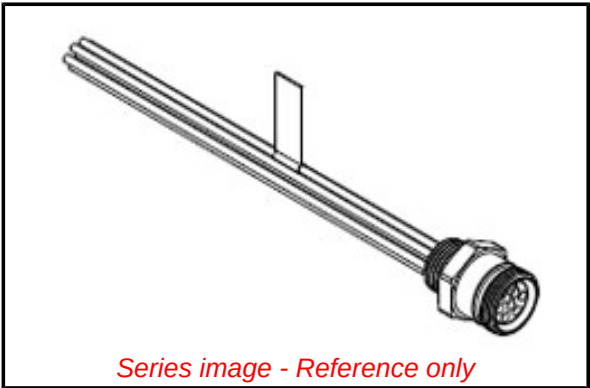

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS Not Reviewed
ELV Not Relevant

Search Parts in this Series

[130014](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION