

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0797580010](#)
Status: **Active**
Overview: [Pre-Crimped Leads](#)
Description: Pre-Crimped Lead Micro-Fit 3.0™ Female-to-Micro-Fit 3.0™ Female Tin Plated, 300mm, 20 AWG

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Cable Assemblies
Series	79758
Assembly Configuration	Pre-crimped Lead Only
Connector to Connector	Micro-Fit 3.0™ Crimp Terminals
Overview	Pre-Crimped Leads
Product Name	Micro-Fit 3.0™
UPC	884982052734


Physical

Cable Length	0.30m
Circuits (Loaded)	1
Color - Resin	Black
Gender	Female-Female
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	1.966/g
Packaging Type	Bag
Single Ended	No
Wire Size AWG	20
Wire/Cable Type	UL 1061

Material Info

Reference - Drawing Numbers

Sales Drawing	SD-797580001
---------------	--------------

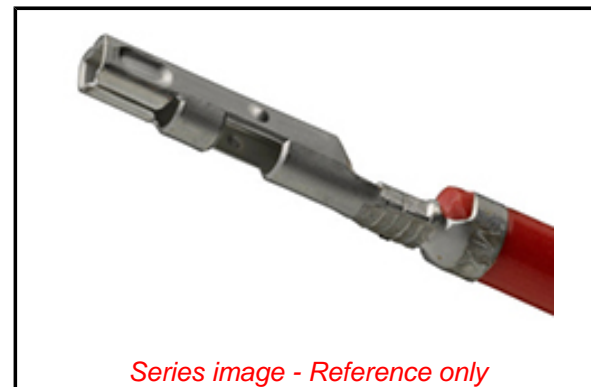

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/108/2014 (17 Dec
2014)

Halogen-Free

Status

Not Low-Halogen

**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS

ELV

Green Image

Not Relevant

Search Parts in this Series

[79758](#) Series

Mates With

[43031](#) Micro-Fit 3.0™ Male Crimp Terminals

Use With

[43645](#) , [43025](#) Micro-Fit 3.0™ Receptacle
Housings, [44133](#) , [44300](#) Micro-Fit BMI™
Panel Mount Housings