



Cabinet Fan Tops *C2TF Series*

Features

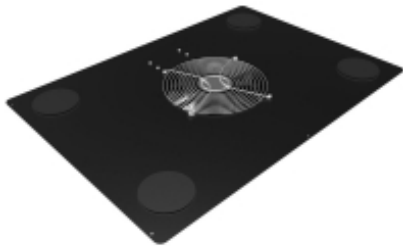

- Use only with Contempra 2 rack frames.
- 14 gauge steel construction.
- 4" fan top panel - fans not included (see below).
- 4 or 6 opening depending on depth of rack.
- Maximum flexibility - add fans OR leave holes open (for cable access) OR use covers (see below) OR any combination.

Gallery

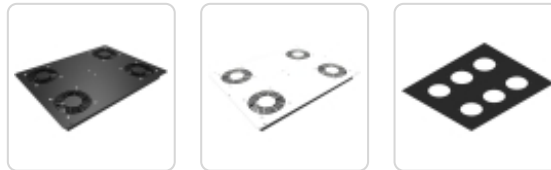

Fan top for use with Four (4) Inch Fans

Part No. Black	Part No. Light Gray	Number of Fan Holes
C2T1923FBK1	C2T1923FLG1	4
C2T1931FBK1	C2T1931FLG1	6
C2T1936FBK1	C2T1936FLG1	6
C2T2423FBK1	C2T2423FLG1	4
C2T2431FBK1	C2T2431FLG1	6
C2T2436FBK1	C2T2436FLG1	6

Fan Top with Pre-wired Four (4) Inch Fans

Part No. Black	Part No. Light Gray	Part No. Black	Part No. Light Gray	Noise (dB)
Thermostat Not Included		Adjustable Thermostat Included		
C2T1923F4BK1	C2T1923F4LG1	C2T1923F4TBK1	C2T1923F4TLG1	64
C2T1931F4BK1	C2T1931F4LG1	C2T1931F4TBK1	C2T1931F4TLG1	64
C2T1936F4BK1	C2T1936F4LG1	C2T1936F4TBK1	C2T1936F4TLG1	64
C2T2423F4BK1	C2T2423F4LG1	C2T2423F4TBK1	C2T2423F4TLG1	64
C2T2431F4BK1	C2T2431F4LG1	C2T2431F4TBK1	C2T2431F4TLG1	64
C2T2436F4BK1	C2T2436F4LG1	C2T2436F4TBK1	C2T2436F4TLG1	64

Includes a quantity of 4 - long life, ball bearing, 4", 115 volt, 50/60 Hz. AC, 100 CFM fans

Fan Top with Pre-wired Ten (10) Inch Fan

Part No. Black	Part No. Light Gray	Part No. Black	Part No. Light Gray	Noise (dB)
Cable Entry Holes Not Included		Four (4) 3.5 Inch Cable Entry Holes and Covers Included		
C2T1923F10BK1	C2T1923F10LG1	C2T1923F10CEBK1	C2T1923F10CELG1	60

Part No. Black	Part No. Light Gray	Part No. Black	Part No. Light Gray	Noise (dB)
Cable Entry Holes Not Included		Four (4) 3.5 Inch Cable Entry Holes and Covers Included		
C2T1931F10BK1	C2T1931F10LG1	C2T1931F10CEBK1	C2T1931F10CELG1	60
C2T1936F10BK1	C2T1936F10LG1	C2T1936F10CEBK1	C2T1936F10CELG1	60
C2T2423F10BK1	C2T2423F10LG1	C2T2423F10CEBK1	C2T2423F10CELG1	60
C2T2431F10BK1	C2T2431F10LG1	C2T2431F10CEBK1	C2T2431F10CELG1	60
C2T2436F10BK1	C2T2436F10LG1	C2T2436F10CEBK1	C2T2436F10CELG1	60

Includes quantity 1 - 10", 550 CFM, 115 V 50/60 Hz. AC fan

Fan Cover Plate

Part No.	DNFPBK1
----------	---------

Individually packaged 4 inch hole cover (hardware included)

Data subject to change without notice