

0.05 Watt – 3203 Series Sealed –




3mm Square

tyco Electronics



$H=2.0, W=3.0, D=3.5$
Supplied on 12mm embossed
tape (reel=1K pcs)

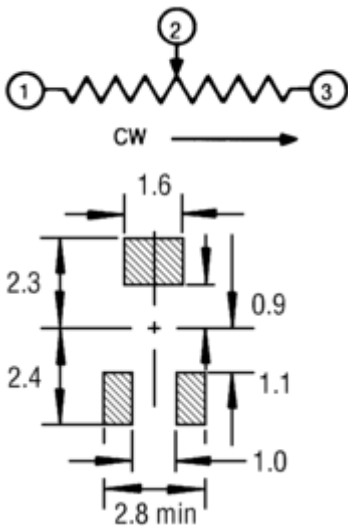

PCB layout

- Ultra compact cermet trimmers
- Sealed to withstand industrial cleaning solvents and modern soldering processes

Voltage rating	15V
Resistance tolerance	±25%
Operating temperature	-20°C to +85°C
Temperature coefficient	±250ppm/°C
Adjustment angle (no end stop)	260° ±20°
End resistance	15% max
Contact resistance variation	5% max
Soldering temperature	260°C for 5 secs. max.