
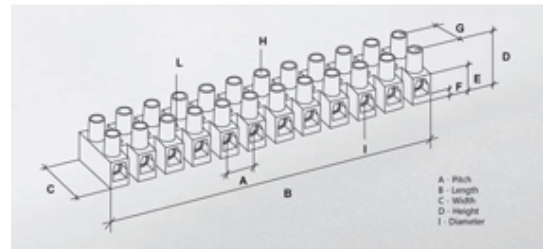


HY431/12 FV

12 pole red-brown polyamide PA6.6, with 25% glass fibre reinforced pillar terminal block 8mm pitch 24a 450v

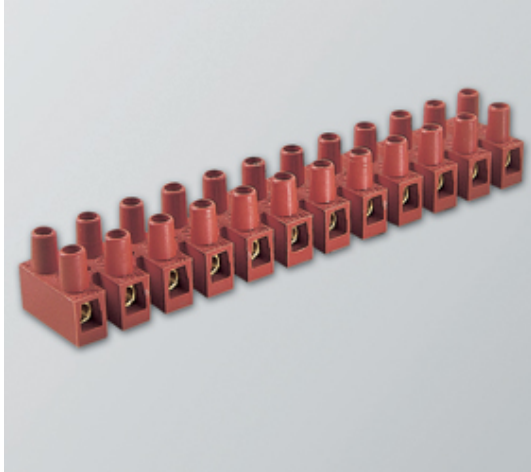

SPECIFICATION

Number of Poles	12
Terminal Material	OT58 nickel plated
Body Material	Polyamide PA6.6, with 25% glass fibre reinforced
Colour	Red-brown
Glow Wire Resistance Test Temp	GWT750°C in 2 sec (EN60695-2-11)
Max Conductor Size (Sq mm)	2.5
Max Current (A)	24
Max Voltage (V)	450
Working Temperature	150
Pitch (mm)	8
Height (mm)	15
Width (mm)	16.5
Length (mm)	94.5
Diameter (mm)	2.6
Terminal Screw Material	White zinc plated steel